
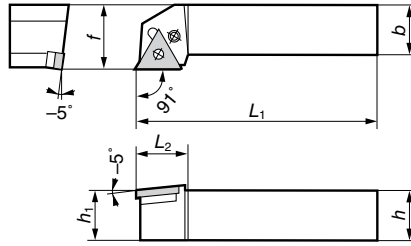
 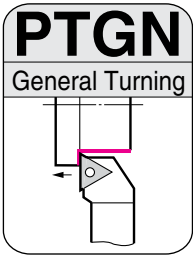


PTGN / PTTN Type




SEC- 70 Type Tool Holders

General Turning and Copying

Lever Lock



■ Spare Parts

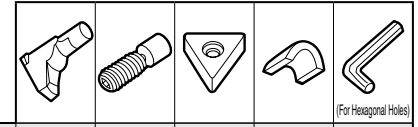

■ Holders

Above figures show right hand tools.

Cat. No.	Conventional Cat. No.	Stock		Dimensions (mm)						Applicable Inserts		Lever Pin	Bolt	Shim	Shim Pin	Spanner
		R	L	h	b	L ₁	f	h ₁	L ₂	Cat. No.	Ref. Page					
PTGN R/L1616H16	PTGN R/L1616-33	●	●	16	16	100	20	16	20	TN□□1604	From B54	LCL3	LCS3	LST317	LSP3	LH025
PTGN R/L2020K16	PTGN R/L2020-33	●	●	20	20	125	25	20	20							
PTGN R/L2520M16	PTGN R/L2520-33			25	20	150	25	25	20							
PTGN R/L2525M16	PTGN R/L2525-33	●	●	25	25	150	32	25	20							
PTGN R/L3225P16	PTGN R/L3225-33			32	25	170	32	32	20							
PTGN R/L2525M22	PTGN R/L2525-43	●	●	25	25	150	32	25	28	TN□□2204	B59	LCL4	LCS4	LST42	LSP4	LH030
PTGN R/L3225P22	PTGN R/L3225-43			32	25	170	32	32	28							
PTGN R/L3232P22	PTGN R/L3232-43			32	32	170	40	32	28							
PTGN R/L3232P27	PTGN R/L3232-54			32	32	170	40	32	33							
PTGN R/L4040R27	PTGN R/L4040-54			40	40	200	50	40	33							

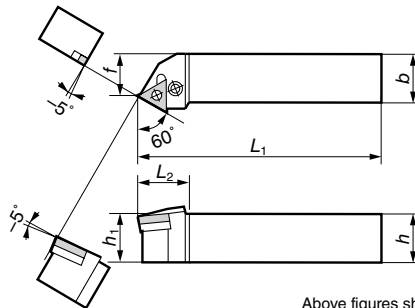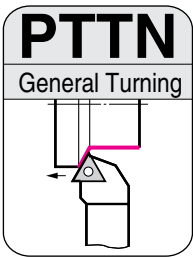


SEC- 70 Type Tool Holders

General Turning and Copying

Lever Lock

■ Spare Parts

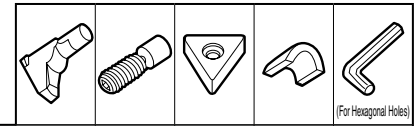

■ Holders

Above figures show right hand tools.

Cat. No.	Conventional Cat. No.	Stock		Dimensions (mm)						Applicable Inserts		Lever Pin	Bolt	Shim	Shim Pin	Spanner
		R	L	h	b	L ₁	f	h ₁	L ₂	Cat. No.	Ref. Page					
PTTN R/L1616H16	PTTN R/L1616-33	●	●	16	16	100	13	16	25	TN□□1604	From B54	LCL3	LCS3	LST317	LSP3	LH025
PTTN R/L2020K16	PTTN R/L2020-33	●	●	20	20	125	17	20	25							
PTTN R/L2520M16	PTTN R/L2520-33			25	20	150	17	25	25							
PTTN R/L2525M16	PTTN R/L2525-33	●	●	25	25	150	22	25	25							
PTTN R/L3225P16	PTTN R/L3225-33			32	25	170	22	32	25							
PTTN R/L2525M22	PTTN R/L2525-43			25	25	150	22	25	25	TN□□2204	B59	LCL4	LCS4	LST42	LSP4	LH030
PTTN R/L3225P22	PTTN R/L3225-43			32	25	170	22	32	25							

External Holders

Negative Inserts

C

D

R

S

T

V

W