




# MDHコイルスクレーパ

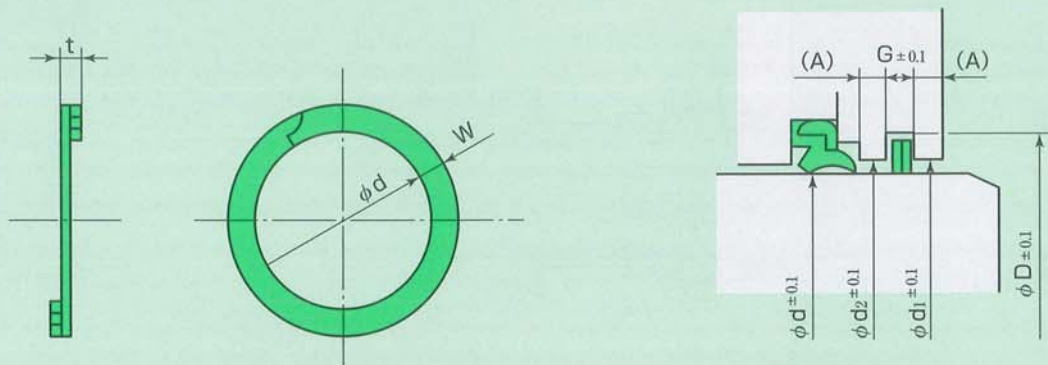

MDHコイルスクレーパ寸法表

単位：mm

呼び番号	コイルスクレーパおよびみぞ寸法									
	標準 (PBW 2)	d	w	t	巻数	D	d <sub>1</sub>	d <sub>2</sub>	G	A
MDH- 16	MDH- 16	16	2.15	1.1	1%	20.7	18	17	1.3	2
MDH- 18	MDH- 18	18	2.15	1.1	1%	22.7	20	19	1.3	2
MDH- 20	MDH- 20	20	2.15	1.1	1%	24.7	22	21	1.3	2
MDH- 22	MDH- 22	22	2.15	1.1	1%	26.7	24	23	1.3	2
MDH- 22.4	MDH- 22.4	22.4	2.15	1.1	1%	27.1	24.4	23.4	1.3	2
MDH- 25	MDH- 25	25	2.15	1.1	1%	29.7	27	26	1.3	2
MDH- 28	MDH- 28	28	2.15	1.1	1%	32.7	30	29	1.3	2
MDH- 30	MDH- 30	30	2.15	1.1	1%	34.7	32	31	1.3	2
MDH- 31.5	MDH- 31.5	31.5	2.15	1.1	1%	36.2	33.5	32.5	1.3	2
MDH- 32	MDH- 32	32	2.15	1.1	1%	36.7	34	33	1.3	2
MDH- 35	MDH- 35	35	2.15	1.1	1%	39.7	37	36	1.3	2
MDH- 35.5	MDH- 35.5	35.5	2.15	1.1	1%	40.2	37.5	36.5	1.3	2
MDH- 36	MDH- 36	36	2.15	1.1	1%	40.7	38	37	1.3	2
MDH- 40	MDH- 40	40	2.15	1.1	1%	44.7	42	41	1.3	2
MDH- 45	MDH- 45	45	2.15	1.1	1%	49.7	47	46	1.3	2
MDH- 50	MDH- 50	50	2.15	1.1	1%	54.7	52	51	1.3	2
MDH- 55	MDH- 55	55	4	1.55	1%	64	57	56	2	3
MDH- 56	MDH- 56	56	4	1.55	1%	65	58	57	2	3
MDH- 60	MDH- 60	60	4	1.55	1%	69	62	61	2	3
MDH- 63	MDH- 63	63	4	1.55	1%	72	65	64	2	3
MDH- 65	MDH- 65	65	4	1.55	1%	74	67	66	2	3
MDH- 70	MDH- 70	70	4	1.55	1%	79	73	71	2	3
MDH- 71	MDH- 71	71	4	1.55	1%	80	74	72	2	3
MDH- 75	MDH- 75	75	4	1.55	1%	84	78	76	2	3
MDH- 80	MDH- 80	80	4	1.55	1%	89	83	81	2	3
MDH- 85	MDH- 85	85	4	1.55	1%	94	88	86	2	3
MDH- 90	MDH- 90	90	4	1.55	1%	99	93	91	2	3
MDH- 95	MDH- 95	95	4	1.55	1%	104	98	96	2	3
MDH- 100	MDH- 100	100	4	1.55	1%	109	103	101	2	3

★ご注文・お問合せは、呼び番号にてご指示下さい。

★表中・呼び番号が色地のものは在庫しております。