

# Standard Pressed Steel Castors –Medium duty type–

RoHS compliant products.

## POINT

- SISIKU's unique point - **Box style wheel**.
- Smooth swiveling by **double bearing** in the swivel head.
- JB stopper lever **locks the wheel and the swivel simultaneously** when the equipment is in a stationary state.
- **JB and KB** stopper levers are available in both **the right and left versions**.
- Precision radial ball bearings for wheel CW, SST, UW, WUW and MC.
- **Smooth and silent rolling** without subsequent lubrication.



Swivel with stopper (Left/Right)



Fixed with stopper (Left/Right)

Plastic tipped end only available for swivel with stopper (Right version).

## USE EXAMPLE

- For various carriers.
- For various kinds of industrial equipment.

◎We'll accept your custom-order. Please feel free to contact us.  
(Use "Specification Form for Custom-designed castor" at the end of this catalog.)  
◎Please feel free to ask about the product weight for each item.

**Options** Upon request

Swivel with Single stopper  
For  $\phi 130, 150$  and 200.  
A stopper locks wheel only.

**Options**

Swivel/Fixed with foot safeguard  
For  $\phi 150$  and 200.

### J Swivel castors



J-75
J-100
J-130
J-150
J-180 (available with W)
J-200
J-250
J-300 (available with W, UW, LW and MC)

● Color/Finish; Zinc plated

### JB Swivel with stopper (Right)



JB-75
JB-100
JB-130
JB-150
* JB-180 (available with W)
JB-200
** JB-250
—
—

\*JB and JB (L): Upon request.  
\*\*JB-250: Without plastic tipped end.

### JB (L) Swivel with stopper (Left)



—
JB-100 (L)
JB-130 (L)
JB-150 (L)
* JB-180 (L) (available with W)
JB-200 (L)
—
—

### K Fixed castors



K-75
K-100
K-130
K-150
K-180 (available with W)
K-200
K-250
K-300 (available with W, UW, LW and MC)

● Color/Finish; Zinc plated

### KK Fixed castors



—
KK-100
KK-130
KK-150
—
—
—
—

### KB Fixed with stopper (Right)



KB-75
KB-100
KB-130
KB-150
*** KB-180 (available with W)
KB-200
—
—

\*\*\*KB and KB (L): Upon request.

### KB (L) Fixed with stopper (Left)



—
KB-100 (L)
KB-130 (L)
KB-150 (L)
*** KB-180 (L) (available with W)
KB-200 (L)
—
—

## WHEELS

ベアリング変更 (MCを除く) JBB→CB

CB ...Pressed bearing JBB ...Radial ball bearing OL ...Oilless bushing



CW (SBR)  
<Made in China>  
NB  $\phi 100, \phi 130, \phi 150$  and  $\phi 200$ .




W (SBR)



SST (NR)  
● Runs more lightly compared with W!  
● Impact resistance: 1.8 times higher than W. Starting performance: 2.5 times better than W.  
NB  $\phi 100, 150$  and 200.



UW (UR)

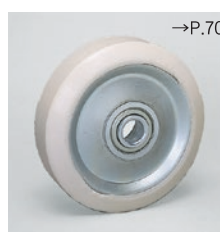

WUW (Antibacterial UR/White)  
● Antibacterial effect, oil resistance and high elasticity.  
● Floor saving and non-marking.



WW (BR)  
● Cold resistance (-40°C~+90°C)  
● Floor saving and non-marking.

LW (BR)