

Inspection Mirror



●Parts are listed from p.243

Item Code	Description	Shaft Length (mm)	Weight (g)	JAN Code	Packing Unit	Package
75758	A-1 Circle 60 mm	125×63×14 (folded)	53	4 960910 757585	10	
75759	A-2 Circle 36 mm	135×38×14 (folded)	40	4 960910 757592		
75756	A-3 Oval 50 x 80 mm	150×53×14 (folded)	56	4 960910 757561		
75757	A-4 Oval 25 x 50 mm	135×28×14 (folded)	42	4 960910 757578		

Features

- Mirror angle can be easily adjusted
- Extend handle and use mirror to inspect places that are difficult to see, such as behind objects or narrow spots
- With clip

Use

- For inspection or observation of car engines, inside and behind machines, etc.

Car engines Inside and behind machines



Specifications

Item Code	75758	75759	75756	75757
Maximum Extension	Up to 645 mm	Up to 690 mm	Up to 660 mm	Up to 670 mm
Maximum extension of antenna	530 mm	600 mm	530 mm	600 mm
Material	Shaft: Brass Mirror Frame: ABS resin Mirror: Glass			

Inspection Mirror with LED Light



●Parts are listed from p.243

Item Code	Description	Shaft Length (mm)	Weight (g)	JAN Code	Packing Unit	Package
74155	D-1 Circle 60 mm	160×62×34 (folded)	70	4 960910 741553	10	
74156	D-2 Circle 36 mm	160×38×34 (folded)	55	4 960910 741560		
74157	D-3 Oval 50 x 80 mm	160×53×34 (folded)	73	4 960910 741577		
74158	D-4 Oval 25 x 50 mm	160×28×34 (folded)	57	4 960910 741584		

Features

- Clear vision even in a dark and tight place
- High brightness LED light shines a light on inspection point by reflecting light in the mirror
- Compact for easy carrying
- Shaft can be extended in seven steps
- With clip



Use

- For inspection or observation of car engines, inside and behind machines, etc.

Specifications

Item Code	74155	74156	74157	74158
Power Source	3x alkaline batteries LR44 (included) (Batteries included are for trial use only and may not last as long)			
Luminosity	30,000 mcd *Varies depending on usage situation			
Maximum Extension	Up to 675 mm	Up to 645 mm	Up to 660 mm	Up to 695 mm
Maximum extension of antenna	530 mm			
Material	Shaft: Brass Mirror Frame, Light: Glass, Light: ABS resin Mirror: Glass			

Magnifying Mirror




●Parts are listed from p.243

Item Code	Description	Shaft Length (mm)	Weight (g)	JAN Code	Packing Unit	Package
75790	B-1 Circle 60 mm 2x	140×63×14 (folded)	53	4 960910 757905	10	
75791	B-2 Circle 36 mm 2x	135×38×14 (folded)	40	4 960910 757912		
75788	B-3 Oval 50 x 80 mm 2x	140×53×14 (folded)	56	4 960910 757882		
75789	B-4 Oval 25 x 50 mm 2x	140×28×14 (folded)	42	4 960910 757899		

Features

- Mirror angle can be easily adjusted
- Extend handle and use mirror to inspect places that are difficult to see, such as behind objects or narrow spots
- With clip

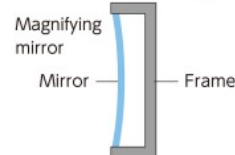

Recessed surface mirror enlarges x 2

Use

- For inspection or observation of car engines, inside and behind machines, etc.

Specifications

Item Code	75790	75791	75788	75789
Maximum Extension	Up to 640 mm	Up to 690 mm	Up to 670 mm	
Maximum extension of antenna	530 mm	600 mm	530 mm	600 mm
Material	Shaft: Brass Mirror Frame: ABS resin Mirror: Glass			