

ポジインサート・マルチコーナタイプ G級


3

超高压焼結体工具

仕 様	外 観	形 番	在庫材種				数 コー ナ 口	寸 法 (mm)						適合ホルダ
			BXM10	BXM20	BX470	BX910		逃げ角 θ	内接円 ϕd	厚さ s	穴径 ϕd_1	コーナ 半径 r_E	CBN長 a	
汎用		2QP-CCGW060202	●	●			2	7°	6.35	2.38	2.8	0.2	2.3	外径用TACバイト (4-63 ~) 内径用TACバイト (5-12 ~) ツーリングシステム (12-47 ~)
		2QP-CCGW060204	●	●	●		2	7°	6.35	2.38	2.8	0.4	2.3	
汎用		2QP-CCGW09T302					2	7°	9.525	3.97	4.4	0.2	2.3	
		2QP-CCGW09T304	●	●	●		2	7°	9.525	3.97	4.4	0.4	2.3	
		2QP-CCGW09T308	●	●	●		2	7°	9.525	3.97	4.4	0.8	2.2	
汎用		2QP-DCGW070202	●	●			2	7°	6.35	2.38	2.8	0.2	2.7	外径用TACバイト (4-63 ~) 内径用TACバイト (5-16 ~)
		2QP-DCGW070204	●	●	●		2	7°	6.35	2.38	2.8	0.4	2.5	
2QP-DCGW070208				●		2	7°	6.35	2.38	2.8	0.8	2.5		
シャープ エッジ		2QP-DCGW11T302F			●		2	7°	9.525	3.97	4.4	0.2	2.7	
	2QP-DCGW11T304F			●		2	7°	9.525	3.97	4.4	0.4	2.5		
汎用		2QP-DCGW11T302	●	●			2	7°	9.525	3.97	4.4	0.2	2.7	
		2QP-DCGW11T304	●	●	●		2	7°	9.525	3.97	4.4	0.4	2.5	
		2QP-DCGW11T308	●	●	●		2	7°	9.525	3.97	4.4	0.8	2.1	
汎用		2QP-SPGW09T308				●	2	11°	9.525	3.97	4.4	0.8	2.4	
		2QP-SPGW09T312				●	2	11°	9.525	3.97	4.4	1.2	2.4	
汎用		2QP-SPGW120408				●	2	11°	12.7	4.76	5.5	0.8	2.4	
		2QP-SPGW120412				●	2	11°	12.7	4.76	5.5	1.2	2.4	
		2QP-SPGW120416				●	2	11°	12.7	4.76	5.5	1.6	2.4	
汎用		2QP-SPGN090308				●	2	11°	9.525	3.18	-	0.8	2.4	
		2QP-SPGN090312				●	2	11°	9.525	3.18	-	1.2	2.4	
汎用		3QP-TPGW080202					3	11°	4.76	2.38	2.3	0.2	2.4	内径用TACバイト (5-20 ~)
		3QP-TPGW080204	●	●			3	11°	4.76	2.38	2.3	0.4	2.2	
汎用		3QP-TPGW090202		●			3	11°	5.56	2.38	2.5	0.2	2.3	ツーリングシステム (12-63 ~)
		3QP-TPGW090204	●	●			3	11°	5.56	2.38	2.5	0.4	2.2	
汎用		3QP-TPGW110202		●			3	11°	6.35	2.38	2.8	0.2	2.3	
		3QP-TPGW110204	●	●	●		3	11°	6.35	2.38	2.8	0.4	2.2	
			3QP-TPGW110208			●		3	11°	6.35	2.38	2.8	0.8	2.2
シャープ エッジ		3QP-TPGW110302F					3	11°	6.35	3.18	3.4	0.2	2.3	
		3QP-TPGW110304F			●		3	11°	6.35	3.18	3.4	0.4	2.2	
			3QP-TPGW110308F			●		3	11°	6.35	3.18	3.4	0.8	2
汎用		3QP-TPGW110302		●			3	11°	6.35	3.18	3.4	0.2	2.3	
		3QP-TPGW110304	●	●	●		3	11°	6.35	3.18	3.4	0.4	2.2	
			3QP-TPGW110308	●	●	●	●	3	11°	6.35	3.18	3.4	0.8	1.9
汎用		3QP-TPGW130302		●				3	11°	7.94	3.18	3.4	0.2	2.3
		3QP-TPGW130304	●	●			3	11°	7.94	3.18	3.4	0.4	2.2	
			3QP-TPGW130308					3	11°	7.94	3.18	3.4	0.8	2
汎用		3QP-TPGW16T302						3	11°	9.525	3.97	4.4	0.2	2.3
		3QP-TPGW16T304	●	●			3	11°	9.525	3.97	4.4	0.4	2.2	
			3QP-TPGW16T308	●	●			3	11°	9.525	3.97	4.4	0.8	1.9
シャープ エッジ		3QP-TPGW160402F						3	11°	9.525	4.76	4.4	0.2	2.3
	3QP-TPGW160404F						3	11°	9.525	4.76	4.4	0.4	2.2	
		3QP-TPGW160408F					3	11°	9.525	4.76	4.4	0.8	2	
汎用		3QP-TPGW160404	●	●			3	11°	9.525	4.76	4.4	0.4	2.2	
		3QP-TPGW160408		●			3	11°	9.525	4.76	4.4	0.8	2	
汎用		3QP-TPGN110308				●	3	11°	6.35	3.18	-	0.8	1.9	
		3QP-TPGN110312				●	3	11°	6.35	3.18	-	1.2	2.4	

製品在庫 ●:在庫形番

ポジインサート

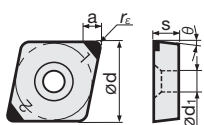

標準ホーニング仕様

▶ 3-6

材種	BXM10	BXM20	BXC50	BX310	BX330	BX360	BX380	BX470	BX480	BX910	BX930	BX950
ネガインサート	S01325	S01325	S01325	S01325	S01325	S01325	S01325	T01315	S01325	S01315	S01315	S01325
ポジインサート	S01325	S01325	-	S00515	S00515	S00515	-	T01315	-	S01315	S00515	S00515