

# Parallel Plates

The number next to the logo mark indicates items in stock for each brand.



Stock 38,650 Items

## Centering Plate "Sukeita"



- Features**
- Various tool bit, jig and other underlying lathes, cicar board, milling, sewing machine, drill press can be used for all centering, very convenient.
  - Also available for thickness adjustment.
- Use**
- For centering work.
- Origin**
- Japan



SKE-1 (15 sheets set)

### Set Contents



### Sukeita Set

Order Unit: 1 Set


TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per set)	MSRP (per set)	W x L (mm)	Set Contents Thickness (mm) x Number of Plates	SPQ (set)	Weight (g/set)
109-0704	SKE-1	¥1,666	¥1,800	20 x 120	0.2 x 2, 0.3 x 3, 0.5 x 4, 1.0 x 3, 1.5 x 1, 2.0 x 1, 3.0 x 1	12	250

### Individual Sukeita

Order Unit: 1 Sheet

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	W x L x Thickness (mm)	SPQ (sheet)	Weight (g)
768-1593	SKE-BARA-02	¥407	¥440	20 x 120 x 0.2	10	10
768-1607	SKE-BARA-03	¥407	¥440	20 x 120 x 0.3	10	10
768-1615	SKE-BARA-05	¥407	¥440	20 x 120 x 0.5	10	10
768-1623	SKE-BARA-10	¥407	¥440	20 x 120 x 1.0	10	20
768-1631	SKE-BARA-15	¥407	¥440	20 x 120 x 1.5	10	30
768-1640	SKE-BARA-20	¥407	¥440	20 x 120 x 2.0	10	40
768-1658	SKE-BARA-30	¥407	¥440	20 x 120 x 3.0	10	60

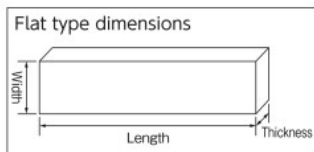


Contact us: 0120-509-849 <http://www.orange-book.com/>



NEW STRONG

Stock 680 Items

## Hardened Ground Parallel

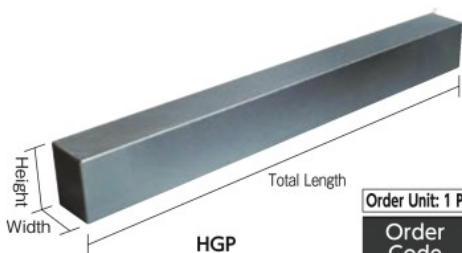

- Features**
- Parallelism is established and precision machining is enabled, which leads to improvement in efficiency.
- Specs**
- Four sides polished finishing
  - Hardness: HRC45
  - Height parallelism: ±0.01mm
  - Width parallelism: ±0.013mm
  - Accuracy: ±0.01mm (W x H), ±0.5mm (total length)
- Materials**
- S45C
- Origin**
- Japan

Order Unit: 1 Piece

NEW STRONG

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Height (mm)	Width (mm)	Total Length (mm)	SPQ (piece)	Weight (kg)
780-6043	HGP-100	¥ 8,640	¥ 8,500	12	8	100	1	0.08
780-6051	HGP-101	¥ 8,910	¥ 8,700	15	8	100	1	0.10
780-6060	HGP-102	¥ 9,315	¥ 9,100	15	10	100	1	0.13
780-6078	HGP-103	¥10,125	¥ 9,940	20	10	100	1	0.17
780-6086	HGP-104	¥10,260	¥10,100	25	10	100	1	0.22
780-6094	HGP-105	¥10,125	¥ 9,940	15	12	100	1	0.16
780-6108	HGP-106	¥10,260	¥10,100	20	12	100	1	0.21
780-6116	HGP-107	¥11,610	¥11,400	25	12	100	1	0.26
780-6124	HGP-108	¥14,175	¥13,900	20	16	150	1	0.42
780-6132	HGP-109	¥11,340	¥11,100	25	16	150	1	0.53
780-6141	HGP-110	¥15,390	¥15,200	30	16	150	1	0.64
780-6159	HGP-111	¥15,795	¥15,500	25	20	200	1	0.88
780-6167	HGP-112	¥15,930	¥15,700	30	20	200	1	1.05
780-6175	HGP-113	¥13,095	¥12,900	40	20	200	1	1.40
780-6183	HGP-114	¥17,685	¥17,400	30	25	250	1	1.64
780-6191	HGP-115	¥19,170	¥18,900	40	25	250	1	2.20
780-6205	HGP-116	¥21,330	¥21,000	50	25	250	1	2.75
780-6213	HGP-117	¥23,355	¥23,000	40	28	300	1	2.95
780-6221	HGP-118	¥24,165	¥23,800	50	28	300	1	3.70
780-6230	HGP-119	¥26,865	¥26,500	75	38	300	1	5.00
780-6248	HGP-120	¥29,565	¥29,200	75	38	300	1	7.50

Contact us: 06-6747-0771 <http://www.newstrong.co.jp/>