


Prices displayed include 8% tax.

BESSEY Stock 100 Items **L Type Clamp**

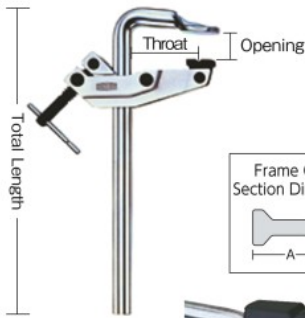

- Features**
- Because the tightening handle is attached to the outside of the rail, it can be used in a narrow place.
 - By replacing the arm part and attaching the GRD of the separately sold attachment, you can work to spread out.
 - For steel and sheet metal.
- Materials**
- Carbon Steel Tools
- Origin**
- Germany

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	Throat (mm)	Frame Dimension (mm)		SPQ (piece)	Weight (kg)
							A	B		
423-5550	GRA-30-12	¥21,955	¥24,910	410	300	120	28	11	5	2.6
423-5568	GRA-60-12	¥24,331	¥27,610	710	600	120	28	11	5	3.3
423-5541	GRA-100-12	¥29,129	¥33,040	1110	1000	120	28	11	5	4.3

Attachment Origin • China

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	SPQ (piece)	Weight (g)
324-9191	GRD	¥3,734	¥4,250	1	700

Contact us: 06-6531-0085 <http://www.daidokogyo-kk.co.jp/>

Clamps · Vices

Toggle Clamps

Hand Vices

Grip Pliers

C-Clamps

L Type Clamp

Clamps for Temporary Structures

Welding Clamps

Hand Clamps


Bar Clamps

Special Clamps

Vices

Parts for Vices

TRUSCO Stock 38,650 Items **Clamp Deep Jaw Type**

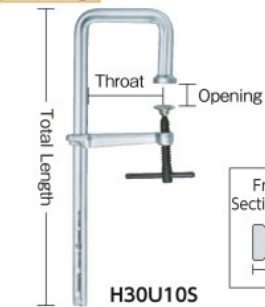


- Features**
- Even if there are obstacles, tightening is possible because of the deep jaw.
- Materials**
- Cold Rolled Steel Material
- Origin**
- Taiwan

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	Throat (mm)	Frame Dimension (mm)		SPQ (piece)	Weight (kg)
							A	B		
490-1193	H25U6S	¥ 5,526	¥ 5,970	410	250	120	22	10.5	2	1.50
490-1207	H30U10S	¥ 6,970	¥ 7,530	510	300	140	25	12.0	2	2.35
490-1215	H30U11S	¥ 9,600	¥10,370	535	300	140	30	15.0	2	3.38
490-1223	H50U11S	¥11,062	¥11,950	735	500	140	30	15.0	2	4.02
490-1231	H30U15S	¥17,774	¥19,200	600	300	175	40	20.0	2	6.80
490-1240	H40U15S	¥18,958	¥20,480	700	400	175	40	20.0	2	7.38
490-1258	H50U15S	¥20,337	¥21,970	800	500	175	40	20.0	2	7.94

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items **Clamp MULTI Deep Jaw Type**

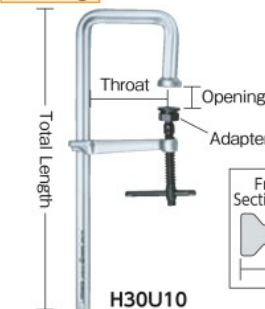

- Features**
- Even if there are obstacles, tightening is possible because of the deep jaw.
 - Tightening angle up to approximately 35° can be possible using the powerful type adapter.
- Materials**
- Cold Rolled Steel Material
- Origin**
- Taiwan

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	Throat (mm)	Frame Dimension (mm)		SPQ (piece)	Weight (kg)
							A	B		
490-1266	H25U6	¥ 6,906	¥ 7,460	410	250	120	22	10.5	2	1.58
490-1274	H30U10	¥ 8,711	¥ 9,410	510	300	140	25	12.0	2	2.46
490-1282	H30U11	¥11,998	¥12,960	535	300	140	30	15.0	2	3.67
490-1291	H50U11	¥13,830	¥14,940	735	500	140	30	15.0	2	4.28
490-1304	H30U15	¥22,217	¥24,000	600	300	175	40	20.0	2	7.20
490-1312	H40U15	¥23,698	¥25,600	700	400	175	40	20.0	2	7.72
490-1321	H50U15	¥25,420	¥27,460	800	500	175	40	20.0	2	8.28

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Orange Jr. Book

A pro-tool compact catalog that lists a wide variety of products all in one, including nearly every category on Orange-Book!

Published once every 2 years

Number of Products Listed: approx. **56,000** items

Number of Off-the-shelf Products: approx. **53,200**, off-the-shelf ratio **95%**

Number of Listed Manufacturers: approx. **1,419** companies

Number of Catalog Pages: approx. **2,700** pages

Order Code	Item No.	Price (tax not included)
858-5867	OBJM2018E	¥5,500

