

# Plate Type Rubber Casters (for light/medium load)

Stock 646Items

2-649


Prices displayed include 8% tax.

TRUSCO Stock 38,650 Items

## Plate Type Caster "α Press Rubber Caster"



- Features**
- The adjustable pivot part adopts a double bearing, smooth rotation was achieved.
  - The wheel rotating part has excellent durability with commercial bearing.
  - Steel wheels are shaped like a star with distinctive design characteristics. (registered design)
- Specs**
- Plate Type
  - With bearing
- Materials**
- Metal Fitting: Steel
  - Metal Fitting Surface Treatment: Unichrome Plated Finishing
  - Wheel: Steel Wheel, Rubber
- Origin**
- China

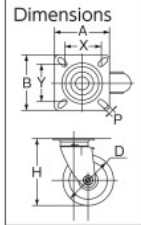


**Flexible** Specs •Flexible Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
288-9951	TJ-100C	¥1,351	¥1,460	80 82	100	35	144	95 x 95	67 to 74 x 67 to 74	10.5	18	1.15
288-9960	TJ-130C	¥2,129	¥2,300	140 143	130	42	177	110 x 110	75 to 90 x 75 to 90	11.0	10	1.95
288-9978	TJ-150C	¥2,370	¥2,560	161 164	150	45	198	120 x 120	75 to 90 x 75 to 90	11.0	8	2.25
299-6081	TJ-200C	¥3,758	¥4,060	200 204	200	46	250	140 x 140	100 to 115 x 100 to 115	11.5	4	3.75


TRUSCO NAKAYAMA CORPORATION

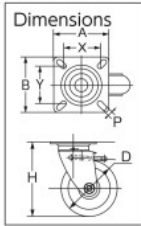

**Flexible with double stopper** Specs •Flexible Type (with double stopper)  
•Simultaneously lock the turning part and the wheel

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
289-0020	TJB-100C	¥1,889	¥2,040	80 82	100	35	144	95 x 95	67 to 74 x 67 to 74	10.5	18	1.25
289-0038	TJB-130C	¥2,722	¥2,940	140 143	130	42	177	110 x 110	75 to 90 x 75 to 90	11.0	10	2.15
289-0046	TJB-150C	¥2,934	¥3,170	161 164	150	45	198	120 x 120	75 to 90 x 75 to 90	11.0	8	2.40
299-6103	TJB-200C	¥4,416	¥4,770	200 204	200	46	250	140 x 140	100 to 115 x 100 to 115	11.5	4	4.00

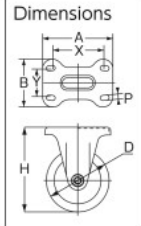

**Fixed** Specs •Fixed Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
288-9986	TK-100C	¥ 982	¥1,060	80 82	100	35	144	115 x 80	80 to 90 x 45 to 50	10.5	18	0.85
288-9994	TK-130C	¥1,731	¥1,870	140 143	130	42	177	138 x 92	100 to 112 x 53 to 56	11.0	10	1.60
289-0011	TK-150C	¥1,916	¥2,070	161 164	150	45	198	138 x 92	100 to 112 x 53 to 56	11.0	8	1.85
299-6090	TK-200C	¥3,120	¥3,370	200 204	200	46	250	155 x 102	112 to 119 x 56 to 63	11.5	4	3.00


Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

## Plate Type Caster (nylon wheel rubber tire)



- Features**
- Approx. 10% lighter than conventional press made wheel rubber tire.
- Specs**
- Plate Type
  - With Commercial Bearing
- Materials**
- Metal Fitting: Steel
  - Metal Fitting Surface Treatment: Trivalent Unichrome Plated
  - Wheel: Nylon Wheel, Rubber
- Origin**
- Japan

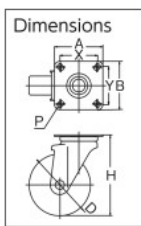


**Flexible** Specs •Flexible Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
278-2481	TYNRJ-100	¥1,379	¥1,490	100 102.0	100	32	144	95 x 95	67 to 74 x 67 to 74	11	16	1.00
278-2499	TYNRJ-130	¥2,129	¥2,300	160 163.2	130	40	177	105 x 105	75 to 82 x 75 to 82	11	8	1.51
278-2502	TYNRJ-150	¥2,314	¥2,500	180 183.6	150	40	198	120 x 120	87 to 94 x 87 to 94	11	8	1.72


TRUSCO NAKAYAMA CORPORATION

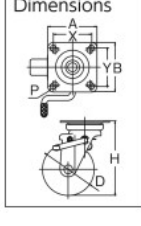

**Flexible with double stopper (right side)** Specs •Flexible Type (with double stopper)  
•Simultaneously lock the turning part and the wheel

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
450-9943	TYNRJB-100A	¥1,869	¥2,020	100 102.0	100	32	144	95 x 95	67 to 74 x 67 to 74	11	16	1.14
450-9951	TYNRJB-130A	¥2,610	¥2,820	160 163.2	130	40	177	105 x 105	75 to 82 x 75 to 82	11	8	1.79
450-9960	TYNRJB-150A	¥2,777	¥3,000	180 183.6	150	40	198	120 x 120	87 to 94 x 87 to 94	11	8	2.00

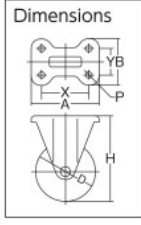

**Fixed** Specs •Fixed Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
278-2545	TYNRK-100	¥1,102	¥1,190	100 102.0	100	32	144	115 x 80	80 x 45	11	16	0.75
278-2553	TYNRK-130	¥1,695	¥1,830	160 163.2	130	40	177	137 x 93	100 x 56	11	8	1.11
278-2561	TYNRK-150	¥1,851	¥2,000	180 183.6	150	40	198	137 x 93	100 x 56	11	8	1.26

Contact us:0120-509-849 <http://www.orange-book.com/>