

# Plate Type Stainless Steel Casters (urethane wheel)

Stock 338 Items

2-729

Prices displayed include 8% tax.


TRUSCO **Stock 38,650 Items**

## Plate Type Caster (nylon wheel urethane tire/stainless steel fittings)



- Features**
- Excellent in corrosion resistance and water resistance because the fittings are made of stainless steel (SUS304) and the wheel employs lightweight nylon wheel urethane tire.
- Specs**
- Plate Type •With stainless steel radial bearing
- Materials**
- Metal Fitting: Stainless Steel (SUS304)
  - Wheel: Nylon Wheel, Urethane
- Origin**
- Japan

TYSGUJ-130

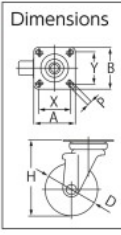

**Flexible** Specs •Flexible Type

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
278-2251	TYSGUJ-100	¥ 5,026	¥ 5,430	100 102.0	100	32	132	90 x 90	68 to 71 x 68 to 71	11.0	16	0.86
278-2260	TYSGUJ-130	¥ 7,701	¥ 8,320	160 163.2	130	40	170	102 x 102	75 to 80 x 75 to 80	11.0	8	1.45
278-2278	TYSGUJ-150	¥ 8,406	¥ 9,080	180 183.6	150	40	190	102 x 102	75 to 80 x 75 to 80	11.0	8	1.56
278-2286	TYSGUJ-200	¥ 11,553	¥ 12,480	250 255.0	200	43	250	140 x 140	105 to 115 x 105 to 115	11.5	4	3.23

TYSGUJ-130S




**Flexible with stopper** Specs •Flexible Type (with stopper)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
278-2294	TYSGUJ-100S	¥ 5,962	¥ 6,440	100 102.0	100	32	132	90 x 90	68 to 71 x 68 to 71	11.0	16	0.93
278-2308	TYSGUJ-130S	¥ 8,878	¥ 9,590	160 163.2	130	40	170	102 x 102	75 to 80 x 75 to 80	11.0	8	1.64
278-2316	TYSGUJ-150S	¥ 9,645	¥ 10,420	180 183.6	150	40	190	102 x 102	75 to 80 x 75 to 80	11.0	8	1.78
278-2324	TYSGUJ-200S	¥ 14,515	¥ 15,680	250 255.0	200	43	250	140 x 140	105 to 115 x 105 to 115	11.5	4	3.58

TYSGUK-130

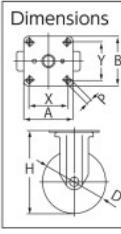

**Fixed** Specs •Fixed Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
278-2367	TYSGUK-100	¥ 3,740	¥ 4,040	100 102.0	100	32	132	110 x 75	80 to 90 x 45 to 50	11.0	16	0.71
278-2375	TYSGUK-130	¥ 5,832	¥ 6,300	160 163.2	130	40	170	102 x 102	75 to 80 x 75 to 80	11.0	8	1.26
278-2383	TYSGUK-150	¥ 6,545	¥ 7,070	180 183.6	150	40	190	102 x 102	75 to 80 x 75 to 80	11.0	8	1.36
278-2391	TYSGUK-200	¥ 8,025	¥ 8,670	250 255.0	200	43	250	151 x 102	112 x 63	11.5	4	2.50

Contact us: 0120-509-849 <http://www.orange-book.com/>


TRUSCO **Stock 38,650 Items**

## Plate Type Noise Reduction Caster (nylon wheel urethane tire/stainless steel fittings)



- Features**
- Made of stainless steel (SUS304), so excellent in corrosion resistance and water resistance.
  - The pivot part is sealed with rubber packings forming dust-proof and water-proof structure.
  - There is no unpleasant sound such as traveling sound that is specific to casters. (noise-free type)
  - Resistance during push start is reduced, turning/rotating is very easy.
  - The wheel is an original star shape pattern.
- Specs**
- Plate Type
  - Rotating Part, Rotating Part: Using Radial Ball Bearing
  - With drip-proof and dust-proof cover
- Materials**
- Metal Fitting: Stainless Steel (SUS304)
  - Bearing: Steel
  - Wheel: Nylon wheel, urethane (with stainless steel wheel cover)
- Origin**
- Japan

TXSUJ Type

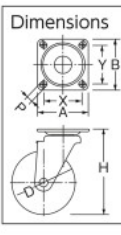


**Flexible** Specs •Flexible Type

Order Unit: 1 Piece

(Price revision date: Jan, 2015) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
256-0640	TXSUJ-100	¥ 4,990	¥ 5,390	100 102	100	33	132	95 x 95	67 to 74 x 67 to 74	11	18	1.10
256-0658	TXSUJ-125	¥ 6,221	¥ 6,720	130 133	125	40	168	110 x 110	75 to 90 x 75 to 90	11	10	1.68
256-0666	TXSUJ-150	¥ 6,684	¥ 7,220	140 143	150	40	190	110 x 110	75 to 90 x 75 to 90	11	8	1.86

TXSUJB Type

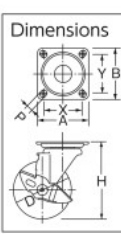


**Flexible with stopper** Specs •Flexible Type (with stopper)

Order Unit: 1 Piece

(Price revision date: Jan, 2015)

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
256-0763	TXSUJB-100	¥ 5,647	¥ 6,100	100 102	100	33	132	95 x 95	67 to 74 x 67 to 74	11	18	1.18
256-0771	TXSUJB-125	¥ 7,239	¥ 7,820	130 133	125	40	168	110 x 110	75 to 90 x 75 to 90	11	10	1.81
256-0780	TXSUJB-150	¥ 7,683	¥ 8,300	140 143	150	40	190	110 x 110	75 to 90 x 75 to 90	11	8	2.20

TXSUK Type

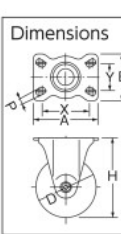

**Fixed** Specs •Fixed Type

Order Unit: 1 Piece

(Price revision date: Jan, 2015)

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
256-0704	TXSUK-100	¥ 3,684	¥ 3,980	100 102	100	33	132	115 x 80	80 to 90 x 45 to 50	11	18	0.85
256-0712	TXSUK-125	¥ 4,684	¥ 5,060	130 133	125	40	168	138 x 92	100 to 112 x 53 to 56	11	10	1.29
256-0721	TXSUK-150	¥ 5,369	¥ 5,800	140 143	150	40	190	138 x 92	100 to 112 x 53 to 56	11	8	1.46

Contact us: 0120-509-849 <http://www.orange-book.com/>