

Plate Type Stainless Steel Casters (nylon wheel)

Stock 338 Items

2-735

Prices displayed include 8% tax.

TRUSCO
Stock 38,650 Items


Plate Type Caster (nylon wheel/stainless steel metal fittings)



- Features** • Excellent in corrosion resistance and water resistance because the fittings are made of stainless steel (SUS304) and the wheel uses nylon wheel.
- Specs** • Plate Type
- Materials** • Metal Fitting: Stainless Steel (SUS304)
• Wheel: Nylon
- Origin** • Japan



TYSNJ-150

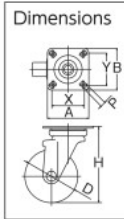

Flexible Specs • Flexible Type


Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
278-1778	TYSNJ-100	¥ 4,443	¥ 4,800	100 102.0	100	32	132	90 x 90	68 to 71 x 68 to 71	11.0	16	0.82
278-1786	TYSNJ-130	¥ 7,239	¥ 7,820	160 163.2	130	40	170	102 x 102	75 to 80 x 75 to 80	11.0	8	1.32
278-1794	TYSNJ-150	¥ 7,934	¥ 8,570	160 163.2	150	40	190	102 x 102	75 to 80 x 75 to 80	11.0	8	1.42
278-1808	TYSNJ-200	¥ 11,377	¥ 12,290	220 224.4	200	43	250	140 x 140	105 to 115 x 105 to 115	11.5	4	3.06

TRUSCO NAKAYAMA CORPORATION



TYSNJ-150S

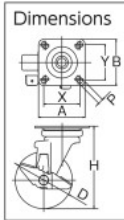


Flexible with stopper Specs • Flexible Type (with stopper)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
278-1841	TYSNJ-100S	¥ 5,378	¥ 5,810	100 102.0	100	32	132	90 x 90	68 to 71 x 68 to 71	11.0	16	0.91
278-1859	TYSNJ-130S	¥ 8,406	¥ 9,080	160 163.2	130	40	170	102 x 102	75 to 80 x 75 to 80	11.0	8	1.52
278-1867	TYSNJ-150S	¥ 9,109	¥ 9,840	160 163.2	150	40	190	102 x 102	75 to 80 x 75 to 80	11.0	8	1.62
278-1875	TYSNJ-200S	¥ 14,321	¥ 15,470	220 224.4	200	43	250	140 x 140	105 to 115 x 105 to 115	11.5	4	3.41



TYSNK-150

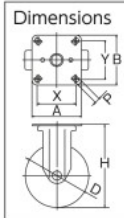

Fixed Specs • Fixed Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
278-1948	TYSNK-100	¥ 3,157	¥ 3,410	100 102.0	100	32	132	110 x 75	80 to 90 x 45 to 50	11.0	16	0.62
278-1956	TYSNK-130	¥ 5,378	¥ 5,810	160 163.2	130	40	170	102 x 102	75 to 80 x 75 to 80	11.0	8	1.12
278-1964	TYSNK-150	¥ 6,073	¥ 6,560	160 163.2	150	40	190	102 x 102	75 to 80 x 75 to 80	11.0	8	1.23
278-1972	TYSNK-200	¥ 7,878	¥ 8,510	220 224.4	200	43	250	151 x 102	112 x 63	11.5	4	2.32

Contact us: 0120-509-849 <http://www.orange-book.com/>


SAMSUNG
Stock 167 Items

Plate Type Caster (nylon wheel/stainless steel metal fittings)

- Features** • Stainless Steel Metal Fitting (SUS304) are used, excellent in corrosion resistance and water resistance of nylon wheel.
• Since the turning part is dust proof and has waterproof seal, it can be used for a long time even in harsh environment.
- Specs** • Plate Type
- Materials** • Metal Fitting: Stainless Steel (SUS304)
• Metal Fitting Surface Treatment: Electrolytic Polishing
• Wheel: Nylon
- Origin** • Korea




TP5130-NYL-SUS

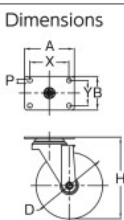

Flexible Specs • Flexible Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (g)
763-0158	TP5130-NYL-SUS	¥ 2,236	¥ 2,760	108 110	76	32	104	95 x 64	76 x 45	8	8	630
763-0182	TP5140-NYL-SUS	¥ 2,419	¥ 2,990	132 135	102	32	129	95 x 64	76 x 45	8	6	690
763-0212	TP5150-NYL-SUS	¥ 3,092	¥ 3,820	132 135	127	32	156	95 x 64	76 x 45	8	4	870

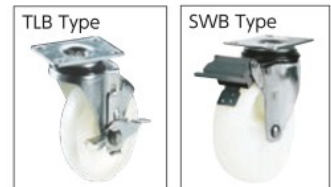


Flexible, stopper type

SAMSUNG CASTER CO. LTD.




TP5130-NYL-SUS-TLB

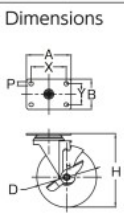

Flexible with stopper Specs • Flexible Type (with stopper)

Order Unit: 1 Piece


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (g)
763-0166	TP5130-NYL-SUS-TLB	¥ 2,549	¥ 3,150	108 110	76	32	104	95 x 64	76 x 45	8	8	680
763-0191	TP5140-NYL-SUS-TLB	¥ 2,811	¥ 3,470	132 135	102	32	129	95 x 64	76 x 45	8	6	760
763-0221	TP5150-NYL-SUS-SWB	¥ 4,069	¥ 5,020	132 135	127	32	156	95 x 64	76 x 45	8	4	1050

 

Warning
• In the TP5150, stopper method switches to the SWB method.



TP5130R-NYL-SUS

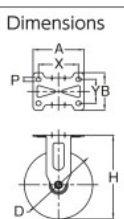

Fixed Specs • Fixed Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (g)
763-0174	TP5130R-NYL-SUS	¥ 1,258	¥ 1,550	108 110	76	32	104	95 x 64	76 x 45	8	8	350
763-0204	TP5140R-NYL-SUS	¥ 1,456	¥ 1,800	132 135	102	32	129	95 x 64	76 x 45	8	6	400
763-0239	TP5150R-NYL-SUS	¥ 2,109	¥ 2,600	132 135	127	32	156	95 x 64	76 x 45	8	4	600

Delivery estimate ★...Manufacturer stock ★...Delivery within 7 working days ★...ASK

Casters

Plate Type Rubber Casters

Plate Type Urethane Casters

Plate Type Nylon Casters

Plate Type Resin Casters

Screwed Rubber Casters

Screwed Urethane Casters

Screwed Nylon Casters

Screwed Resin Casters

Nuts, Spanners

Stem Casters

Stainless Steel Casters

Angle Casters

Corner Casters

Dual Wheel Casters

Sound Reducing Casters

ESD-Safe Casters

Shock Absorbing Casters

Casters for Specific Environment

Pneumatic/No-Puncture Caster

Low Level Casters

Heavy-Duty Casters

Casting Casters

Stoppers

2-735