

Prices displayed include 8% tax.

TRUSCO
 Stock 38,650 Items


Powerful Barrel Bolt

.Com Drawing



TMO-300K

- Features**
- Trivalent chromate treatment with consideration for environmental problems is finished.
 - Considering the safety of the size of 150mm or more, the corner of the main body is rounded.
- Use**
- Steel Made Breaking Edge/Access Ceiling Manhole
- Materials**
- **Board: Cold Rolled Steel Plate (SPCC)**
 - **Round Bar: Soft Steel (SS41)**
- Accessories**
- Wood Screws
- Origin**
- Japan

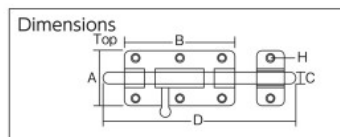

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	A (mm)	B (mm)	C (mm)	D (mm)	H (mm)	SPQ (piece)	Weight (g)
352-4876	TMO-80K	¥ 463	¥ 500	37	55	9	77	4.5	2	75
352-4795	TMO-100K	¥ 537	¥ 580	37	55	9	99	4.5	2	95
352-4825	TMO-150K	¥ 787	¥ 850	47	80	12	147	5.0	2	250
352-4833	TMO-300K	¥1,018	¥1,100	47	80	12	300	5.0	2	380
352-4817	TMO-450K	¥1,157	¥1,250	47	80	12	450	5.0	2	500

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO
 Stock 38,650 Items


Powerful Barrel Bolt

.Com Drawing



TMO-300S

- Features**
- Made of stainless steel and excellent in corrosion resistance and heat resistance.
- Use**
- Steel Made Breaking Edge/Access Ceiling Manhole
- Materials**
- **Stainless Steel (SUS304)**
- Accessories**
- Wood screw stainless steel M3.5 x 25 8 pieces
- Origin**
- Japan

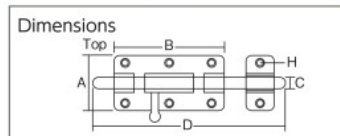

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	A (mm)	B (mm)	C (mm)	D (mm)	H (mm)	SPQ (piece)	Weight (g)
300-1768	TMO-100S	¥1,500	¥1,620	47	80	12	100	4.5	2	235
300-1776	TMO-150S	¥1,944	¥2,100	47	80	12	150	4.5	2	280
300-1784	TMO-300S	¥2,499	¥2,700	47	80	12	300	4.5	2	400
300-1792	TMO-450S	¥3,165	¥3,420	47	80	12	450	4.5	2	550

Contact us:0120-509-849 <http://www.orange-book.com/>

SUGATSUNE
 Stock 766 Items

"SPRING LOADED BARREL BOLT BSS Type"




.Com CAD



BSS type

- Features**
- Since a stop bar is long and adjustable in some levels, it can securely lock.
 - It has a built-in spring type that a stop bar does not rattle or is not removed even against vibration, impact, etc.
- Use**
- For gate doors, doors, back doors.
- Materials**
- **Stainless Steel (SUS304)**
 - **Surface treatment: Hair line finishing**
- Accessories**
- Cross recess countersunk wood screw M3.5 x 20 (stainless steel)
- Origin**
- Japan

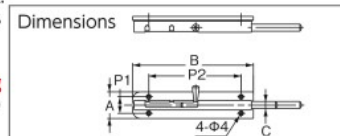

SUGATSUNE KOGYO Co.Ltd.

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	A (mm)	B (mm)	C (mm)	P1 (mm)	P2 (mm)	SPQ (piece)	Weight (g)
376-9682	BSS2-90	¥3,024	¥2,800	33	90	9	20.5	60	15	140
376-9674	BSS2-150	¥3,996	¥3,700	33	150	9	20.5	115	10	212
376-9691	BSS3-240	¥5,076	¥4,700	33	240	9	20.5	205	6	320

Contact us:03-3851-1122 <http://www.sugatsune.co.jp/>

TRUSCO
 Stock 38,650 Items

W Slide Bolt Latch

▶ For padlocks, see p. 2-876 to 884

.Com Drawing



TKNW-152S

- Features**
- Made of stainless steel and excellent in corrosion resistance and heat resistance.
 - A dual-purpose type for both left and right.
 - The hole diameter of the catch has been made larger, and it corresponds to the gap after installation.
 - The handle part is subjected to anti-slip processing.
- Use**
- Steel gate door/steel joinery.
- Materials**
- **Stainless Steel (SUS304)**
- Origin**
- Japan

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece



Order Code	Item No.	Price (per piece)	MSRP (per piece)	A (mm)	B (mm)	C (mm)	D (mm)	SPQ (piece)	Weight (g)
300-1661	TKNW-107S	¥2,926	¥3,160	50	70	12.5	107	4	310
300-1679	TKNW-152S	¥7,776	¥8,400	65	100	15.5	152	4	930

Receiving bracket

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	E (mm)	F (mm)	G (mm)	H (mm)	SPQ (piece)	Weight (g)
300-1687	TKNW-107SU	¥ 750	¥ 810	50	31	32	7	20	85
300-1695	TKNW-152SU	¥1,666	¥1,800	65	45	45	9	10	122

Contact us:0120-509-849 <http://www.orange-book.com/>

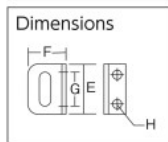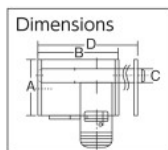

TKNW-152SU (receiving bracket)