

The number next to the logo mark indicates items in stock for each brand.

Door Closers

Door Stoppers

Hinges

Slide Bolt Latches

Catches

Handles

Keys

Chains

Wire Ropes

Metal Fittings for Handling

Suspension Metal Fittings

Shelf Peg Metal Fittings

Joint Fittings

Steel Wires

Wire Nets

Inspection Doors, Air Inlet/Outlets

Handrails, Slopes

Corrugated Plates

Plastic Materials

Metal Materials

Construction Materials

Sash Rollers

Door Hangers



Stock 38,650 Items

## Stainless Steel Cut Chain (with chain eye)




- Features
- A set of chain eyes are set every 2 connections on the stainless steel chain.
  - Since it reflects and shines to the car's headlight in evening or at night, it is useful for securing safety.



- Materials
- Chain: Stainless steel (SUS304)
  - Chain eye: Polyethylene (PE)
- Origin
- Japan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

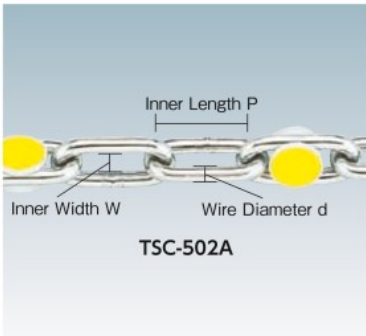

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (m)	Wire Diameter d (mm)	Inner Length P (mm)	Inner Width W (mm)	Working Load (kN)	SPQ (piece)	Weight (kg)
352-4078	TSC-401A	¥2,638	¥2,850	1	4.0	26	6.5	1.67	5	0.275
352-4051	TSC-402A	¥4,073	¥4,400	2	4.0	26	6.5	1.67	5	0.551
352-4043	TSC-403A	¥5,647	¥6,100	3	4.0	26	6.5	1.67	5	0.826
352-4035	TSC-405A	¥9,257	¥10,000	5	4.0	26	6.5	1.67	5	1.377
352-3993	TSC-501A	¥2,916	¥3,150	1	5.0	27	8.0	2.45	5	0.438
352-5180	TSC-502A	¥4,351	¥4,700	2	5.0	27	8.0	2.45	5	0.876
352-5139	TSC-503A	¥6,295	¥6,800	3	5.0	27	8.0	2.45	5	1.314
352-5147	TSC-505A	¥9,442	¥10,200	5	5.0	27	8.0	2.45	5	2.190

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock 529 Items

## "Chain Eye"




- Features
- When attached to a chain that is difficult to see in the evening or at night, it reflects on the car's headlight and shines.
- Specs
- Compatible chain size: Wire diameter 4 to 6mm
- Materials
- Polyethylene (PE)
- Origin
- Japan



Order Unit: 1 Bag

MIZUMOTO MACHINE MFG.Co.Ltd

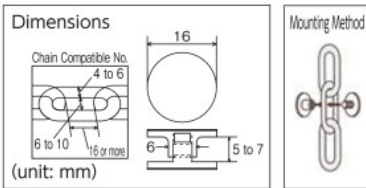

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Color	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
282-6712	C-1654	¥518	¥610	Green	6	5	11
282-6721	C-1655	¥518	¥610	Red	6	5	11
282-6739	C-1656	¥518	¥610	Yellow	6	5	11
282-6747	C-1907	¥518	¥610	White	6	5	11

Contact us: 079-246-2501 <http://www.mizumoto-mm.co.jp/>





Stock 529 Items

## Stainless Steel Chain



- Features
- Since it is excellent in corrosion resistance and acid-resistance, it is used in a very wide range.
- Materials
- Stainless Steel (SUS304)
- Origin
- Japan

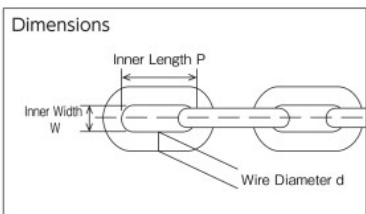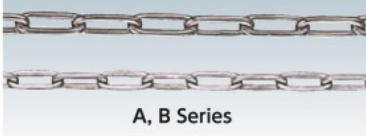

Order Unit: 1 Piece

MIZUMOTO MACHINE MFG.Co.Ltd

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (m)	Wire Diameter d (mm)	Inner Length P (mm)	Inner Width W (mm)	Working Load (kN)	SPQ (piece)	Weight (kg)
780-5551	1.2-A	¥15,274	¥18,000	30	1.2	7.7	3.0	0.10	1	0.78
780-5560	1.4-A	¥17,820	¥21,000	30	1.4	7.3	3.2	0.15	1	1.14
780-5578	1.6-A	¥16,547	¥19,500	30	1.6	16.8	5.0	0.20	1	1.20
211-4879	2-A	¥25,457	¥30,000	30	2.0	12.0	3.5	0.29	1	2.25
211-4887	2.5-A	¥29,276	¥34,500	30	2.5	14.0	4.5	0.59	1	3.45
211-4895	3-B	¥30,549	¥36,000	30	3.0	24.0	5.0	0.98	1	4.38
211-4909	4-B	¥38,186	¥45,000	30	4.0	26.0	6.5	1.67	1	7.98
211-4917	5-B	¥48,369	¥57,000	30	5.0	27.0	8.0	2.45	1	12.87
211-4925	5.5-B	¥53,460	¥63,000	30	5.5	30.0	8.0	2.94	1	15.90
211-4933	6-B	¥68,734	¥81,000	30	6.0	31.0	9.0	3.43	1	18.99
780-5632	7-B	¥96,737	¥114,000	30	7.0	37.0	10.0	4.41	1	24.60

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands |

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (m)	Wire Diameter d (mm)	Inner Length P (mm)	Inner Width W (mm)	Working Load (kN)	SPQ (piece)	Weight (kg)
★780-5641	8-B	¥127,286	¥150,000	30	8	38	12	5.88	1	34.5
★780-5659	9-B	¥178,200	¥210,000	30	9	39	13	7.84	1	45.6
★780-5586	10-A	¥216,386	¥255,000	30	10	40	15	8.82	1	60.0
★780-5594	11-A	¥254,571	¥300,000	30	11	44	17	9.80	1	72.0
★780-5608	12-A	¥320,760	¥378,000	30	12	48	18	12.74	1	90.0
★780-5616	13-A	¥381,857	¥450,000	30	13	52	20	14.70	1	102.0
★780-5624	16-A	¥636,429	¥750,000	30	16	64	24	19.60	1	153.0

Contact us: 079-246-2501 <http://www.mizumoto-mm.co.jp/>