

Prices displayed include 8% tax.

TRUSCO Stock 38,650 Items

Stainless Steel Wire Rope



CWS-6S30

- Features**
- The stainless steel rope is excellent in corrosion resistance, rust resistance, heat resistance, and abrasion resistance.
 - Especially when used in sea water, it has about 10 times longer life than general wire rope.

- Materials**
- Stainless Steel (SUS304)
- Origin**
- China




Example

Order Unit: 1 Roll

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per roll)	MSRP (per roll)	Rope Diameter (mm)	Length (m)	Working Load (kg)	SPQ (roll)	Weight (kg)
489-1325	CWS-1S30	¥ 1,851	¥ 2,000	1.0	30	15	10	0.12
489-1333	CWS-1S50	¥ 3,055	¥ 3,300	1.0	50	15	10	0.20
489-1309	CWS-1S100	¥ 5,277	¥ 5,700	1.0	100	15	10	0.40
489-1317	CWS-1S200	¥ 10,183	¥ 11,000	1.0	200	15	5	0.80
489-1287	CWS-1S530	¥ 2,129	¥ 2,300	1.5	30	30	10	0.26
489-1295	CWS-1S550	¥ 3,147	¥ 3,400	1.5	50	30	10	0.45
489-1261	CWS-1S5100	¥ 6,017	¥ 6,500	1.5	100	30	5	0.87
489-1279	CWS-1S5200	¥ 11,109	¥ 12,000	1.5	200	30	5	1.74
489-1368	CWS-2S30	¥ 2,499	¥ 2,700	2.0	30	50	5	0.51
489-1376	CWS-2S50	¥ 4,027	¥ 4,350	2.0	50	50	5	0.85
489-1341	CWS-2S100	¥ 8,054	¥ 8,700	2.0	100	50	5	1.70
489-1350	CWS-2S200	¥ 15,737	¥ 17,000	2.0	200	50	2	3.40
213-4802	CWS-3S10	¥ 1,342	¥ 1,450	3.0	10	100	10	0.37
213-4811	CWS-3S20	¥ 2,407	¥ 2,600	3.0	20	100	10	0.73
213-4829	CWS-3S30	¥ 3,703	¥ 4,000	3.0	30	100	6	1.10
489-1406	CWS-3S50	¥ 6,110	¥ 6,600	3.0	50	100	5	1.90
489-1384	CWS-3S100	¥ 12,219	¥ 13,200	3.0	100	100	2	3.80
489-1392	CWS-3S200	¥ 22,217	¥ 24,000	3.0	200	100	1	7.60
213-4837	CWS-4S10	¥ 2,416	¥ 2,610	4.0	10	180	10	0.65
213-4845	CWS-4S20	¥ 4,564	¥ 4,930	4.0	20	180	6	1.30
213-4853	CWS-4S30	¥ 6,711	¥ 7,250	4.0	30	180	4	1.95
489-1431	CWS-4S50	¥ 11,275	¥ 12,180	4.0	50	180	2	3.20
489-1414	CWS-4S100	¥ 22,550	¥ 24,360	4.0	100	180	1	6.50
489-1422	CWS-4S200	¥ 41,657	¥ 45,000	4.0	200	180	1	13.00
489-1449	CWS-5S10	¥ 3,240	¥ 3,500	5.0	10	260	10	1.00
489-1465	CWS-5S20	¥ 6,850	¥ 7,400	5.0	20	260	5	2.00
489-1481	CWS-5S30	¥ 9,257	¥ 10,000	5.0	30	260	3	3.00
489-1490	CWS-5S50	¥ 15,737	¥ 17,000	5.0	50	260	2	5.00
489-1457	CWS-5S100	¥ 30,919	¥ 33,400	5.0	100	260	1	10.00
489-1473	CWS-5S200	¥ 53,460	¥ 57,500	5.0	200	260	1	20.00
213-4861	CWS-6S10	¥ 4,147	¥ 4,480	6.0	10	400	8	1.47
213-4870	CWS-6S20	¥ 7,739	¥ 8,360	6.0	20	400	4	2.94
213-4888	CWS-6S30	¥ 11,405	¥ 12,320	6.0	30	400	2	4.41
489-1520	CWS-6S50	¥ 18,514	¥ 20,000	6.0	50	400	1	7.50
489-1503	CWS-6S100	¥ 37,029	¥ 40,000	6.0	100	400	1	15.00
489-1511	CWS-6S200	¥ 67,947	¥ 73,400	6.0	200	400	1	30.00
818-8163	CWS-8S10	¥ 7,221	¥ 7,800	8.0	10	700	10	2.68
818-8164	CWS-8S20	¥ 13,886	¥ 15,000	8.0	20	700	5	5.36
818-8165	CWS-8S30	¥ 20,366	¥ 22,000	8.0	30	700	3	8.04
818-8166	CWS-8S50	¥ 34,251	¥ 37,000	8.0	50	700	2	13.40
818-8167	CWS-8S100	¥ 66,651	¥ 72,000	8.0	100	700	1	26.80

Contact us: 0120-509-849 <http://www.orange-book.com/>

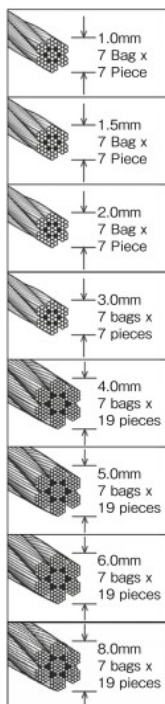

CWS-6S30

TRUSCO Stock 38,650 Items

Stainless Steel Wire Rope (with special sleeves)



CWS-2S20

- Features**
- The stainless steel rope is excellent in corrosion resistance, rust resistance, heat resistance, and abrasion resistance.
 - Especially when used in sea water, it has about 10 times longer life than general wire rope.

- Materials**
- Stainless Steel (SUS304)

- Accessories**
- Dedicated sleeve (CWS-1S: with AS1 x 4 pieces, CWS-1S5: with AS1.5 x 4 pieces, CWS-2S: with AS2 x 4 pieces)

- Origin**
- China




Please stop the wire with the included conforming sleeve.

Order Unit: 1 Roll

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per roll)	MSRP (per roll)	Rope Diameter (mm)	Length (m)	Working Load (kg)	SPQ (roll)	Weight (kg)
213-4501	CWS-1S5	¥ 593	¥ 640	1.0	5	15	20	0.020
213-4519	CWS-1S10	¥ 787	¥ 850	1.0	10	15	20	0.040
213-4527	CWS-1S20	¥ 1,231	¥ 1,330	1.0	20	15	10	0.060
213-4535	CWS-1S55	¥ 630	¥ 680	1.5	5	30	30	0.048
213-4543	CWS-1S510	¥ 814	¥ 880	1.5	10	30	20	0.095
213-4551	CWS-1S520	¥ 1,342	¥ 1,450	1.5	20	30	10	0.190
213-4560	CWS-2S5	¥ 759	¥ 820	2.0	5	50	20	0.085
213-4578	CWS-2S10	¥ 1,037	¥ 1,120	2.0	10	50	10	0.170
213-4586	CWS-2S20	¥ 1,620	¥ 1,750	2.0	20	50	6	0.340

Contact us: 0120-509-849 <http://www.orange-book.com/>

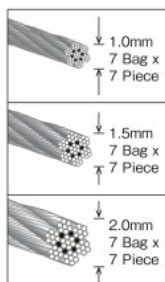

CWS-2S20 (with 4 sleeves)