

Prices displayed include 8% tax.

JOPLAX **Stock 86 Items**

Coil Hose



T-805J

- Features**
- Coil hose with high durability and reliability that is less likely stretched.
 - Because resin coupling is installed as standard features, detachment can be done smoothly with the air tool.
- Specs**
- Adaption fluid: air
 - Fluid Temperature: 0 to 60° C
 - **Working Pressure: 0.7MPa**
 - Hose Inner Diameter x Outer Diameter: 5 x 8mm
- Materials**
- Polyurethane
- Origin**
- Japan

Order Unit: 1 Piece


JOPLAX Co.Ltd

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Coil Diameter (mm)	Color	Operating Range (m)	Total Length (mm)	Coil Length (mm)	SPQ (piece)	Weight (g)
826-6590	T-805J	¥4,725	¥5,000	42	Yellow	4	1000	180	1	220
826-6591	T-808J	¥5,832	¥6,170	42	Yellow	6	1230	630	1	320

Contact us:072-893-6301 <http://www.joplax.co.jp/>

MEIJI **Stock 5 Items**

May Coil Set

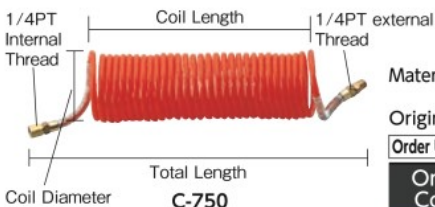

C-750

- Features**
- Extendable by 30 times with 1/2 lightness of rubber hose.
- Specs**
- Working Fluid: Air
 - Fluid Temperature: -5 to 60° C
 - **Working Pressure: 0.8MPa**
 - Connecting Joint: 1/4 PT external Thread and 1/4 PT external Thread
 - Nylon Tube Applied Coil Form Processing
 - Metal Fitting Male/Female Fixed, with 1/4PT (BC)
- Materials**
- Main Body: Nylon Tube, Nylon 12
 - Metal Fitting (1/4 PT male/female): Brass (BC)
- Origin**
- Japan

Order Unit: 1 Piece

MEIJI NYLON HOSE.LTD

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Coil Diameter (mm)	Color	Operating Range (m)	Total Length (mm)	Coil Length (mm)	SPQ (piece)	Weight (g)
106-5751	C-375	¥3,348	-	90.2	Orange	3	265	125	2	158
106-5769	C-500	¥3,956	-	90.2	Orange	4	305	165	2	182
106-5777	C-750	¥5,184	-	90.2	Orange	6	390	250	1	224
106-5785	C-1000	¥6,440	-	90.2	Orange	8	470	330	1	266
106-5793	C-1500	¥8,546	-	90.2	Orange	12	640	500	1	350

KURITA **Stock 47 Items**

Coil Hose




CH500

- Features**
- Hose excellent in elasticity and flexibility, and lightweight.
- Specs**
- Working Fluid: Air
 - Fluid Temperature: -5 to 60° C
 - **Working Pressure: 0.7MPa**
 - Hose Inner Diameter x Outer Diameter: 5 x 8mm
 - Connection Partner: With G1/4 internal threads both ends
- Materials**
- Main Body: Polyurethane (PU)
 - Coupling: Brass Rod (C3604) Chrome Plating
- Origin**
- Japan

Order Unit: 1 Piece

KURITA SEISAKUSHO

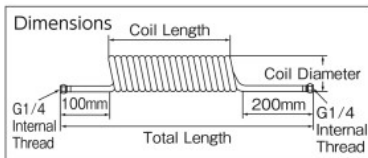

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Coil Diameter (mm)	Color	Operating Range (m)	Total Length (mm)	Coil Length (mm)	SPQ (piece)	Weight (g)
433-9606	CH300	¥2,939	¥2,930	38	Orange	2.4	540	240	5	127
556-8218	CH500	¥3,474	¥3,465	38	Orange	4.0	710	410	5	182
556-8234	CH700	¥4,112	¥4,100	38	Orange	5.6	880	580	5	250
556-8188	CH1000	¥7,305	¥7,285	45	Orange	9.0	1020	720	5	380

Contact us:03-5638-8261 <http://www.cup-kurita.co.jp/>

KURITA **Stock 47 Items**

"Tsuru Ring" for Hanging Hoses



SG300

- Features**
- By using this spring in the inner diameter part of the coil hose, the coil hose can smoothly expand and shrink.
- Specs**
- Hanging Load: 200g
- Materials**
- Hard Steel Wire (SW-B)
 - Surface Treatment: Trivalent Chromate
- Origin**
- Japan

Order Unit: 1 Piece

KURITA SEISAKUSHO

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Outer Diameter x Total Length (mm)	Wire Diameter (mm)	Applicable Case	SPQ (piece)	Weight (g)
556-9672	SG300	¥577	¥575	18 x 300	1	CH300	10	95
556-9681	SG500	¥723	¥720	18 x 500	1	CH500	10	165
556-9699	SG700	¥928	¥925	18 x 700	1	CH700	10	230

Contact us:03-5638-8261 <http://www.cup-kurita.co.jp/>

Fluid Couplings·Tubes

Tube Fittings

Couplings

Pipe Joints

Ball Valves

Needle Valves

Air Tubes, Hoses

Tools for Tube

Tube Cutters

Air Reels

Artificial shock, bending, tension may cause damage.