

Prices displayed include 8% tax.


TRUSCO Stock 38,650 Items

Urethane Blade Tube (with coupling for lock type tube)



Com.eco Chemical Content Inspection Com Drawing

- Features**
- Excellent in oil resistance and pressure resistance and flexibility at low temperature (-5° C).
 - Compatible with general coupling.
- Specs**
- Working Fluid: Air
 - Fluid Temperature: -5 to 60° C (to be freeze free)
 - **Working Pressure: 1.5MPa**
 - Allowable Bending Radius: 50mm
 - Coupling Connection Joint: TL200-65SN/65PN
- Materials**
- Polyurethane
- Origin**
- Japan

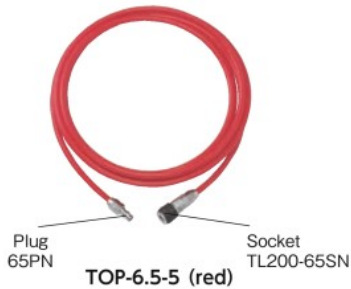

Color: Red

Order Unit: 1 Roll

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per roll)	MSRP (per roll)	Color	Outer Diameter x Inner Diameter (mm)	Total Length (m)	Thickness (mm)	SPQ (roll)	Weight (kg)
104-3099	TOP-6.5-5	¥2,499	¥2,700	Red	10 x 6.5	5	1.75	20	0.43
104-3102	TOP-6.5-10	¥3,398	¥3,670	Red	10 x 6.5	10	1.75	20	0.70
104-3111	TOP-6.5-20	¥5,277	¥5,700	Red	10 x 6.5	20	1.75	10	1.25
104-3129	TOP-6.5-30	¥7,387	¥7,980	Red	10 x 6.5	30	1.75	10	1.80

Color: Neo Gray

Order Unit: 1 Roll

Order Code	Item No.	Price (per roll)	MSRP (per roll)	Color	Outer Diameter x Inner Diameter (mm)	Total Length (m)	Thickness (mm)	SPQ (roll)	Weight (kg)
214-7386	TOP-6.5-5NG	¥2,499	¥2,700	Neo Gray	10 x 6.5	5	1.75	20	0.43
214-7394	TOP-6.5-10NG	¥3,398	¥3,670	Neo Gray	10 x 6.5	10	1.75	20	0.70
214-7408	TOP-6.5-20NG	¥5,277	¥5,700	Neo Gray	10 x 6.5	20	1.75	10	1.25
214-7416	TOP-6.5-30NG	¥7,387	¥7,980	Neo Gray	10 x 6.5	30	1.75	10	1.80

Contact us:0120-509-849 <http://www.orange-book.com/>


TRUSCO Stock 38,650 Items

Urethane Braided Tube (with free angle joint)



Com Drawing

- Features**
- Can rotate 360° to reduce burden to wrists and eliminate twist of hose.
 - With free angle joint.
 - Can be easily connected with a single action.
 - Compatible with general coupling.
- Specs**
- Working Fluid: Air
 - Fluid Temperature: -5 to 60° C (to be freeze free)
 - **Working Pressure: 1.5MPa**
 - Allowable Bending Radius: (room temperature) 60mm
 - Connecting Joint: C4P-6.5H/2FAS-6.5H
- Materials**
- Polyurethane
- Origin**
- Japan

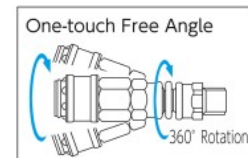

Order Unit: 1 Roll

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per roll)	MSRP (per roll)	Color	Outer Diameter x Inner Diameter (mm)	Total Length (m)	Thickness (mm)	SPQ (roll)	Weight (kg)
104-4559	TOP-6.5-10F	¥6,555	¥7,080	Red	10 x 6.5	10	1.75	20	0.77
104-4567	TOP-6.5-20F	¥9,442	¥10,200	Red	10 x 6.5	20	1.75	20	1.43

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

Urethane Blade Tube (with coupling for lock type tube)



Com.eco Chemical Content Inspection Com Drawing

- Features**
- Compared with rubber hose, it is approx. 1/3 to 1/5 lighter.
 - Excellent in oil resistance and pressure resistance and flexibility at low temperature (-5° C).
 - Compatible with general coupling.
- Specs**
- Working Fluid: Air
 - Fluid Temperature: -5 to 60° C (to be freeze free)
 - **Working Pressure: 1.5MPa**
 - Allowable Bending Radius: (room temperature) 60mm
 - Coupling Connection Joint: TL200-85SN/85PN
- Materials**
- Polyurethane
- Origin**
- Japan



Order Unit: 1 Roll

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per roll)	MSRP (per roll)	Color	Outer Diameter x Inner Diameter (mm)	Total Length (m)	Thickness (mm)	SPQ (roll)	Weight (kg)
214-7424	TOP-8.5-5	¥3,203	¥3,460	Red	12.5 x 8.5	5	2.00	20	0.51
214-7432	TOP-8.5-10	¥4,842	¥5,230	Red	12.5 x 8.5	10	2.00	10	0.85
214-7441	TOP-8.5-20	¥8,100	¥8,750	Red	12.5 x 8.5	20	2.00	10	1.54
214-7459	TOP-8.5-30	¥11,368	¥12,280	Red	12.5 x 8.5	30	2.00	5	2.22

Contact us:0120-509-849 <http://www.orange-book.com/>

⚠ Artificial shock, bending, tension may cause damage.