

The number next to the logo mark indicates items in stock for each brand.

Air
Impact
WrenchesAir
Ratchet
WrenchesAir
ScrewdriversAir
DrillsAir
Micro
GrindersAir
GrindersAir
FilesAir
SandersAir
Belt
SandersAir
ChiselsAir
HammersAir
SawsAir
BevelersAir
NippersAir
DustersAir
GunsAir
Blast
MachinesKURITA
栗田製作所Stock
47
Items

Air Duster Rate-increase Nozzle

RoHS



- Features**
- Several times the air volume compared with the normal nozzle (N-AG45) can be obtained.
- Origin**
- Japan



Order Unit: 1 Piece

(Price revision date: Jan, 2015) KURITA SEISAKUSHO

 
Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nozzle Length (mm)	Nozzle Opening Diameter (mm)	Nozzle Mounting Port	SPQ (piece)	Weight (g)
391-3724	N-AG60L	¥1,956	¥1,950	58.0	12	G1/8	5	67
391-3732	N-AG60S	¥1,504	¥1,500	39.0	9	G1/8	5	24
391-3741	N-AG70L	¥1,857	¥1,850	67.3	12	G1/8	5	23
391-3759	N-AG70S	¥1,605	¥1,600	47.3	10	G1/8	5	17

Contact us: 03-5638-8261 <http://www.cup-kurita.co.jp/>TRUSCO
TRUSCOStock
38,650
Items

Air Duster Conical Nozzle

.Com
Drawing

- Features**
- 12 holes make a powerful air conical.
 - Silent (68dB) type with increased flow rate.
 - Quiet and soft blow which is efficient.
- Origin**
- Japan



Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nozzle Length (mm)	Nozzle Opening Diameter (mm)	Nozzle Mounting Port	SPQ (piece)	Weight (g)
288-2141	TD-CAN	¥1,389	¥1,500	15	1 x 12	G1/8	10	23

Contact us: 0120-509-849 <http://www.orange-book.com/>TRUSCO
TRUSCOStock
38,650
Items


Silent Nozzle for Air Dusters

.Com
Drawing

 - Features**
- It is possible to blow air gently compared with sound of the normal nozzle. (78dB for standard nozzle 91dB at 0.5MPa)
- Origin**
- Japan

.Com
Drawing

- Features**
- Air curtain effect can be obtained while efficiently blowing air balance.
 - Safety nozzle that prevents spraying of bounce at the time of blowing.
 - Silent (67dB) type with increased flow rate.
- Origin**
- Japan

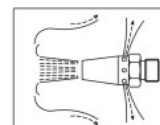

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nozzle Length (mm)	Nozzle Opening Diameter (mm)	Nozzle Mounting Port	SPQ (piece)	Weight (g)
228-0680	TD-18-SN	¥1,000	¥1,080	28	Special	G1/8	10	18

Contact us: 0120-509-849 <http://www.orange-book.com/>

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nozzle Length (mm)	Nozzle Opening Diameter (mm)	Nozzle Mounting Port	SPQ (piece)	Weight (g)
288-2159	TD-CYAN	¥1,851	¥2,000	25	1 x 8	G1/8	10	36

Contact us: 0120-509-849 <http://www.orange-book.com/>TRUSCO
TRUSCOStock
38,650
Items

Flat Nozzle for Air Dusters

.Com
Drawing

- Features**
- When blowing air at a distance of 20cm from the workpiece, air comes out with the sector pattern of approximately 25cm.
 - When air is blown on the flat surface, work can be performed efficiently compared with round nozzle air blow.
- Origin**
- Japan

.Com
Drawing

- Features**
- Since the tip is rubber, it does not hurt the work.
 - By blowing the tip directly against the pipe, the inner surface of the pipe will be cleaned quickly.
- Origin**
- Taiwan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nozzle Length (mm)	Nozzle Opening Diameter (mm)	Nozzle Mounting Port	SPQ (piece)	Weight (g)
284-3790	TD-18-FN	¥3,129	¥3,380	25	3	G1/8	20	20

Contact us: 0120-509-849 <http://www.orange-book.com/>

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nozzle Length (mm)	Nozzle Opening Diameter (mm)	Nozzle Mounting Port	SPQ (piece)	Weight (g)
284-3773	TD-18-PN	¥1,592	¥1,720	30	2	G1/8	20	10

Contact us: 0120-509-849 <http://www.orange-book.com/>