

Prices displayed include 8% tax.

For Disc Grinders, see p. 5-209 to 226

TRUSCO **Stock 38,650 Items**

"Soft Power Disc α"



Com.eco Chemical Content Inspection
Com. Drawing SDS

- Features**
- Blue sponge-like grinding grindstones made from Polyvinyl alcohol (PVA) excellent in elasticity, beautiful finished vinyl can be obtained with moderate elasticity.
 - Durability is improved and a beautiful and stable polished surface is obtained.
- Specs**
- Max Working Peripheral Velocity: 44.5m/s (2669m/min)
- Accessories**
- With 15mm hole adapter (1 piece per box)
- Origin**
- Japan



TSPA100-B (for metal)

Estimated Unit Price per Sheet
¥1,484



TSPA100-P (for non-metal)

Estimated Unit Price per Sheet
¥1,484

For Metal

- Features**
- GC (green carbon random) + WA (white a random) abrasive grain is used, the resin was selected compared with existing items.
- Use**
- Stain removal of various metals, rust removal, burring, welding masks finish, plating base polishing, scale removal, tank finishing. (Steel, stainless steel, aluminum, zinc, brass, copper)

Order Unit: 1 Box

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	OP	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter x Thickness x Hole Diameter (mm)	Max Working Rotation Speed (rpm)	Q'ty Per Box (sheet)	SPQ (box)	Weight (g/box)
261-2526	TSPA100-B	46	¥7,420	¥9,160	46	100 x 8 x 16	8500	5	20	490
261-2534	TSPA100-B	120	¥7,420	¥9,160	120	100 x 8 x 16	8500	5	20	420
261-2542	TSPA100-B	240	¥7,420	¥9,160	240	100 x 8 x 16	8500	5	20	380
261-2551	TSPA100-B	400	¥7,420	¥9,160	400	100 x 8 x 16	8500	5	20	370
261-2569	TSPA100-B	800	¥7,420	¥9,160	800	100 x 8 x 16	8500	5	20	360

For Non-Metal

- Features**
- GC (green carborundum) abrasive grain was used, carefully selected resin compared to conventional PVA.
- Use**
- Titanium, stone, glass polishing, chamfering of resin, burring.

Order Unit: 1 Box

Order Code	Item No.	OP	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter x Thickness x Hole Diameter (mm)	Max Working Rotation Speed (rpm)	Q'ty Per Box (sheet)	SPQ (box)	Weight (g/box)
261-2623	TSPA100-P	46	¥7,420	¥9,160	46	100 x 8 x 16	8500	5	20	475
261-2631	TSPA100-P	120	¥7,420	¥9,160	120	100 x 8 x 16	8500	5	20	420
261-2640	TSPA100-P	240	¥7,420	¥9,160	240	100 x 8 x 16	8500	5	20	380
261-2658	TSPA100-P	400	¥7,420	¥9,160	400	100 x 8 x 16	8500	5	20	370
261-2666	TSPA100-P	800	¥7,420	¥9,160	800	100 x 8 x 16	8500	5	20	350

Contact us: 0120-509-849 <http://www.orange-book.com/>


TRUSCO **Stock 38,650 Items**

"Soft Power Disc" (for medium finish polishing)



Com.eco Chemical Content Inspection
Com. Drawing SDS

- Features**
- A beautiful finish like with a double action sander even when using a single action sander greatly shortens sheet metal work.
 - As the cushioning body of the special foam material contacts the polished surface evenly, polishing with a feather touch is possible.
 - As the abrasive grains and special foam material repeat wear and regeneration, it will not clog.
 - A grain size of #60 (equivalent to a finishing surface of #180 to #240).
 - Made of urethane resin for medium finish polishing.
- Use**
- Scratch removal and scale removal of standard metals and finish polishing of stainless steel.
 - Exhibits power with paint removal.
- Specs**
- Max Working Peripheral Velocity: 26.2m/s (1570m/min)
- Accessories**
- With 15mm hole adapter (1 piece per box)
- Origin**
- Japan

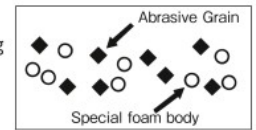

SP100C3

Estimated Unit Price per Sheet
¥2,698

Order Unit: 1 Box

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter x Thickness x Hole Diameter (mm)	Max Working Rotation Speed (rpm)	Q'ty Per Box (sheet)	SPQ (box)	Weight (g/box)
175-8560	SP100C3	¥13,487	¥16,650	60	100 x 8 x 16	5000	5	10	400

Contact us: 0120-509-849 <http://www.orange-book.com/>


TRUSCO **Stock 38,650 Items**

Poly Disc α (For polishing)



Com.eco Chemical Content Inspection
Com. Drawing SDS

- Features**
- Blue wool felt disc impregnated with non-chromium type oil-and-fat composition, you can make gloss mirror surface as it is.
- Use**
- Optimum for polishing stainless steel, standard metal.
 - Polishing, mirror surface finishing.
- Specs**
- Max Working Peripheral Velocity: 62.8m/s (3768m/min)
- Accessories**
- With 15mm hole adapter (1 piece per box)
- Origin**
- Japan

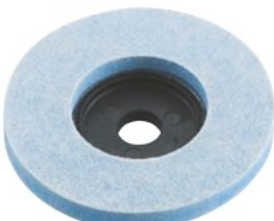

TPDA-100

Estimated Unit Price per Sheet
¥1,863

Order Unit: 1 Box

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter x Thickness x Hole Diameter (mm)	Max Working Rotation Speed (rpm)	Q'ty Per Box (sheet)	SPQ (box)	Weight (g/box)
261-2500	TPDA-100	¥9,315	¥11,500	Polisher	100 x 10 x 16	12000	5	20	400

Contact us: 0120-509-849 <http://www.orange-book.com/>

Abrasives

Grinding Wheels

Disk Papers

Papers for Double Action Sander

Nylon Discs

Urethane Discs

Felt Discs

Diamond Wheels

Grinding Wheels

Dressers

Flap Wheels

Nylon Wheel with Shaft

Shank Mounted Felt Wheels with Shaft

Bands

Shank Mounted Stones

Carbide Bars

Diamond Bars

CBN Bars

Files

Diamond Files

Grinding Stones

Abrasives

Sheet Sanding Papers

Abrasive Belts

Cup Brushes

Wheel Brushes with Shank

Hand Brushes