

Flap Wheels with Shaft (shaft diameter 6mm)

The number next to the logo mark indicates items in stock for each brand.

TRUSCO



Stock 38,650 Items



"Soft Wheel with Shaft" (shaft diameter 6mm)



Com Drawing SDS



- Features**
- For general metal.
 - As the polishing cloths have small slits, it is ideal for polishing not only small parts but also uneven surfaces.
 - Does not clog due to the "self-sharpening" effect.
 - Enables soft touch polishing.
 - A product that improves the diversity of grinding work while maintaining the characteristics of a flap wheel with shaft.
- Use**
- Polishing of uneven surfaces, polishing of wood and plastic, and light burr removal.
 - Working Tool: Straight-type grinder.
- Origin**
- Japan

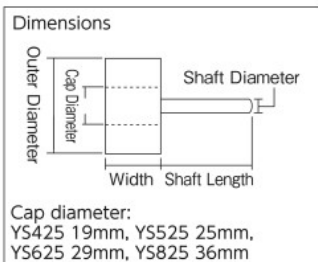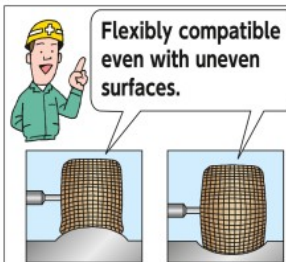

Estimated Unit Price per Piece
¥810 to ¥1,188

Outer diameter 40, 50mm Specs •Max Working Rotation Speed: 10000rpm

Order Unit: 1 Box TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Box SPQ: 20 Boxes

Order Code	Item No.	OP	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter x W x Shaft Diameter x Shaft Length (mm)	Blade Number (sheet)	Q'ty Per Box (piece)	Weight (g/box)
171-4244	YS425	40	¥4,050	¥5,000	40	40 x 25 x 6 x 40	Approx. 33	5	239
171-4252	YS425	60	¥4,050	¥5,000	60	40 x 25 x 6 x 40	Approx. 54	5	245
171-4261	YS425	80	¥4,050	¥5,000	80	40 x 25 x 6 x 40	Approx. 63	5	243
171-4279	YS425	100	¥4,050	¥5,000	100	40 x 25 x 6 x 40	Approx. 71	5	242
171-4287	YS425	120	¥4,050	¥5,000	120	40 x 25 x 6 x 40	Approx. 67	5	249
171-4295	YS425	150	¥4,050	¥5,000	150	40 x 25 x 6 x 40	Approx. 72	5	249
171-4309	YS425	180	¥4,050	¥5,000	180	40 x 25 x 6 x 40	Approx. 79	5	247
171-4317	YS425	240	¥4,050	¥5,000	240	40 x 25 x 6 x 40	Approx. 86	5	240
171-4325	YS425	320	¥4,050	¥5,000	320	40 x 25 x 6 x 40	Approx. 96	5	236
171-4333	YS425	400	¥4,050	¥5,000	400	40 x 25 x 6 x 40	Approx. 98	5	233

Order Code	Item No.	OP	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter x W x Shaft Diameter x Shaft Length (mm)	Blade Number (sheet)	Q'ty Per Box (piece)	Weight (g/box)
117-7028	YS525	40	¥4,050	¥5,000	40	50 x 25 x 6 x 40	Approx. 36	5	288
117-7036	YS525	60	¥4,050	¥5,000	60	50 x 25 x 6 x 40	Approx. 56	5	293
117-7044	YS525	80	¥4,050	¥5,000	80	50 x 25 x 6 x 40	Approx. 64	5	289
117-7052	YS525	100	¥4,050	¥5,000	100	50 x 25 x 6 x 40	Approx. 75	5	293
117-7061	YS525	120	¥4,050	¥5,000	120	50 x 25 x 6 x 40	Approx. 67	5	301
117-7079	YS525	150	¥4,050	¥5,000	150	50 x 25 x 6 x 40	Approx. 74	5	295
117-7087	YS525	180	¥4,050	¥5,000	180	50 x 25 x 6 x 40	Approx. 77	5	295
117-7095	YS525	240	¥4,050	¥5,000	240	50 x 25 x 6 x 40	Approx. 90	5	287
117-7109	YS525	320	¥4,050	¥5,000	320	50 x 25 x 6 x 40	Approx. 93	5	281
117-7117	YS525	400	¥4,050	¥5,000	400	50 x 25 x 6 x 40	Approx. 101	5	287

Outer Diameter 60mm Specs •Max Working Rotation Speed: 8000rpm

Order Unit: 1 Box

Order Unit: 1 Box SPQ: 10 Boxes

Order Code	Item No.	OP	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter x W x Shaft Diameter x Shaft Length (mm)	Blade Number (sheet)	Q'ty Per Box (piece)	Weight (g/box)
171-4341	YS625	40	¥5,193	¥6,410	40	60 x 25 x 6 x 40	Approx. 45	5	368
171-4350	YS625	60	¥5,193	¥6,410	60	60 x 25 x 6 x 40	Approx. 70	5	380
171-4368	YS625	80	¥5,193	¥6,410	80	60 x 25 x 6 x 40	Approx. 82	5	376
171-4376	YS625	100	¥5,193	¥6,410	100	60 x 25 x 6 x 40	Approx. 93	5	381
171-4384	YS625	120	¥5,193	¥6,410	120	60 x 25 x 6 x 40	Approx. 92	5	393

Order Code	Item No.	OP	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter x W x Shaft Diameter x Shaft Length (mm)	Blade Number (sheet)	Q'ty Per Box (piece)	Weight (g/box)
171-4392	YS625	150	¥5,193	¥6,410	150	60 x 25 x 6 x 40	Approx. 96	5	387
171-4406	YS625	180	¥5,193	¥6,410	180	60 x 25 x 6 x 40	Approx. 96	5	389
171-4414	YS625	240	¥5,193	¥6,410	240	60 x 25 x 6 x 40	Approx. 120	5	368
171-4422	YS625	320	¥5,193	¥6,410	320	60 x 25 x 6 x 40	Approx. 119	5	363
171-4431	YS625	400	¥5,193	¥6,410	400	60 x 25 x 6 x 40	Approx. 132	5	367

Outer Diameter 80mm Specs •Max Working Rotation Speed: 6000rpm

Order Unit: 1 Box

Order Unit: 1 Box SPQ: 10 Boxes

Order Code	Item No.	OP	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter x W x Shaft Diameter x Shaft Length (mm)	Blade Number (sheet)	Q'ty Per Box (piece)	Weight (g/box)
117-7125	YS825	40	¥5,938	¥7,330	40	80 x 25 x 6 x 40	Approx. 55	5	549
117-7133	YS825	60	¥5,938	¥7,330	60	80 x 25 x 6 x 40	Approx. 86	5	572
117-7141	YS825	80	¥5,938	¥7,330	80	80 x 25 x 6 x 40	Approx. 102	5	568
117-7150	YS825	100	¥5,938	¥7,330	100	80 x 25 x 6 x 40	Approx. 109	5	564
117-7168	YS825	120	¥5,938	¥7,330	120	80 x 25 x 6 x 40	Approx. 111	5	584

Order Code	Item No.	OP	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter x W x Shaft Diameter x Shaft Length (mm)	Blade Number (sheet)	Q'ty Per Box (piece)	Weight (g/box)
117-7176	YS825	150	¥5,938	¥7,330	150	80 x 25 x 6 x 40	Approx. 120	5	594
117-7184	YS825	180	¥5,938	¥7,330	180	80 x 25 x 6 x 40	Approx. 121	5	574
117-7192	YS825	240	¥5,938	¥7,330	240	80 x 25 x 6 x 40	Approx. 141	5	559
117-7206	YS825	320	¥5,938	¥7,330	320	80 x 25 x 6 x 40	Approx. 146	5	548
117-7214	YS825	400	¥5,938	¥7,330	400	80 x 25 x 6 x 40	Approx. 157	5	545

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO



Stock 38,650 Items

Ceramic Abrasive Grain Flap Wheel (suitable for polishing difficult-to-grind materials)




- Features**
- By employing ceramic abrasive grains, high grinding capacity and long life have been realized.
 - Capable of polishing of difficult-to-grind materials such as stainless steel and titanium.
 - For coarse grinding.
 - Compared to our conventional products, grinding performance has more than tripled.
 - *According to tests by our company
- Use**
- Rust remover, burring, polishing of pipe's inner side.
 - Working Tool: Straight-type grinder.
- Origin**
- Japan



HF5025C-60

Estimated Unit Price per Piece
¥972 to ¥1215

Order Unit: 1 Box TRUSCO NAKAYAMA CORPORATION

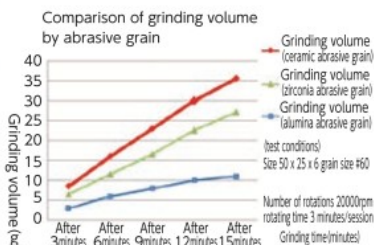

Order Code	Item No.	Price (per box)	MSRP (per box)	Grain Size (#)	Outer Diameter x W x Shaft Diameter x Shaft Length (mm)	Blade Number (sheet)	Max Working Rotation Speed (rpm)	Q'ty Per Box (piece)	SPQ (box)	Weight (g/box)
856-3406	HF4025C-40	¥4,860	¥6,000	40	40 x 25 x 6 x 40	Approx. 29	20000	5	20	145
856-3407	HF4025C-60	¥4,860	¥6,000	60	40 x 25 x 6 x 40	Approx. 38	20000	5	20	190
856-3408	HF4025C-80	¥4,860	¥6,000	80	40 x 25 x 6 x 40	Approx. 44	20000	5	20	220
856-3409	HF5025C-40	¥5,265	¥6,500	40	50 x 25 x 6 x 40	Approx. 42	20000	5	20	210
856-3410	HF5025C-60	¥5,265	¥6,500	60	50 x 25 x 6 x 40	Approx. 53	20000	5	20	265
856-3411	HF5025C-80	¥5,265	¥6,500	80	50 x 25 x 6 x 40	Approx. 59	20000	5	20	295
856-3412	HF6025C-40	¥6,075	¥7,500	40	60 x 25 x 6 x 40	Approx. 51	18000	5	20	255
856-3413	HF6025C-60	¥6,075	¥7,500	60	60 x 25 x 6 x 40	Approx. 61	18000	5	20	305
856-3414	HF6025C-80	¥6,075	¥7,500	80	60 x 25 x 6 x 40	Approx. 71	18000	5	20	355

Contact us: 0120-509-849 <http://www.orange-book.com/>