


Prices displayed include 8% tax.


Stock
38,650
 Items

Diamond Wire

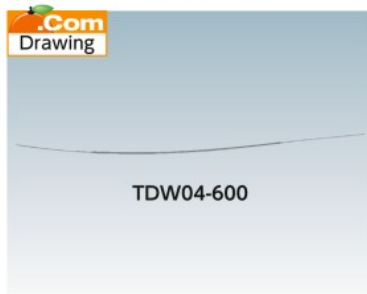

- Features**
- Suitable for processing narrow groove-like curved surfaces and shapes.
 - The wire can be bent to the needed angle (R) for use.
- Use**
- For groove processing of punching steel.
 - For polishing work of groove portions.
 - For polishing of narrow spaces.
- Origin**
- Israel




Example


Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Grain Size (#)	Shape	Total Length (mm)	Blade Length (mm)	SPQ (piece)	Weight (g)
764-4931	TDW10-170	¥4,443	¥4,800	170	Wire diameter 1.0mm	130	70	10	1.0
764-4922	TDW05-325	¥4,443	¥4,800	325	Wire diameter 0.5mm	130	70	10	0.9
764-4914	TDW04-600	¥4,443	¥4,800	600	Wire diameter 0.4mm	130	70	10	0.8

 Contact us: 0120-509-849 <http://www.orange-book.com/>
Stock
38,650
 Items

Diamond Feather Edge Saw File

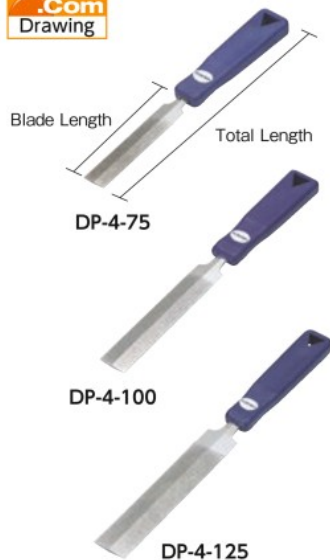

- Features**
- Can grind ceramics, carbide and hardened steel that can not be ground by files and whetstones.
- Use**
- Polishing of carbide tip, tool bit, drill. Tipped saw and grass cutting blade fitting, etc.
- Materials**
- Carbon Steel for Structures (S45C)
- Origin**
- Japan



Example

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Grain Size (#)	Shape	Total Length (mm)	Blade Length (mm)	SPQ (piece)	Weight (g)
171-4473	DP-4-75	¥2,434	¥2,630	140	Rhombus	175	75	10	47.2
171-4481	DP-4-100	¥2,971	¥3,210	140	Rhombus	205	100	10	63.4
171-4490	DP-4-125	¥3,786	¥4,090	140	Rhombus	235	125	10	85.2

Contact us: 0120-509-849 <http://www.orange-book.com/>
Stock
38,650
 Items

Diamond Lapper



- Use**
- Optimum for glass, ceramics, woodwork, aluminum, copper and plastic, stone processing.
- Specs**
- Diamond Dimensions: 29 x 10.5mm
- Origin**
- Japan

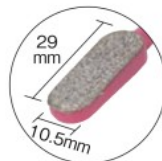

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Grain Size (#)	Comments	Total Length (mm)	SPQ (piece)	Weight (g)
171-4546	GDH-80	¥1,074	¥1,160	80	Pink/Ultra Rough Finish	172	10	20
171-4554	GDH-180	¥ 944	¥1,020	180	Green/Rough Finish	172	10	20
171-4562	GDH-400	¥ 889	¥ 960	400	Blue/Finishing	172	10	20
286-8181	GDH-600	¥ 889	¥ 960	600	Sky Blue/Finishing	172	10	20
286-8199	GDH-800	¥ 889	¥ 960	800	Light Green/Precision Finish	172	10	20
286-8202	GDH-1000	¥ 889	¥ 960	1000	Orange/ultra precision finishing	172	10	20

Contact us: 0120-509-849 <http://www.orange-book.com/>