


Prices displayed include 8% tax.

TRUSCO Stock 38,650 Items

Wheel Brush with Shaft (shaft diameter 6.35mm)



- Features**
- The shape of the brush is a disc type, and hair is planted radially toward the outside.
 - Since it is used with electric impact drivers, it can be removed with one touch.
- Use**
- Burring of metal surfaces, polishing, cleaning, etc.
- Specs**
- Wheel brush (disc type) with hexagonal shaft
 - 10mm thick specification
- Materials**
- Shaft: Steel (zinc plated iron material)
- Origin**
- Korea

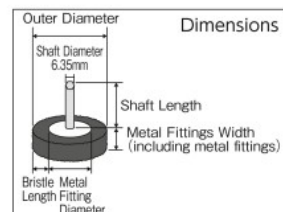

Steel Wire

Order Unit: 1 Piece

(Price revision date: Jan, 2018) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Wire Diameter (mm)	Bristle Material	Outer Diameter x Bristle Length x Shaft Length x Shaft Diameter (mm)	Metal fitting diameter (mm)	Metal Fitting Width (mm)	Max Working Rotation Speed (rpm)	SPQ (piece)	Weight (g)
352-1079	TB-6202-60	¥1,157	¥1,250	0.3	Steel Wire	32 x 6 x 27 x 6.35	20	12	3000	1	35
352-1095	TB-6212-60	¥1,157	¥1,250	0.3	Steel Wire	38 x 9 x 27 x 6.35	20	12	3000	1	43
352-1117	TB-6222-60	¥1,203	¥1,300	0.3	Steel Wire	50 x 12 x 27 x 6.35	26	12	3000	1	60
352-1133	TB-6232-60	¥1,203	¥1,300	0.3	Steel Wire	65 x 17 x 27 x 6.35	32	12	3000	1	85
352-1087	TB-6242-60	¥1,296	¥1,400	0.3	Steel Wire	75 x 19 x 27 x 6.35	37	12	3000	1	110
352-1044	TB-6252-60	¥1,389	¥1,500	0.3	Steel Wire	100 x 31 x 27 x 6.35	38	12	3000	1	130



TB-6232-60 (wire steel wire)

Stainless Steel

Order Unit: 1 Piece

(Price revision date: Jan, 2018)

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Wire Diameter (mm)	Bristle Material	Outer Diameter x Bristle Length x Shaft Length x Shaft Diameter (mm)	Metal fitting diameter (mm)	Metal Fitting Width (mm)	Max Working Rotation Speed (rpm)	SPQ (piece)	Weight (g)
352-1052	TB-6203-60	¥1,666	¥1,800	0.3	Stainless Steel	32 x 6 x 27 x 6.35	20	12	3000	1	35
352-1109	TB-6213-60	¥1,666	¥1,800	0.3	Stainless Steel	38 x 9 x 27 x 6.35	20	12	3000	1	43
352-1125	TB-6223-60	¥1,713	¥1,850	0.3	Stainless Steel	50 x 12 x 27 x 6.35	26	12	3000	1	60
352-0960	TB-6233-60	¥1,759	¥1,900	0.3	Stainless Steel	65 x 17 x 27 x 6.35	32	12	3000	1	85
352-1061	TB-6243-60	¥1,805	¥1,950	0.3	Stainless Steel	75 x 19 x 27 x 6.35	37	12	3000	1	110
352-1036	TB-6253-60	¥2,037	¥2,200	0.3	Stainless Steel	100 x 31 x 27 x 6.35	38	12	3000	1	130



TB-6233-60 (stainless steel)

Brass Plating Steel Wire

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Wire Diameter (mm)	Bristle Material	Outer Diameter x Bristle Length x Shaft Length x Shaft Diameter (mm)	Metal fitting diameter (mm)	Metal Fitting Width (mm)	Max Working Rotation Speed (rpm)	SPQ (piece)	Weight (g)
855-4878	TB-6201-60	¥1,203	¥1,300	0.25	Brass Plating Steel Wire	32 x 6 x 27 x 6.35	20	12	3000	1	35
855-4879	TB-6211-60	¥1,203	¥1,300	0.25	Brass Plating Steel Wire	38 x 9 x 27 x 6.35	20	12	3000	1	43
855-4880	TB-6221-60	¥1,231	¥1,330	0.25	Brass Plating Steel Wire	50 x 12 x 27 x 6.35	26	12	3000	1	60
855-4881	TB-6231-60	¥1,278	¥1,380	0.25	Brass Plating Steel Wire	65 x 17 x 27 x 6.35	32	12	3000	1	90
855-4882	TB-6241-60	¥1,416	¥1,530	0.25	Brass Plating Steel Wire	75 x 19 x 27 x 6.35	37	12	3000	1	115
855-4883	TB-6251-60	¥1,435	¥1,550	0.25	Brass Plating Steel Wire	100 x 31 x 27 x 6.35	38	12	3000	1	145



TB-6251-60 (brass plating steel wire)

Brass Wire

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Wire Diameter (mm)	Bristle Material	Outer Diameter x Bristle Length x Shaft Length x Shaft Diameter (mm)	Metal fitting diameter (mm)	Metal Fitting Width (mm)	Max Working Rotation Speed (rpm)	SPQ (piece)	Weight (g)
855-4884	TB-6204-60	¥1,666	¥1,800	0.15	Brass Wire	32 x 6.0 x 27 x 6.35	20	12	3000	1	35
855-4885	TB-6214-60	¥1,666	¥1,800	0.15	Brass Wire	38 x 9.0 x 27 x 6.35	20	12	3000	1	40
855-4886	TB-6224-60	¥1,759	¥1,900	0.15	Brass Wire	50 x 12.0 x 27 x 6.35	26	12	3000	1	55
855-4887	TB-6234-60	¥1,851	¥2,000	0.15	Brass Wire	65 x 17.0 x 27 x 6.35	32	12	3000	1	75
855-4888	TB-6244-60	¥2,222	¥2,400	0.15	Brass Wire	75 x 19.0 x 27 x 6.35	37	12	3000	1	95
855-4889	TB-6254-60	¥2,407	¥2,600	0.15	Brass Wire	100 x 31.0 x 27 x 6.35	38	12	3000	1	115



TB-6254-60 (brass wire)

Contact us: 0120-509-849 <http://www.orange-book.com/>

YANASE Stock 585 Items

Safety Brush



- Features**
- A normal steel wire brush processed with bonding (resin) to reduce bristles from falling out or bending as much as possible.
 - The bonding process has improved safety and extended the product life.
- Materials**
- Steel wire plating
- Origin**
- China



BKFA-75

Order Unit: 5 Pieces

YANASE Co.Ltd

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Qty Per Pack (piece)	Wire Diameter (mm)	Bristle Material	Outer Diameter x Bristle Length x Shaft Length x Shaft Diameter (mm)	Max Working Rotation Speed (rpm)	Weight (g)
855-5935	BKFA-75	¥1,823*	¥2,700*	5	0.3	Steel Wire	75 x 22.5 x 25 x 6	10000	94

Contact us: 0795-77-2151 <http://www.yanase-saving.com/>