


Stock
38,650
Items

Threaded Type Coupling Tee (outside x outside x outside screw)



TN-02T

- Features** • Those with male threads are subjected to sealing of all male screw thread parts.
Use • For pipe and parts for pipe and fluid equipment such as tightness resistance connection.
Specs • Working Fluid: Water, Air, Oil • Fluid Temperature: 0 to 100° C
 • Working Pressure: 14MPa
Materials • Brass (C3771)
Origin • Japan

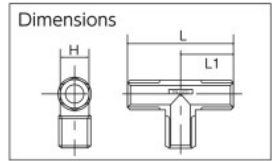

Order Unit: 1 Piece

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nominal Diameter	Dimension (mm)			SPQ (piece)	Weight (g)
					H	L	L1		
257-6732	TN-01T	¥ 583	¥ 630	R1/8 x R1/8 x R1/8	10	37	18.5	10	20
257-6741	TN-02T	¥ 593	¥ 640	R1/4 x R1/4 x R1/4	12	44	22.0	10	35
257-6759	TN-03T	¥ 741	¥ 800	R3/8 x R3/8 x R3/8	14	52	26.0	25	70
257-6767	TN-04T	¥1,602	¥1,730	R1/2 x R1/2 x R1/2	22	66	33.0	20	120


Contact us:0120-509-849 <http://www.orange-book.com/>Stock
38,650
Items

Threaded Type Coupling Tee (inside x inside x outside screw)



TN-0414T

- Features** • Those with male threads are subjected to sealing of all male screw thread parts.
Use • For pipe and parts for pipe and fluid equipment such as tightness resistance connection.
Specs • Working Fluid: Water, Air, Oil • Fluid Temperature: 0 to 100° C
 • Working Pressure: 14MPa
Materials • Brass (C3771)
Origin • Japan

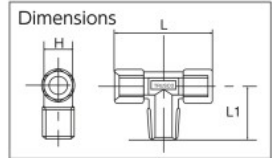

Order Unit: 1 Piece

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nominal Diameter	Dimension (mm)			SPQ (piece)	Weight (g)
					H	L	L1		
257-6775	TN-0111T	¥ 537	¥ 580	Rc1/8 x R1/8 x Rc1/8	12	42	21	10	40
257-6783	TN-0212T	¥ 676	¥ 730	Rc1/4 x R1/4 x Rc1/4	14	50	25	10	60
257-6791	TN-0313T	¥1,185	¥1,280	Rc3/8 x R3/8 x Rc3/8	18	60	30	25	130
257-6805	TN-0414T	¥1,555	¥1,680	Rc1/2 x R1/2 x Rc1/2	22	66	33	20	210


Contact us:0120-509-849 <http://www.orange-book.com/>Stock
38,650
Items

Threaded Type Coupling Tee (inside x inside x inside screw)



TN-14T

- Features** • It is for holding external screw of threaded couplings.
Use • For pipe and parts for pipe and fluid equipment such as tightness resistance connection.
Specs • Working Fluid: Water, Air, Oil • Fluid Temperature: 0 to 100° C
 • Working Pressure: 14MPa
Materials • Brass (C3771)
Origin • Japan

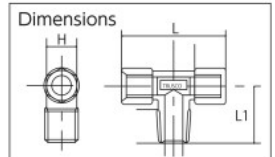

Order Unit: 1 Piece

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nominal Diameter	Dimension (mm)			SPQ (piece)	Weight (g)
					H	L	L1		
257-6813	TN-11T	¥ 490	¥ 530	Rc1/8 x Rc1/8 x Rc1/8	12	42	21	10	40
257-6821	TN-12T	¥ 658	¥ 710	Rc1/4 x Rc1/4 x Rc1/4	14	50	25	10	60
257-6830	TN-13T	¥1,435	¥1,550	Rc3/8 x Rc3/8 x Rc3/8	18	60	30	25	150
257-6848	TN-14T	¥1,490	¥1,610	Rc1/2 x Rc1/2 x Rc1/2	22	66	33	20	230


Contact us:0120-509-849 <http://www.orange-book.com/>Stock
38,650
Items

Threaded Type Coupling Tee (inside x inside x outside screw/different diameter)



TN-0314T

- Features** • Those with male threads are subjected to sealing of all male screw thread parts.
Use • For pipe and parts for pipe and fluid equipment such as tightness resistance connection.
Specs • Working Fluid: Water, Air, Oil
 • Fluid Temperature: 0 to 100° C
 • Working Pressure: 14MPa
Materials • Brass (C3771)
Origin • Japan

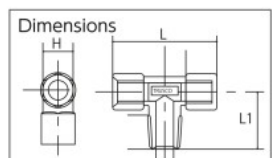

Order Unit: 1 Piece

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nominal Diameter	Dimension (mm)			SPQ (piece)	Weight (g)
					H	L	L1		
257-6856	TN-0213T	¥1,185	¥1,280	Rc3/8 x R1/4 x Rc3/8	18	60	28.5	25	130
257-6864	TN-0314T	¥1,555	¥1,680	Rc1/2 x R3/8 x Rc1/2	22	66	31.0	20	200

Contact us:0120-509-849 <http://www.orange-book.com/>