

# Wheel Conveyors for Picking Rack

For Pipe Systems, see p. 8-384 to 396

The number next to the logo mark indicates items in stock for each brand.

Conveyors

Steel Roller Conveyors

Stainless Steel Roller Conveyors

Aluminum Roller Conveyors

Resin Roller Conveyors

Extension Roller Conveyors

Wheels Conveyors

Ball Casters Units

Upward Ball Casters

Downward Ball Casters

Upward/Downward Combined Use Ball Casters

Cleanroom Type Ball Casters

Ball Casters for Special Purpose

Motor Pulleys, Motor Rollers

Belt Conveyors

Mini Belt Conveyors

Belts

TRUSCO




Wheel Conveyors for Picking Rack (wheel diameter 18mm)



Com Drawing



- Features**
- Wheel made of resin is being used.
  - It has a small diameter (18mm) and small pitch (20mm) so it can convey small workpieces.
- Use**
- For small parts and containers.
- Specs**
- Load Per Wheel: 10kg
  - Wheel width: 20mm
- Materials**
- Frame: Hot dip zinc-plated steel plate
  - Wheel: Polypropylene (PP)
- Origin**
- Japan

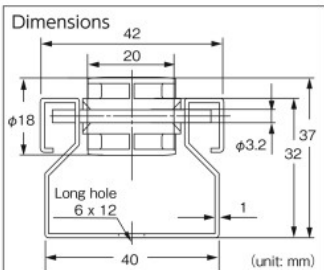

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands |

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Pitch (mm)	Conveyor Length (mm)	SPQ (piece)	Weight (kg)
★300-5569	V-1820UP-20-1000	¥2,610	¥2,820	20	1000	1	1.25
★300-5577	V-1820UP-20-1500	¥3,925	¥4,240	20	1500	1	1.87
★300-5585	V-1820UP-20-2000	¥5,221	¥5,640	20	2000	1	2.50
★300-5593	V-1820UP-20-3000	¥7,831	¥8,460	20	3000	1	3.75
★300-5607	V-1820UP-25-1000	¥2,323	¥2,510	25	1000	1	1.23
★300-5615	V-1820UP-25-1500	¥3,489	¥3,770	25	1500	1	1.85
★300-5623	V-1820UP-25-2000	¥4,638	¥5,010	25	2000	1	2.46
★300-5631	V-1820UP-25-3000	¥6,952	¥7,510	25	3000	1	3.69

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO




Wheel Conveyors for Picking Rack (wheel diameter 18mm)



Com Drawing



- Features**
- Wheel made of resin is being used.
  - It has a small diameter (18mm) and small pitch (20mm) so it can convey small workpieces.
- Use**
- For small parts and containers.
- Specs**
- Load Per Wheel: 10kg
  - Wheel width: 67mm
- Materials**
- Frame: Hot dip zinc-plated steel plate
  - Wheel: Polypropylene (PP)
- Origin**
- Japan

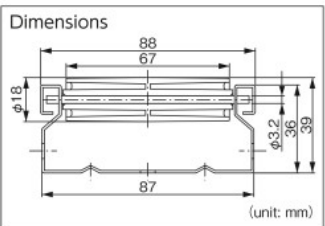

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands |

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Pitch (mm)	Conveyor Length (mm)	SPQ (piece)	Weight (kg)
★854-9333	V-1870UP-20-1000	¥4,302	¥5,310	20	1000	1	2.19
★854-9334	V-1870UP-20-1500	¥6,456	¥7,970	20	1500	1	3.29
★854-9335	V-1870UP-20-2000	¥8,602	¥10,620	20	2000	1	4.38
★854-9336	V-1870UP-20-2400	¥10,319	¥12,740	20	2400	1	5.26
★854-9337	V-1870UP-20-3000	¥12,904	¥15,930	20	3000	1	6.57
★854-9338	V-1870UP-25-1000	¥3,735	¥4,610	25	1000	1	2.05
★854-9339	V-1870UP-25-1500	¥5,598	¥6,910	25	1500	1	3.08
★854-9340	V-1870UP-25-2000	¥7,468	¥9,220	25	2000	1	4.10
★854-9341	V-1870UP-25-2400	¥8,959	¥11,060	25	2400	1	4.92
★854-9342	V-1870UP-25-3000	¥11,203	¥13,830	25	3000	1	6.15

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO




Wheel Conveyors for Picking Rack (wheel diameter 36mm)



Com Drawing



- Features**
- Wheel made of resin is being used.
  - It is quieter than resin wheels and does not damage the workpieces.
- Use**
- For mounting FIFO racks, hand carts and line pallets.
- Specs**
- Load Per Wheel: 10kg
  - Wheel width: 20mm
- Materials**
- Frame: Hot dip zinc-plated steel plate
  - Wheel: Polypropylene (PP)
- Origin**
- Japan

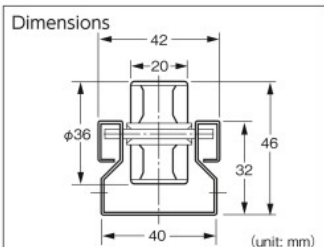

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands |

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Pitch (mm)	Conveyor Length (mm)	SPQ (piece)	Weight (kg)
★461-2191	V-3620UP-40-1000	¥2,278	¥2,460	40	1000	1	1.28
★461-2205	V-3620UP-40-1500	¥3,406	¥3,680	40	1500	1	1.92
★285-2411	V-3620UP-40-1800	¥4,202	¥4,540	40	1800	1	2.30
★461-2213	V-3620UP-40-2000	¥4,638	¥5,010	40	2000	1	2.56
★285-2420	V-3620UP-40-2400	¥5,610	¥6,060	40	2400	1	3.07
★461-2221	V-3620UP-40-3000	¥6,915	¥7,470	40	3000	1	3.84
★461-2230	V-3620UP-50-1000	¥2,019	¥2,180	50	1000	1	1.25
★461-2248	V-3620UP-50-1500	¥3,046	¥3,290	50	1500	1	1.87
★285-2390	V-3620UP-50-1800	¥3,684	¥3,980	50	1800	1	2.25
★461-2256	V-3620UP-50-2000	¥4,027	¥4,350	50	2000	1	2.50
★285-2403	V-3620UP-50-2400	¥4,915	¥5,310	50	2400	1	3.00
★461-2264	V-3620UP-50-3000	¥6,091	¥6,580	50	3000	1	3.75

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO




Wheel Conveyors for Picking Rack (wheel diameter 36mm)



Com Drawing



- Features**
- Wheel made of resin is being used.
  - It is quieter than resin wheels and does not damage the workpieces.
- Use**
- For mounting FIFO racks, hand carts and line pallets.
- Specs**
- Load Per Wheel: 10kg
  - Wheel width: 67mm
- Materials**
- Frame: Hot dip zinc-plated steel plate
  - Wheel: Polypropylene (PP)
- Origin**
- Japan

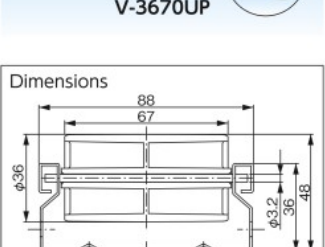

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands |

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Pitch (mm)	Conveyor Length (mm)	SPQ (piece)	Weight (kg)
★854-9363	V-3670UP-40-1000	¥3,337	¥4,120	40	1000	1	2.31
★854-9364	V-3670UP-40-1500	¥5,006	¥6,180	40	1500	1	3.46
★854-9365	V-3670UP-40-2000	¥6,674	¥8,240	40	2000	1	4.62
★854-9366	V-3670UP-40-2400	¥8,011	¥9,890	40	2400	1	5.54
★854-9367	V-3670UP-40-3000	¥10,012	¥12,360	40	3000	1	6.93
★854-9368	V-3670UP-50-1000	¥2,965	¥3,660	50	1000	1	2.15
★854-9369	V-3670UP-50-1500	¥4,447	¥5,490	50	1500	1	3.23
★854-9370	V-3670UP-50-2000	¥5,929	¥7,320	50	2000	1	4.30
★854-9371	V-3670UP-50-2400	¥7,120	¥8,790	50	2400	1	5.16
★854-9372	V-3670UP-50-3000	¥8,902	¥10,990	50	3000	1	6.45

Contact us: 0120-509-849 <http://www.orange-book.com/>