

Prices displayed include 8% tax.

TRUSCO **Stock 38,650 Items**



Low Partition



- Features**
- Cloth type with high versatility.
 - Available in a rich variety of sizes for both width and height.
 - Flexible layout is possible by using self-supporting/connecting parts.
 - Simplified connection enables easy construction.
- Specs**
- Panel thickness: 30mm
 - Full cloth covered
- Materials**
- Panel: Flush plywood
 - Panel fram: Vinyl chloride molded item
- Origin**
- Japan

Warning

- Stabilizer feet, connecting members, etc. are not included in the panel main body.

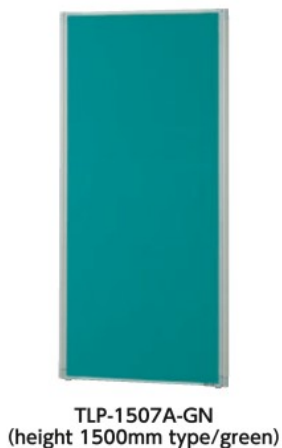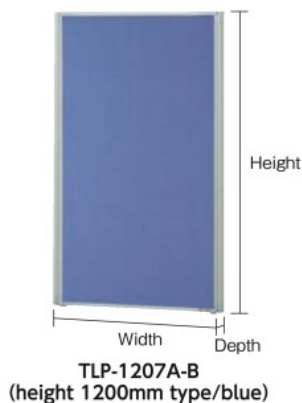

Height 1200mm type

Order Unit: 1 Sheet | Factory direct | No freight charge | Excluding remote islands | TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Color	W x D x H (mm)	Type	SPQ (sheet)	Weight (kg)
★764-9037	TLP-1206A-B	¥20,169	¥24,900	Blue	600 x 30 x 1165	Connected Type	1	3.5
★764-9045	TLP-1206A-GN	¥20,169	¥24,900	Green	600 x 30 x 1165	Connected Type	1	3.5
★764-9053	TLP-1206A-GY	¥20,169	¥24,900	Gray	600 x 30 x 1165	Connected Type	1	3.5
★764-9061	TLP-1206A-OR	¥20,169	¥24,900	Orange	600 x 30 x 1165	Connected Type	1	3.5
★764-9070	TLP-1207A-B	¥25,758	¥31,800	Blue	700 x 30 x 1165	Connected Type	1	4.0
★764-9088	TLP-1207A-GN	¥25,758	¥31,800	Green	700 x 30 x 1165	Connected Type	1	4.0
★764-9096	TLP-1207A-GY	¥25,758	¥31,800	Gray	700 x 30 x 1165	Connected Type	1	4.0
★764-9100	TLP-1207A-OR	¥25,758	¥31,800	Orange	700 x 30 x 1165	Connected Type	1	4.0
★764-9118	TLP-1208A-B	¥26,001	¥32,100	Blue	800 x 30 x 1165	Connected Type	1	4.5
★764-9126	TLP-1208A-GN	¥26,001	¥32,100	Green	800 x 30 x 1165	Connected Type	1	4.5
★764-9134	TLP-1208A-GY	¥26,001	¥32,100	Gray	800 x 30 x 1165	Connected Type	1	4.5
★764-9142	TLP-1208A-OR	¥26,001	¥32,100	Orange	800 x 30 x 1165	Connected Type	1	4.5
★764-9151	TLP-1209A-B	¥26,892	¥33,200	Blue	900 x 30 x 1165	Connected Type	1	5.0
★764-9169	TLP-1209A-GN	¥26,892	¥33,200	Green	900 x 30 x 1165	Connected Type	1	5.0
★764-9177	TLP-1209A-GY	¥26,892	¥33,200	Gray	900 x 30 x 1165	Connected Type	1	5.0
★764-9185	TLP-1209A-OR	¥26,892	¥33,200	Orange	900 x 30 x 1165	Connected Type	1	5.0
★764-9240	TLP-1212A-B	¥31,995	¥39,500	Blue	1200 x 30 x 1165	Connected Type	1	7.0
★764-9258	TLP-1212A-GN	¥31,995	¥39,500	Green	1200 x 30 x 1165	Connected Type	1	7.0
★764-9266	TLP-1212A-GY	¥31,995	¥39,500	Gray	1200 x 30 x 1165	Connected Type	1	7.0
★764-9274	TLP-1212A-OR	¥31,995	¥39,500	Orange	1200 x 30 x 1165	Connected Type	1	7.0

Height 1500mm type

Order Unit: 1 Sheet | Factory direct | No freight charge | Excluding remote islands

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Color	W x D x H (mm)	Type	SPQ (sheet)	Weight (kg)
★764-9339	TLP-1506A-B	¥24,624	¥30,400	Blue	600 x 30 x 1465	Connected Type	1	5.0
★764-9347	TLP-1506A-GN	¥24,624	¥30,400	Green	600 x 30 x 1465	Connected Type	1	5.0
★764-9355	TLP-1506A-GY	¥24,624	¥30,400	Gray	600 x 30 x 1465	Connected Type	1	5.0
★764-9363	TLP-1506A-OR	¥24,624	¥30,400	Orange	600 x 30 x 1465	Connected Type	1	5.0
★764-9371	TLP-1507A-B	¥28,188	¥34,800	Blue	700 x 30 x 1465	Connected Type	1	5.5
★764-9380	TLP-1507A-GN	¥28,188	¥34,800	Green	700 x 30 x 1465	Connected Type	1	5.5
★764-9398	TLP-1507A-GY	¥28,188	¥34,800	Gray	700 x 30 x 1465	Connected Type	1	5.5
★764-9401	TLP-1507A-OR	¥28,188	¥34,800	Orange	700 x 30 x 1465	Connected Type	1	5.5
★764-9410	TLP-1508A-B	¥28,674	¥35,400	Blue	800 x 30 x 1465	Connected Type	1	6.0
★764-9428	TLP-1508A-GN	¥28,674	¥35,400	Green	800 x 30 x 1465	Connected Type	1	6.0
★764-9436	TLP-1508A-GY	¥28,674	¥35,400	Gray	800 x 30 x 1465	Connected Type	1	6.0
★764-9444	TLP-1508A-OR	¥28,674	¥35,400	Orange	800 x 30 x 1465	Connected Type	1	6.0
★764-9452	TLP-1509A-B	¥29,970	¥37,000	Blue	900 x 30 x 1465	Connected Type	1	7.0
★764-9461	TLP-1509A-GN	¥29,970	¥37,000	Green	900 x 30 x 1465	Connected Type	1	7.0
★764-9479	TLP-1509A-GY	¥29,970	¥37,000	Gray	900 x 30 x 1465	Connected Type	1	7.0
★764-9487	TLP-1509A-OR	¥29,970	¥37,000	Orange	900 x 30 x 1465	Connected Type	1	7.0
★764-9584	TLP-1512A-B	¥33,615	¥41,500	Blue	1200 x 30 x 1465	Connected Type	1	8.0
★764-9592	TLP-1512A-GN	¥33,615	¥41,500	Green	1200 x 30 x 1465	Connected Type	1	8.0
★764-9606	TLP-1512A-GY	¥33,615	¥41,500	Gray	1200 x 30 x 1465	Connected Type	1	8.0
★764-9614	TLP-1512A-OR	¥33,615	¥41,500	Orange	1200 x 30 x 1465	Connected Type	1	8.0

Height 1800 type

Order Unit: 1 Sheet | Factory direct | No freight charge | Excluding remote islands

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Color	W x D x H (mm)	Type	SPQ (sheet)	Weight (kg)
★764-9673	TLP-1806A-B	¥25,515	¥31,500	Blue	600 x 30 x 1765	Connected Type	1	7
★764-9681	TLP-1806A-GN	¥25,515	¥31,500	Green	600 x 30 x 1765	Connected Type	1	7
★764-9690	TLP-1806A-GY	¥25,515	¥31,500	Gray	600 x 30 x 1765	Connected Type	1	7
★764-9703	TLP-1806A-OR	¥25,515	¥31,500	Orange	600 x 30 x 1765	Connected Type	1	7
★764-9711	TLP-1809A-B	¥33,129	¥40,900	Blue	900 x 30 x 1765	Connected Type	1	8
★764-9720	TLP-1809A-GN	¥33,129	¥40,900	Green	900 x 30 x 1765	Connected Type	1	8
★764-9738	TLP-1809A-GY	¥33,129	¥40,900	Gray	900 x 30 x 1765	Connected Type	1	8
★764-9746	TLP-1809A-OR	¥33,129	¥40,900	Orange	900 x 30 x 1765	Connected Type	1	8
★764-9843	TLP-1812A-B	¥37,827	¥46,700	Blue	1200 x 30 x 1765	Connected Type	1	10
★764-9851	TLP-1812A-GN	¥37,827	¥46,700	Green	1200 x 30 x 1765	Connected Type	1	10
★764-9860	TLP-1812A-GY	¥37,827	¥46,700	Gray	1200 x 30 x 1765	Connected Type	1	10
★764-9878	TLP-1812A-OR	¥37,827	¥46,700	Orange	1200 x 30 x 1765	Connected Type	1	10

Contact us: 0120-509-849 <http://www.orange-book.com/>

Desks

PC Desks

Meeting Tables

Cafeteria Tables

Office Chairs

Meeting Chairs

Working Chairs

Anti-Static Stools

Benches

Umbrella Stands

Reception Room Furnitures

Hanger Racks

Partitions

Book Cabinets

Counters

Filing Cabinets

Catalog Cases

Map Cases·Letter Cases

Pamphlet Stands

File Wagons

Lockers

Shoes Boxes

Safes

Mailboxes

Key Boxes

Window Films

Interior Blinds

OA Floors

System Kitchens