

# 10-154 Standard Bookshelves (depth 400mm type)


For Bases, see p. 10-156/For Shelf Boards and Fall Prevention Metal Fittings, see p. 10-164 to 165 The number next to the logo mark indicates items in stock for each brand.

Office Furniture

- Desks
- PC Desks
- Meeting Tables
- Cafeteria Tables
- Office Chairs
- Meeting Chairs
- Working Chairs
- Anti-Static Stools
- Benches
- Umbrella Stands
- Reception Room Furnitures
- Hanger Racks
- Partitions
- Book Cabinets
- Counters
- Filing Cabinets
- Catalog Cases
- Map Cases/Letter Cases
- Pamphlet Stands
- File Wagons
- Lockers
- Shoes Boxes
- Safes
- Mailboxes
- Key Boxes
- Window Films
- Interior Blinds
- OA Floors
- System Kitchens

**Stock**  
38,650 Items

## Bookshelf

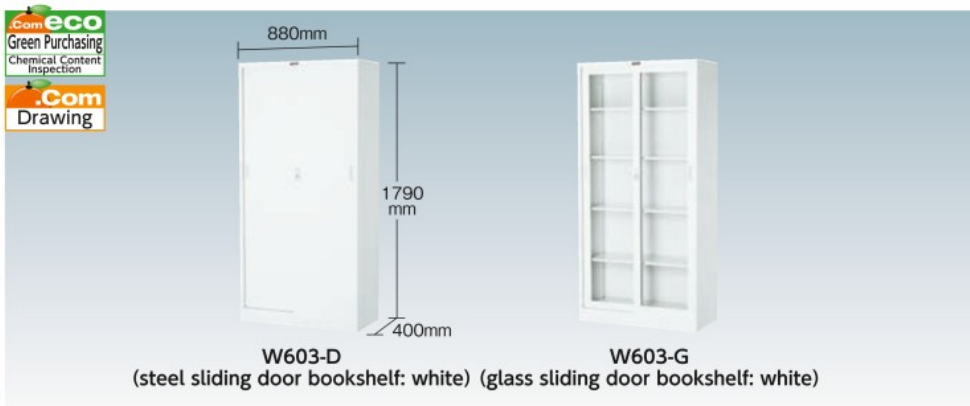

**Specs** •Compatible Type Fall Prevention Metal Fittings: TK/NTK Type

**Materials** •Steel

**Origin** •Japan

Order Unit: 1 Piece   Factory direct   Freight: ¥2,000   Excluding remote islands						TRUSCO NAKAYAMA CORPORATION					
Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Load Capacity (kg/piece)	Equal Load Capacity (kg/stage)	W x D x H (mm)	Installation Type	Accessories	Shelf Board Pitch (mm)	Additional Shelf Board	Weight (kg)
★448-9977	W603-D	¥43,323	¥46,800	200	60	880 x 400 x 1790	Designated for bottom placing	Cylinder Lock, Shelf Board x 4	30	W-33	51.9
★462-7580	W603-G	¥47,304	¥51,100	200	60	880 x 400 x 1790	Designated for bottom placing	Cylinder Lock, Shelf Board x 4	30	W-33	54.3

**Contact us: 0120-509-849** <http://www.orange-book.com/>

**Stock**  
38,650 Items

## Cabinet Bookshelf

**Features** •Keys are placed at 2 positions, which makes it possible to lock each row separately.

**Specs** •Color: White

**Materials** •Steel    **Origin** •Japan

**Warning**  
•Use 303B for the base.



Order Unit: 1 Piece   Factory direct   Freight: ¥3,000   Excluding remote islands						TRUSCO NAKAYAMA CORPORATION					
Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Load Capacity (kg/piece)	Equal Load Capacity (kg/stage)	W x D x H (mm)	Installation Type	Type	Drawer inner dimension (mm) W x D x H (effective height)	Weight (kg)	
★462-7628	WT2C35	¥63,134	¥68,200	200	50	880 x 400 x 880	Designated for bottom placing	3 stages 2 rows	370 x 320 x 264 (178)	43.9	
★462-7636	WT2C45	¥65,448	¥70,700	200	50	880 x 400 x 880	Designated for bottom placing	4 stages 2 rows	370 x 320 x 198 (178)	49.5	
★462-7644	WT2C65	¥70,725	¥76,400	200	50	880 x 400 x 880	Designated for bottom placing	6 stages 2 rows	370 x 320 x 132 (112)	56.7	

**Contact us: 0120-509-849** <http://www.orange-book.com/>

**Stock**  
38,650 Items

## One-sided Opening Type Combination Bookshelf

**Features** •With an all-lock key, all drawers can be locked with one key.

**Specs** •Color: White

**Materials** •Steel    **Origin** •Japan

**Warning**  
•Use 303B for the base.



Order Unit: 1 Piece   Factory direct   Freight: ¥3,000   Excluding remote islands						TRUSCO NAKAYAMA CORPORATION					
Order Code	Item No.	Price (per piece)	MSRP (per piece)	Max Load Capacity (kg/piece)	Equal Load Capacity (kg/stage)	W x D x H (mm)	Installation Type	Type	Drawer inner dimension (mm) W x D x H (effective height)	Weight (kg)	
★462-7652	WTCB333	¥43,971	¥47,500	200	50	880 x 400 x 880	Designated for bottom placing	3-stage one-sided opening	370 x 320 x 264 (178)	38.3	
★462-7661	WTCB343	¥46,101	¥49,800	200	50	880 x 400 x 880	Designated for bottom placing	4-stage one-sided opening	370 x 320 x 198 (178)	41.1	
★462-7679	WTCB363	¥47,952	¥51,800	200	50	880 x 400 x 880	Designated for bottom placing	6-stage one-sided opening	370 x 320 x 132 (112)	44.7	

**Contact us: 0120-509-849** <http://www.orange-book.com/>