

Prices displayed include 8% tax.

TRUSCO **Stock 38,650 Items**

Circle Cutter



TCC-125A



TCC-125CD



TCC-125KA (replacement blade)



- Features**
- Can be used over a wide range from wood to iron plate.
 - To accommodate a wide range of tools, the shank part adopts a two-step shape (10/13mm).
- Use**
- Drilling with large holes can be done with electric drill/drilling machines.
 - Work material: Thin iron plate (up to 1.5mm), veneer plate (up to 3mm), plastic, aluminum plate (up to 1.2mm), brass plate, acrylic (up to 6.3mm).
- Specs**
- Shaft type: Three chamfering
 - Compatible Model: Electric Drill, Drill Press
- Materials**
- Main body: S45C
 - Blade part: High-speed steel
 - Drill Part: High-Speed Steel
- Accessories**
- Hexagonal bar wrench for 3mm
 - Center drill (TCC-125CD) x 1
 - Replacement Blade (TCC-125KA) 1 Piece
- Origin**
- Japan



Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Machining Hole Diameter (mm)	Shaft Diameter (mm)	SPQ (piece)	Weight (g)
277-6090	TCC-125A	¥4,073	¥4,400	25 to 125	10, 13	6	172

Center Drill Origin •Japan

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Cutting Diameter (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
836-4768	TCC-125CD	¥1,944	¥2,100	5.5	48	5	7

Replacement Blade Origin •Taiwan

 
Order Unit: 1 Sheet

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Width (mm)	Total Length (mm)	Use	SPQ (sheet)	Weight (g)
277-6146	TCC-125KA	¥1,972	¥2,130	5	50	For Iron working	6	8
277-6154	TCC-125KB	¥1,972	¥2,130	5	50	For thin board/flexible material	6	8

Contact us:0120-509-849 <http://www.orange-book.com/>

STAR-M **Stock 290 Items**

Adjustable Circle Cutter



36

- Features**
- This machine can be used for a range of hole diameters from 30 to 120mm.
 - Optimum for drilling into wood and plaster boards.
 - Optimum for drilling into plaster boards as well if changed to the center drill for thin plates (attached).
 - Suitable for installing down light.
- Use**
- Work material: Wood, plaster board.
- Specs**
- Shaft type: Three grooves
 - Drillable depth: One side 25mm/Both sides 50mm
 - Compatible Model: Electric Drill
- Materials**
- Center drill (S55C)
 - Replacement blade: High-speed steel
- Accessories**
- Hexagonal wrench
 - Center drill for thin plate
- Origin**
- Taiwan



Order Unit: 1 Piece

STAR-M CORPORATION


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Machining Hole Diameter (mm)	Shaft Diameter (mm)	SPQ (piece)	Weight (g)
394-7696	36	¥4,223	¥4,210	30 to 120	10	6	380

Replacement blade (contains 2)

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Width (mm)	Total Length (mm)	Q'ty Per Set (sheet)	SPQ (set)	Weight (g/set)
392-7261	36-K	¥1,203	¥1,200	10	48	2	6	20

Contact us:0794-82-0200 <http://www.starminfo.com/>

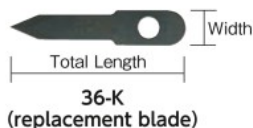

36-K (replacement blade)

Drills

Coated Carbide Drills

Carbide Drills

High Speed Steel Coated Drills

High Speed Steel Drills

Thin Shaft Drills

Spot Cutters

Taper Shank Drills

Hex Shank Ironsmith Drills

Drill Sets

Drill Cases

Step Drills

Cutters for Magnetic Cutting Unit

Hole Saws

Core Drills

Concrete Drills

Drills

Bits, Cutters for Wood

For other cutting tools, see p. 1-805 to 1006