

The number next to the logo mark indicates items in stock for each brand.

Magnetic
Stands

Magnetic
Bases

Magnetic
Blocks

Magnetic
Chucks

Electro
magnetic
Holders

Magnet
Sheets

Magnetic
Materials

Magnetic
Holders

Magnet
Holders
for Welding

Magnet
Hands

Magnet
Choose
Articles

Magnetizing
Equipments,
Demagnetizing
Equipments

Lifting
Magnets




Stock 38,650 Items


Magnetic Bar



- Features** •With waterproof structure, can be used in liquid (water, oil etc.).
Use •Recovery for metals contained in raw materials such as powders, fluid or liquid and granules.
Specs •Tapped Hole: M6/Depth 8mm (both ends)
 •Working Temperature Limit: 80° C
Materials •Magnet: Anisotropic Ferrite Magnet
 •Exterior part: Stainless Steel (SUS316L)
 •Surface finish: #400 Buff finish
Origin •Japan

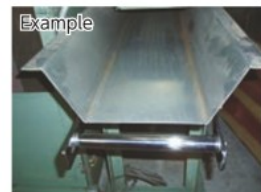

TRUSCO NAKAYAMA CORPORATION

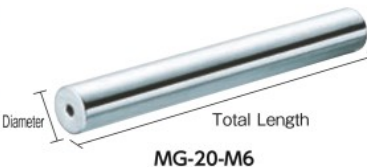

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Surface Magnetic Flux Density (T)	Diameter (mm)	Total Length (mm)	SPQ (piece)	Weight (kg)
229-4028	MG-10-M6	¥ 9,072	¥ 9,800	0.3	25	100	1	0.30
229-4036	MG-15-M6	¥ 9,998	¥ 10,800	0.3	25	150	1	0.40
229-4044	MG-20-M6	¥ 10,923	¥ 11,800	0.3	25	200	1	0.50
229-4052	MG-25-M6	¥ 13,330	¥ 14,400	0.3	25	250	1	0.58
229-4061	MG-30-M6	¥ 16,663	¥ 18,000	0.3	25	300	1	0.68
266-3465	MG-35-M6	¥ 18,885	¥ 20,400	0.3	25	350	1	0.85
266-3473	MG-40-M6	¥ 21,569	¥ 23,300	0.3	25	400	1	0.95
266-3481	MG-45-M6	¥ 24,531	¥ 26,500	0.3	25	450	1	1.00
266-3490	MG-50-M6	¥ 25,920	¥ 28,000	0.3	25	500	1	1.20
266-3511	MG-60-M6	¥ 31,937	¥ 34,500	0.3	25	600	1	1.35

Contact us:0120-509-849 <http://www.orange-book.com/>




Stock 38,650 Items

Sanitary Magnetic Bar



- Features** •Can also be installed in liquid as it is waterproof.
Use •For collection of metals contained in raw materials such as powders, fluids, and granules and collection of stainless steel wear powder (SUS304.316) generated during production processes.
Specs •Tapped Hole: M6/Depth 8mm (both ends)
 •Working Temperature Limit: 80° C
Materials •Magnet: Neodymium Rare Earth Magnet
 •Exterior part: Stainless Steel (SUS316L)
 •Surface finish: #400 Buff finish
Origin •Japan

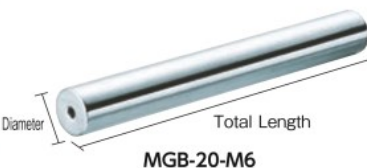

SPQ: 1 Piece

Powerful Type

SPQ: 1 Piece

Order Unit: 1 Piece (Price revision date: Jan. 2016) TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Surface Magnetic Flux Density (T)	Diameter (mm)	Total Length (mm)	Weight (kg)	Order Code	Item No.	Price (per piece)	MSRP (per piece)	Surface Magnetic Flux Density (T)	Diameter (mm)	Total Length (mm)	Weight (kg)
266-3384	MGB-10-M6	¥ 31,937	¥ 34,500	1.0	25	100	0.30	470-2701	MGB-H10-M6	¥ 40,731	¥ 44,000	1.2	25	100	0.30
266-3392	MGB-15-M6	¥ 45,221	¥ 48,850	1.0	25	150	0.40	470-2719	MGB-H15-M6	¥ 56,469	¥ 61,000	1.2	25	150	0.40
266-3406	MGB-20-M6	¥ 55,108	¥ 59,530	1.0	25	200	0.50	470-2727	MGB-H20-M6	¥ 73,131	¥ 79,000	1.2	25	200	0.50
266-3414	MGB-25-M6	¥ 64,430	¥ 69,600	1.0	25	250	0.58	470-2735	MGB-H25-M6	¥ 88,869	¥ 96,000	1.2	25	250	0.58
266-3422	MGB-30-M6	¥ 74,890	¥ 80,900	1.0	25	300	0.68	470-2743	MGB-H30-M6	¥ 104,606	¥ 113,000	1.2	25	300	0.68
266-3431	MGB-35-M6	¥ 82,657	¥ 89,290	1.0	25	350	0.85								
266-3449	MGB-40-M6	¥ 91,313	¥ 98,640	1.0	25	400	0.95								
266-3457	MGB-50-M6	¥ 114,927	¥ 124,150	1.0	25	500	1.30								

Contact us:0120-509-849 <http://www.orange-book.com/>

Made to order For inquiries related to special orders of magnetic bars

TRUSCO NAKAYAMA CORPORATION

Modifications such as lengths and upward holes to suit customer needs can be made on special order. Refer to the following details.

Magnetic Bar Special Production Compatibility Table

1	Length	Units of 1mm from 70mm to 2000mm
2	Tapped hole	None, one-side only, hole size up to M16, depth, up to M24 with male thread
3	Others	Grip, handle, bracket mounting, etc.

Sanitary Magnetic Bar Special Production Compatibility Table

1	Length	Units of 1mm from 70mm to 2000mm
2	Tapped hole	None, one-side only, hole size up to M16, depth, up to M24 with male thread
3	Outer Diameter	φ22 φ20 Other, please inquire.
4	Working temperature limit	120° C 150° C 240° C(not applicable to powerful type)
5	Others	Grip, handle, bracket mounting, etc.



①With handle, ferule, and tip processing *Attach a simple hand-drawn sketch when making an inquiry.



②③ Modified length, with mounting bracket

