
 
 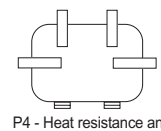


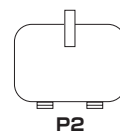


Specifications

Levers and hinges of each model size

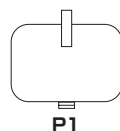

Regular style (Standard) (Heat resistance model : same as the below dimensions)

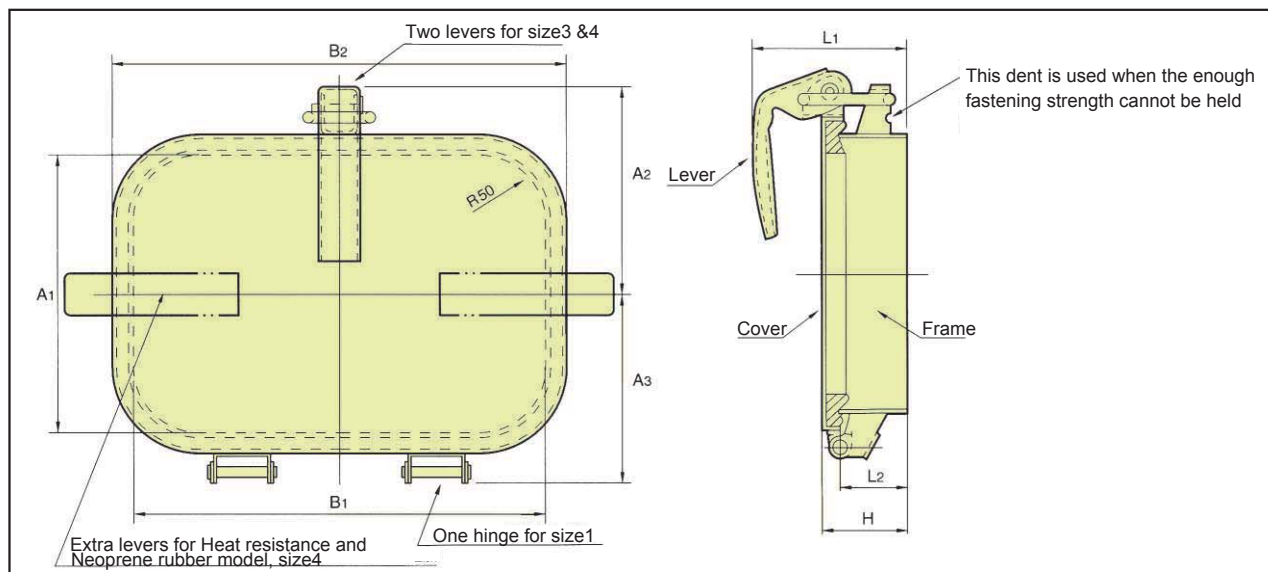


(mm)

Model No.	Frame body		Cover				Lever			Weight (kg)
	A ₁	B ₁	A ₂	A ₃	B ₂	H	L ₁	L ₂	Qty.	
CMD-P1 (-Q1) (-R1)	130	200	115	103	230	63	121	48	1	2.0
CMD-P2 (-Q2) (-R2)	200	300	150	138	330	63	121	48	1	3.0
CMD-P3 (-Q3) (-R3)	350	500	225	213	530	63	121	48	2	6.0
※ CMD-P4 (-R4)	500	600	300	288	630	88	146	73	2 (4)	11.0

※ () Size 4 of Heat resistance and Neoprene rubber model

High neck style (Standard) (Heat resistance model : same as the below dimensions)

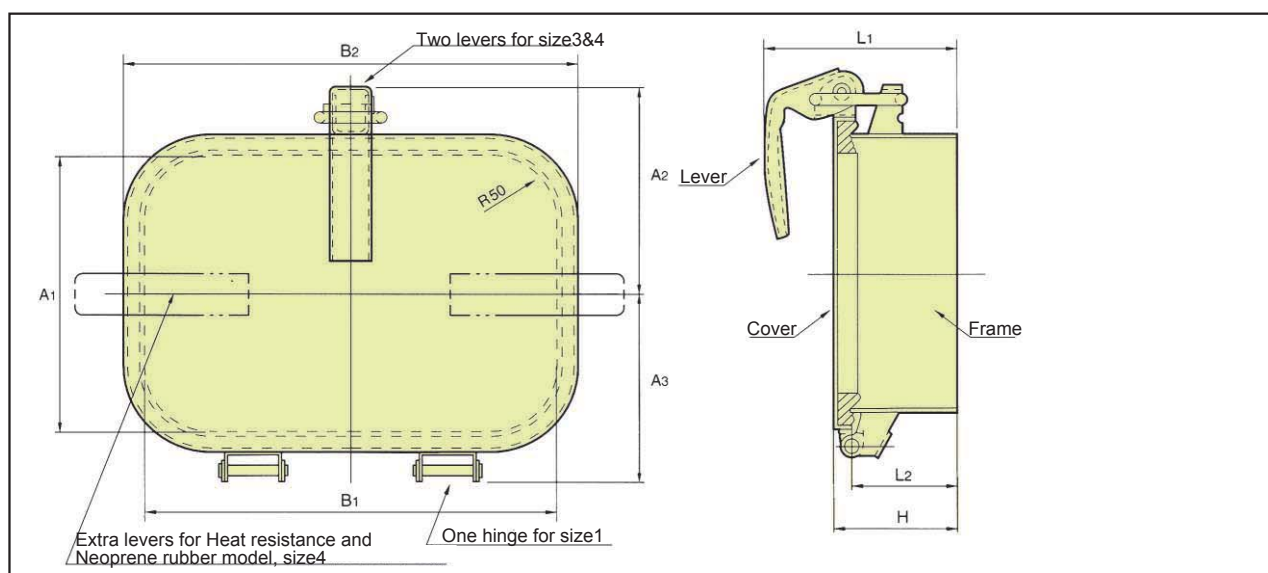

(mm)

Model No.	Frame body		Cover				Lever			Weight (kg)
	A ₁	B ₁	A ₂	A ₃	B ₂	H	L ₁	L ₂	数	
CMD-P1-H (-Q1-H) (-R1-H)	130	200	115	103	230	113	171	98	1	2.7
CMD-P2-H (-Q2-H) (-R2-H)	200	300	150	138	330	113	171	98	1	4.2
CMD-P3-H (-Q3-H) (-R3-H)	350	500	225	213	530	113	171	98	2	8.0
CMD-P4-H (-R4-H)	500	600	300	288	630	113	171	98	2 (4)	12.4

※ () Size 4 of Heat resistance and Neoprene rubber model