 
 
 



Specifications

Levers and hinges of each model size



Transparent windowed

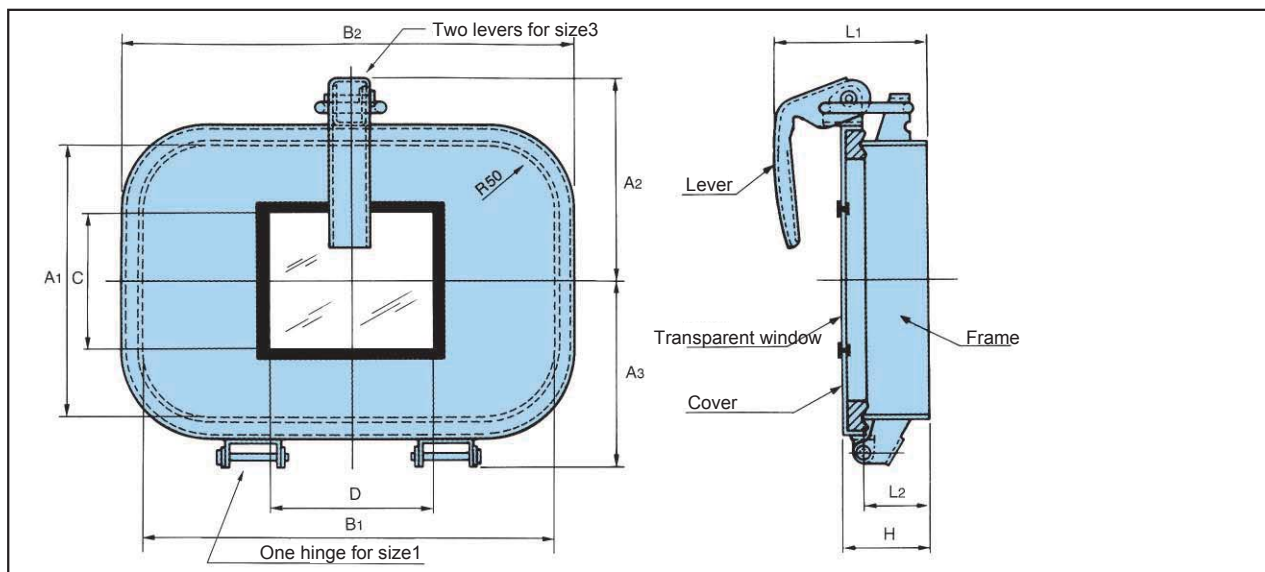


(mm)

Model No.	Frame body		Cover				Lever			Transparent window		Weight (kg)
	A ₁	B ₁	A ₂	A ₃	B ₂	H	L ₁	L ₂	数	C	D	
CMD-P1-T (-Q1-T) (-R1-T)	130	200	115	103	230	63 (113)	121 (171)	48 (98)	1	70	85	2.0 (2.7)
CMD-P2-T (-Q2-T) (-R2-T)	200	300	150	138	330	63 (113)	121 (171)	48 (98)	1	85	130	3.0 (4.2)
CMD-P3-T (-Q3-T) (-R3-T)	350	500	225	213	530	63 (113)	121 (171)	48 (98)	2	150	220	6.0 (8.0)

※ () High-neck style

Withstanding pressure type

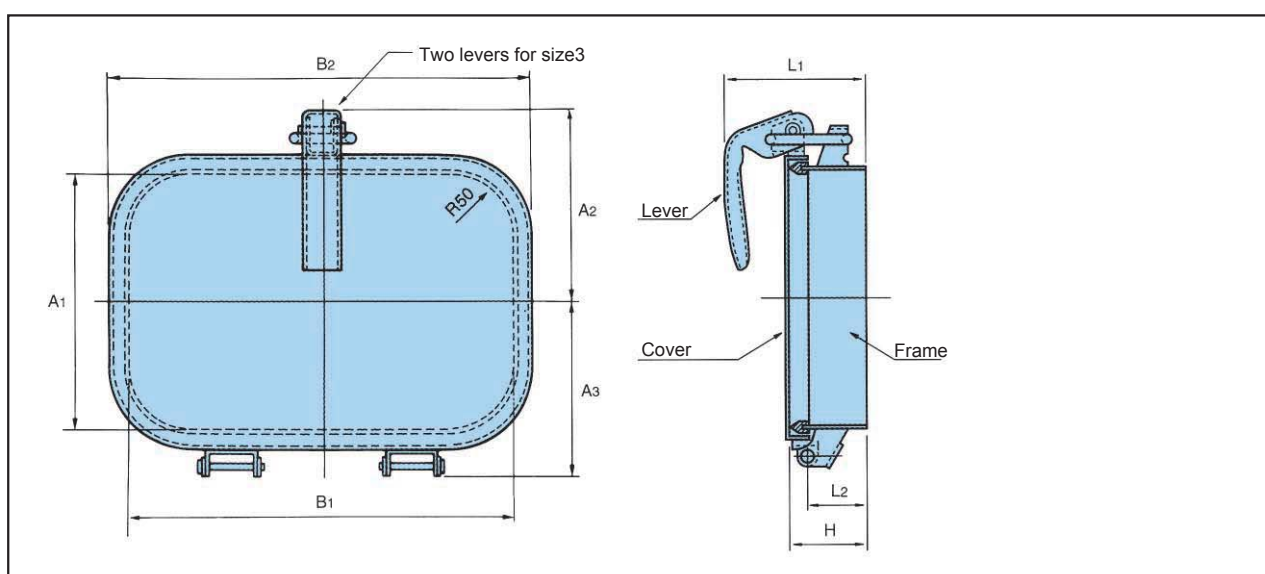

(mm)

Model No.	Frame body		Cover				Lever			Weight (kg)
	A ₁	B ₁	A ₂	A ₃	B ₂	H	L ₁	L ₂	数	
CMD-P2-V (-P2-H-V)	200	300	151	139	333	65 (115)	121 (171)	48 (98)	1	5.1 (6.8)
CMD-P3-V (-P3-H-V)	350	500	226	214	533	65 (115)	121 (171)	48 (98)	2	11.2 (14.0)

※ () High-neck style