 
 



P1




P2



 
P3



P4

 
P4 - Heat resistance and
Neoprene rubber model

Residual Prevention Type

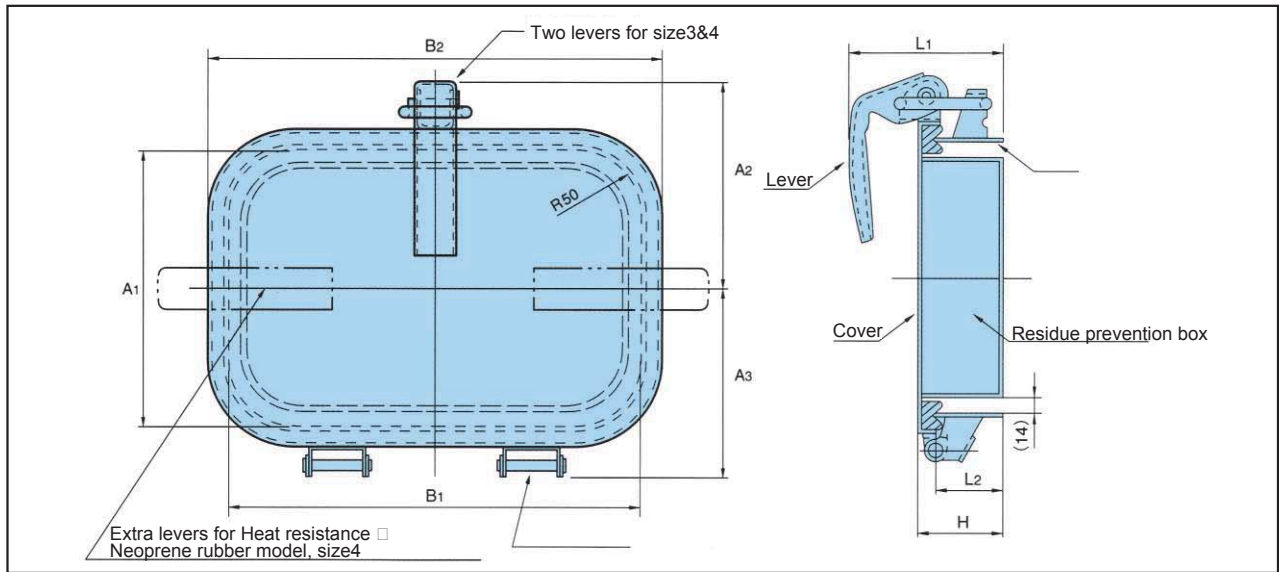


(mm)

Model No.	Frame body		Cover				Lever			Weight (kg)
	A ₁	B ₁	A ₂	A ₃	B ₂	H	L ₁	L ₂	数	
CMD-P1-B (-Q1-B) (-R1-B)	130	200	115	103	230	63	121	48	1	3.0
CMD-P2-B (-Q2-B) (-R2-B)	200	300	150	138	330	63	121	48	1	4.8
CMD-P3-B (-Q3-B) (-R3-B)	350	500	225	213	530	63	121	48	2	10.5
CMD-P4-B	500	600	300	288	630	88	146	73	2 (4)	19.3

※ () Only size 4 of Neoprene rubber model

Flanged door type

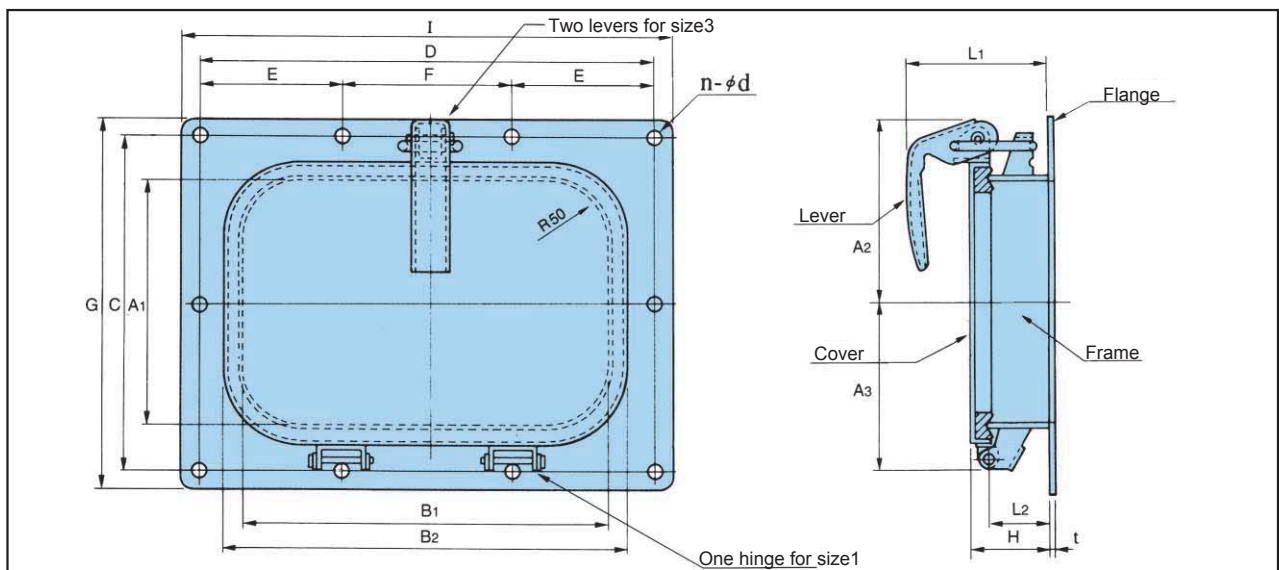

(mm)

Model No.	Frame body		Cover				Lever			Flange									Weight (kg)
	A ₁	B ₁	A ₂	A ₃	B ₂	H	L ₁	L ₂	数	C	D	E	F	G	I	t	n	d	
CMD-P1-F	130	200	115	103	230	63	121	48	1	180	250	0	0	210	280	3.2	4	10	3.0
CMD-P2-F	200	300	150	138	330	63	121	48	1	2×135	370	115	140	300	400	3.2	10	12	5.0
CMD-P3-F	350	500	225	213	530	63	121	48	2	2×205	560	180	200	450	600	4.5	10	14	9.0

※ Not includ bolts, nuts and gaskets for fixing flange, but gasket for the cover