 
 


Specifications

 
Levers and hinges of each model size



P1




P2



P3

Safty Grid Insert Without Roller Catch Fixing (1-G)

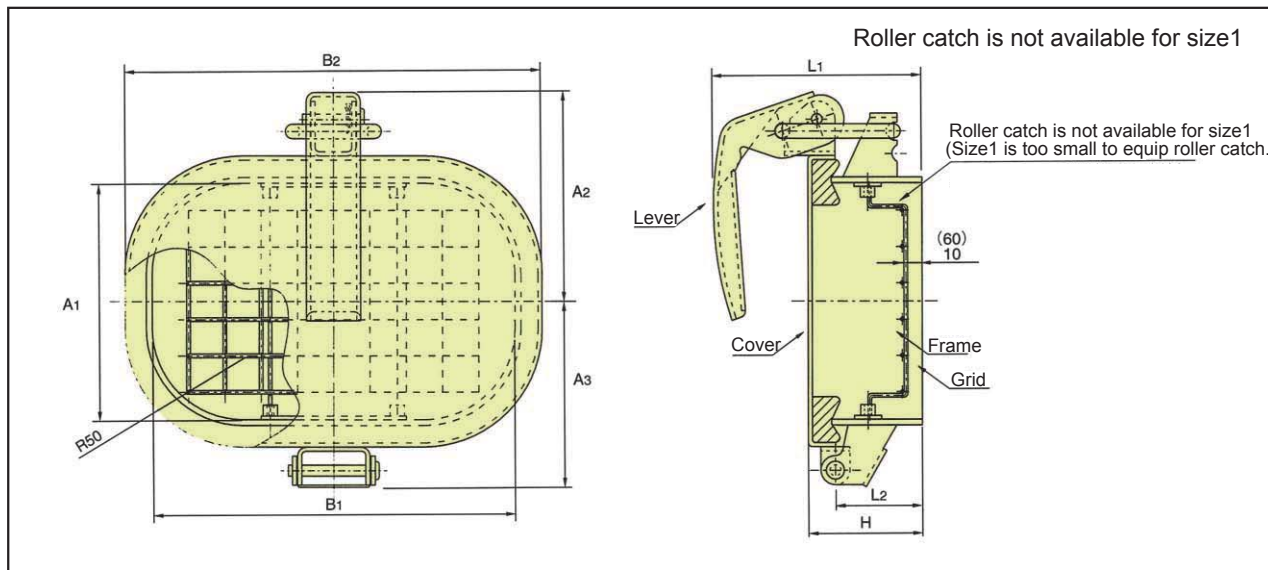


(mm)

Model No.	Frame body		Cover				Lever			Weight (kg)
	A ₁	B ₁	A ₂	A ₃	B ₂	H	L ₁	L ₂	数	
CMD-P1-G (-Q1-G) (-R1-G)	130	200	115	103	230	63 (113)	121 (171)	48 (98)	1	2.0 (2.7)

※ () High-neck style

Safty Grid Insert Roller Catch Fixing (2,3-G)

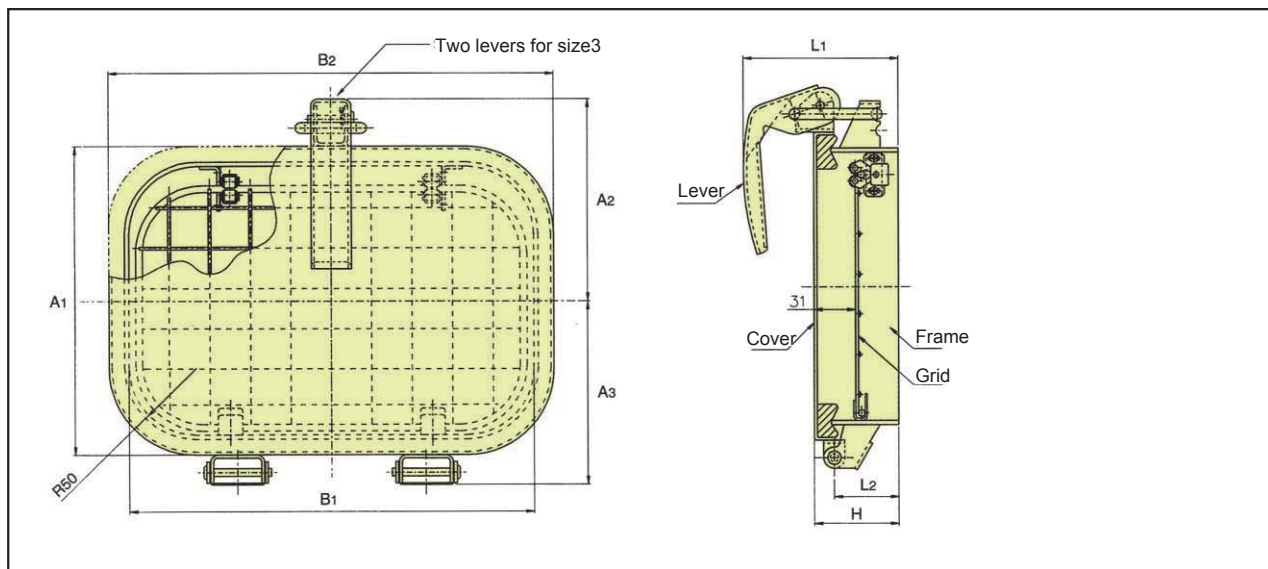

(mm)

Model No.	Frame body		Cover				Lever			Weight (kg)
	A ₁	B ₁	A ₂	A ₃	B ₂	H	L ₁	L ₂	数	
CMD-P2-G (-Q2-G) (-R2-G)	200	300	150	138	330	63 (113)	121 (171)	48 (98)	1	3.3 (4.5)
CMD-P3-G (-Q3-G) (-R3-G)	350	500	225	213	530	63 (113)	121 (171)	48 (98)	2	6.6 (8.6)

※ () High-neck style