



Levers and hinges of each model size

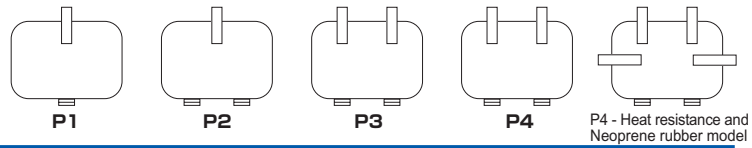

Safty Grid Insert Bolt Fixing (1-G)

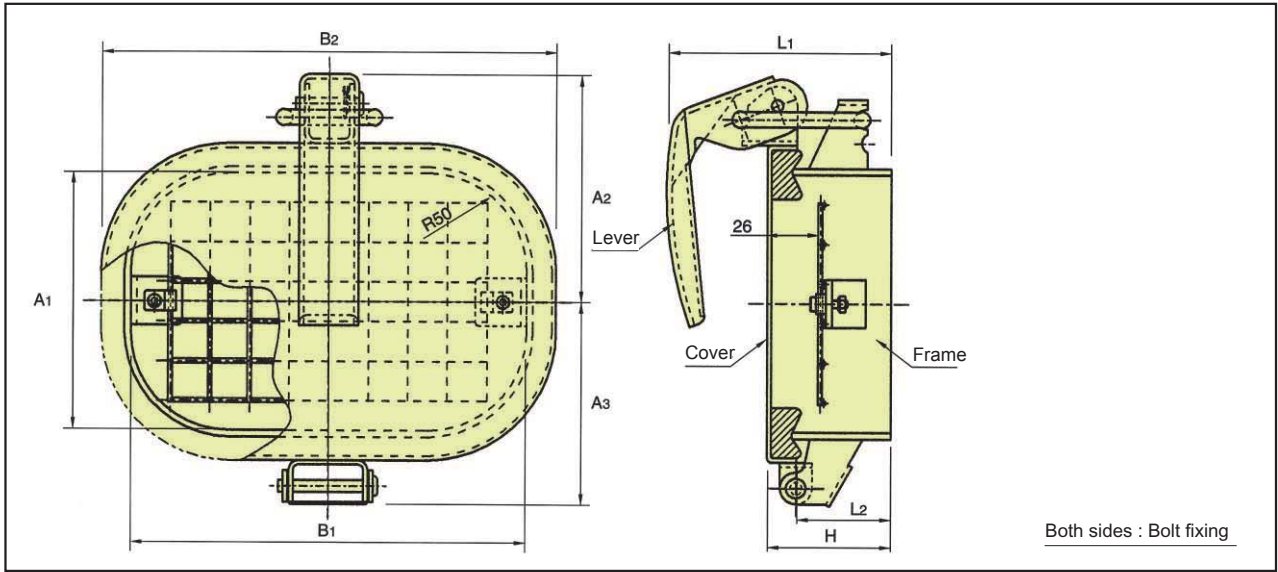


(mm)

Model No.	Frame body		Cover				Lever			Weight (kg)
	A ₁	B ₁	A ₂	A ₃	B ₂	H	L ₁	L ₂	数	
CMD-P1-GK (-Q1-GK) (-R1-GK)	130	200	115	103	230	63 (113)	121 (171)	48 (98)	1	2.0 (2.7)

※ () High-neck style

Safty Grid Insert Bolt Fixing (2,3&4-G)

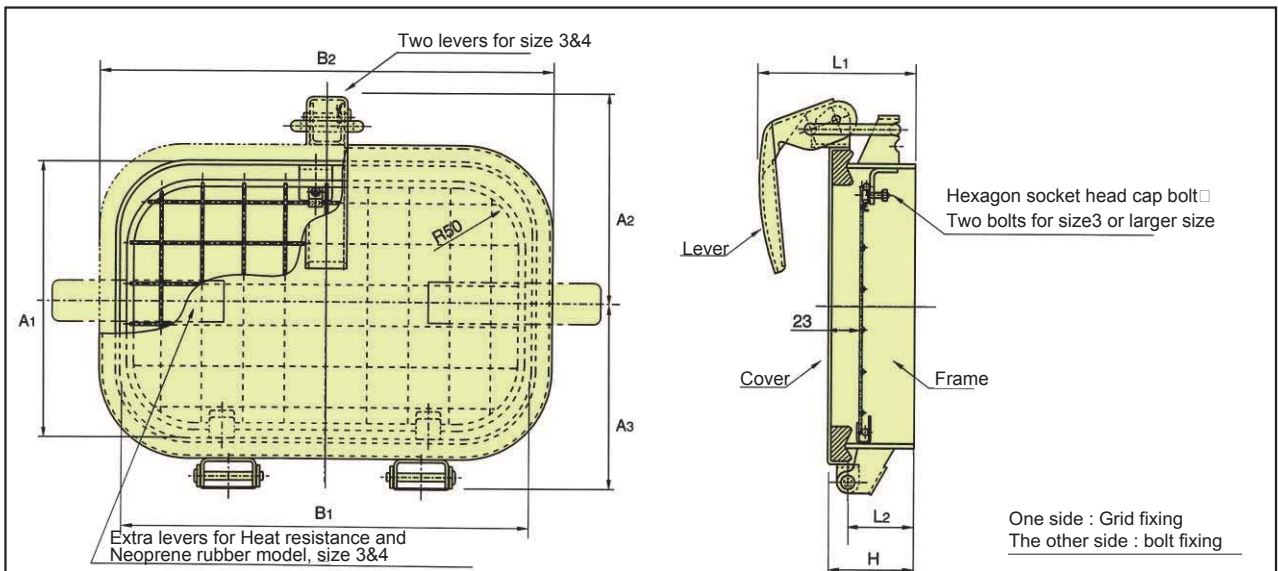

(mm)

Model No.	Frame body		Cover				Lever			Weight (kg)
	A ₁	B ₁	A ₂	A ₃	B ₂	H	L ₁	L ₂	数	
CMD-P2-GK (-Q2-GK) (-R2-GK)	200	300	150	138	330	63 (113)	121 (171)	48 (98)	1	3.3 (4.5)
CMD-P3-GK (-Q3-GK) (-R3-GK)	350	500	225	213	530	63 (113)	121 (171)	48 (98)	2	6.6 (8.6)
CMD-P4-GK (-Q4-GK) (-R4-GK)	500	600	300	288	630	88 (113)	146 (171)	73 (98)	2 [4]	12.0 (13.4)

※ () High-neck style

※ [] Size 4 of Heat resistance and Neoprene rubber model