

# シャフトホルダ 精密鑄造品

—フランジ型・T型—



Order  
注文例

型式(Type・軸径)  
**SCJHF25**



型式(Type・軸径)  
**SCJK30**

## ■フランジ型



CAD 2D 3D

Type	M 材質	S 表面処理	A 付属品
SCJHF	アルミ合金	白アルマイト	六角穴付ボルト1本 (SUS)

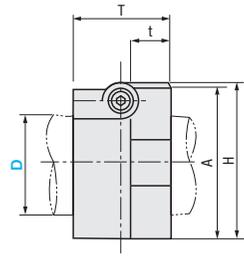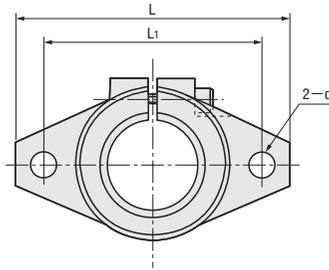



型式		L	T	t	H	A	L1	d	締付ボルト M	質量 (g)
Type	軸径D									
SCJHF	10	43	10	5	24	20	32	5.5	M4	13
	12	47	13	7	28	25	36			20
	13									27
	16	50	16	8	31	28	40	7	M5	40
	20	60	20		37	34	48			60
	25	70	25	10	42	40	56	9	M6	110
	30	80	30	12	50	46	64			12
	35	92	35	14	58	50	72	12	M8	510
	40	102	40	16	67	56	80			M10
50	122	50	19	83	70	96	14	M12		

## ■T型



CAD 2D 3D

Type	M 材質	S 表面処理	A 付属品
SCJK	アルミ合金	白アルマイト	六角穴付ボルト1本 (SUS)

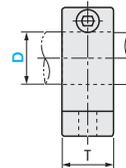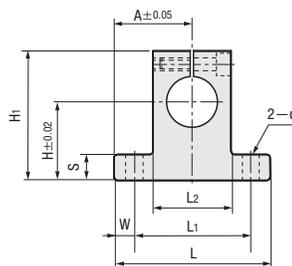

型式		H	L	H1	T	L1	d	S	A	L2	W	締付ボルト M	質量 (g)
Type	軸径D												
SCJK	8	20	42	32.8	14	32	5.5	6	21	18	5	M4	24
	10			37.5						20			30
	12			37.5						20			30
	13	23	48	44	16	38	6.6	8	24	25	7.5	M5	40
	16												31
	20	35	70	60	24	56	9	12	35	38	7	M6	130
	25	42	84	70	28	64			42	44	10		180
	30	50	98	85	32	74	11	15	49	50	12	M8	270
	35	60	114	96	36	90			57	60			12
	40	70	126	120	40	100	14	18	63	74	13	M12	750