

ナイロン管用クイック継手

—ミリタイプ—

選定手順①～③より型式・数値を選択の上、ご注文ください。



Order
注文例

型式 (①Type・②No.・③管ねじ)

VMC04M03T


型式 (Type・No.)

VU10M

■コネクタ(ミリタイプ)



VMC□M□T

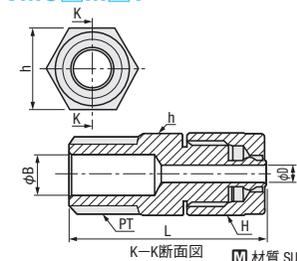


K-K断面図 材質 SUS304

■ユニオン(ミリタイプ)



VU□M

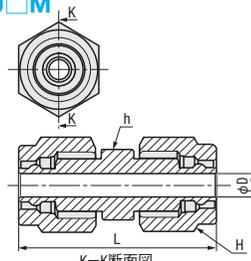

K-K断面図 材質 SUS304

型式			適用ナイロン 管内径(mm)	D	P (PT)	L	B	対辺	
①Type	②No.	③管ねじ						本体h	ナットH
VMC	04M	03T	4	1.5	1/8	28	5	11	12
		06T			1/4	32	7	14	
	06M	03T	6	3	1/8	30	5	12	14
		06T			1/4	34.5	7	14	
		10T			3/8	35.5	9	17	
		15T			1/2	40.5	12	22	
	08M	03T	8	4	1/8	30	5	12	14
		06T			1/4	34.5	7	14	
		10T			3/8	35.5	9	17	
		15T			1/2	40.5	12	22	
	10M	06T	10	5.5	1/4	35.5	7	14	17
		10T			3/8	36.5	9	17	
15T		1/2			41.5	12	22		
12M	06T	12	7	1/4	36	7	17	19	
	10T			3/8	37	9	17		
	15T			1/2	72	12	22		

型式		D	L	対辺	
Type	No.			本体h	ナットH
VU	10M	5.5	34.5	14	14
	12M	7	39	19	19