


AFB series - Exhaust valve

Order expression and Operation specification

CHELIC PNEUMATIC





How to order

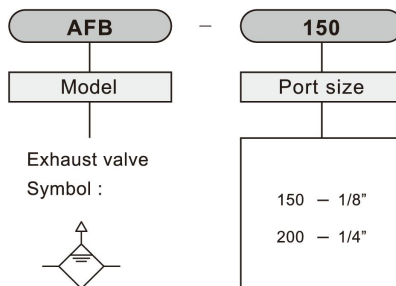

Specification

Item	Model	AFB-150	AFB-200
Fluid		Air	
Port size	Rc	1/8"	1/4"
Proof pressure	kgf/cm ² (kpa)	9.2 (920)	
Ambient and fluid temperature	°C	5~60°C	
Recommended lubricants		First class lubricant (ISO - VG32) or equivalent	
Weight	kg	0.1	0.2
Material	Body	Aluminum die-casted	
	Bowl	Polycarbonate	

AFB Standard

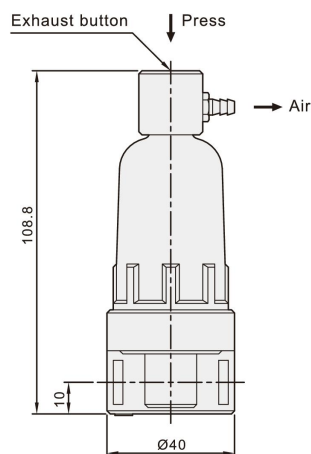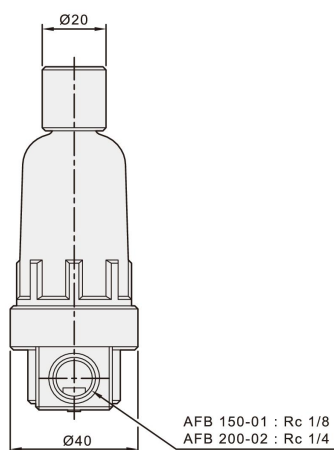

NC
F.R.L.
Combinations

NFC
F.R.L.
Combinations

PSN-10
30,41
Pressure switch

NFR
Filter
regulator

MFR
Mist filter
regulator

MFRD
Micro mist
filter regulator

NF
Air filter

MF
Mist
separator

MFD
Micro mist
separator

NR
Regulator

ARX
Regulator

NL
Lubricator

N series
Mounting
bracket

DM
Large-
sized filter

ER
Precision
regulator

PG/AFB
NDV/AD