

 



MV series Mechanical valve - MV 100

Operation specification and Order expression

CHELIC PNEUMATIC

Internal structure

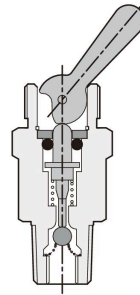

V : Toggle lever type

P : Press button type

MV
Mechanical
Valve

HVL
Hand-operated
Valve

HVM
Hand-operated
Valve

HVT
Mini type
Hand-operated
Valve

QE
Quick exhaust
Valve

FVA
Foot
Valve

FVS
Foot
Valve

Specification

Item	Model	MV-100-□-V	MV-100-□-P
Fluid		Air	
Pressure range	Kgf/cm ² (Kpa)	0 ~ 9 (0 ~ 900)	
Range of service temperature	°C	0 ~ 60 °C	
Number of positions ports		2 positions	
Valve functions		2 ports or 3 ports	
Orifice	mm ² (CV)	1.8 (0.1)	
Connection port	Rc(PT)	M5	
Weight	g	30g	

How to order

