



Vacuum pad / Bellows type

External dimension
PBK series / Vertical connection with fitting

CHELIC PNEUMATIC

◉ Ø10 , Ø15

◉ Ø20 ~ Ø30

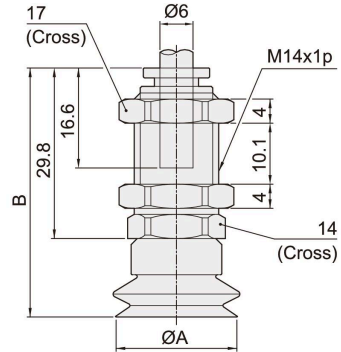
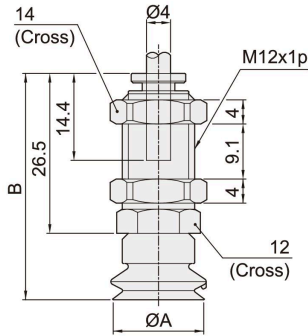


Pad type	Item	Pad dia. A	Whole length B	Size of PU tube
Circle pad	PBK-10	Ø10	36	PU tube Ø4 x Ø2.5
	PBK-15	Ø15	37.5	

Pad type	Item	Pad dia. A	Whole length B	Size of PU tube
Circle pad	PBK-20	Ø20	42.8	PU tube Ø6 x Ø4
	PBK-30	Ø30	47.8	

◉ Ø40 , Ø50

◉ Ø60 , Ø80

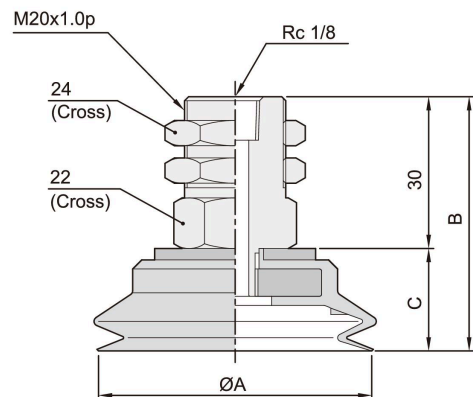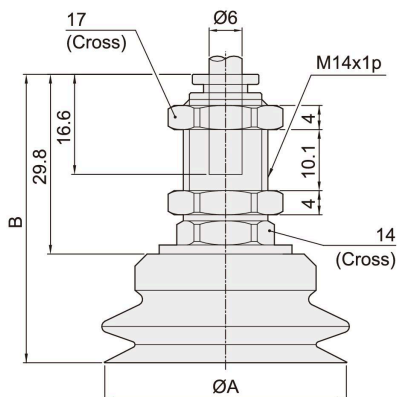

Pad type	Item	Pad dia. A	Whole length B	Size of PU tube
Circle pad	PBK-40	Ø40	47.8	PU tube Ø6 x Ø4
	PBK-50	Ø50	49.8	

Pad type	Item	Pad dia. A	Whole length B	C	Size of PU tube
Circle pad	PBK-60	Ø60	52.5	22.5	Rc 1/8"
	PBK-80	Ø80	53.5	23.5	

PA

Pad / Standard type

PAF

Pad / Vertical connection

PAK

Pad / Vertical connection With fitting

PAT

Pad / Horizontal connection

PAFS

Pad / Vertical spring type

PATS

Pad / Horizontal spring type

PB

Pad / Bellows type

PBF

Pad / Vertical connection

PBK

Pad / Vertical connection With fitting

PBT

Pad / Horizontal connection

PBFS

Pad / Vertical spring type

PBTS

Pad / Horizontal spring type