



蝸輪減速機E系列 WORM REDUCER E SERIES


E系列 Series

■特點：

體積小、重量輕，任意安裝方向，可附加腳座，安裝方式多變化，型號從40#至135#。

FEATURES：

Small size, light weight, free installation direction, with base kits, various installation methods, Model No.: 40# to 135#

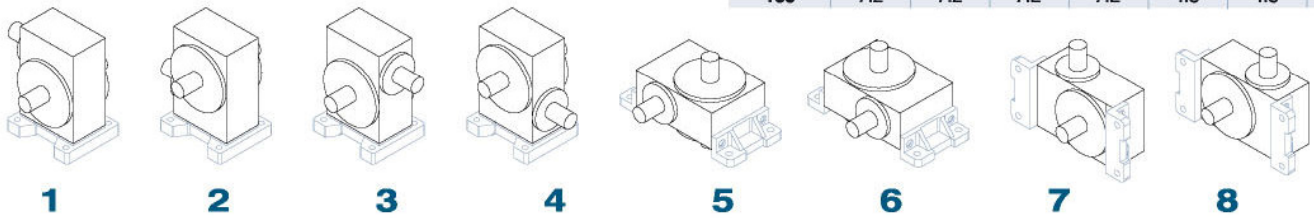

■油量表 (OIL CAPACITIES)：

單位：公升(UNIT：L)

機型 型號	E EM	EO, EOM	EOV	EOVM	TW	TM	VOF VOFM
40	0.2	0.2					
50	0.4	0.4	0.4	0.4	0.3	0.3	
60	0.5	0.5	0.5	0.5	0.4	0.4	
70	0.8	0.8	0.8	0.8	0.9	0.9	0.6
80	1.2	1.2	1.2	1.2	1.2	1.2	1.0
100	2.6	2.6	2.6	2.6	2.6	2.6	1.6
120	4.5	4.5	4.5	4.5	3.9	3.9	2.4
135	7.2	7.2	7.2	7.2	4.8	4.8	3.5

■單段蝸輪減速機E系列分解系統圖

Disassembly diagram of single-stage worm-gear reducer E series

NO.	名稱	PARTS NAME	NO.	名稱	PARTS NAME
1	出力軸	Output shaft	18	滾錐軸承	Taper roller bearing
2	雙圓鍵	Key	19	非石棉墊片	
3	蝸輪	Worm wheel	20	油封	Oil seal
4	滾珠軸承	Ball bearing	21	入力軸蓋(左)	Input shaft cover (L)
5	滾珠軸承	Ball bearing	22	六角承高頭螺絲	Hex. Screw
6	O形環	O-ring	23	入力軸蓋(右)	Input shaft cover (R)
7	非石棉墊片		24	六角承高頭螺絲	Hex. Screw
8	油封	Oil seal	25	馬達盤	Motor flange
9	出力軸蓋	Output shaft cover	26	油封	Oil seal
10	六角承高頭螺絲	Hex. Screw	27	單圓鍵	Key
11	蝸輪箱	Worm wheel	28	馬達	Motor
12	L型腳座	Base kits (L)	29	六角承高頭螺絲	Hex. Screw
13	六角承高頭螺絲	Hex. Screw	30	注油栓	Oil plug
14	H型腳座	Base kits (H)	31	沉頭油栓	Plug
15	六角承高頭螺絲	Hex. Screw	32	洩油栓	Drain plug
16	蝸桿(入力軸)	Worm shaft (Input shaft)	33	油鏡	Oil gauge
17	滾錐軸承	Taper roller bearing	17,18	60#以下滾珠軸承	Ball bearing of 60# below

