


2085


オス・メス45°エルボ
Male female 45° elbow
External pipe/Internal pipe

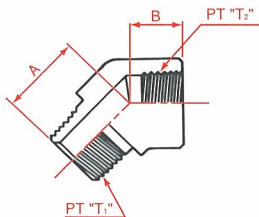

呼称サイズ	T ₁	T ₂	A	B
02	1/8	1/8	19	19
02-04	1/8	1/4	19	19
04	1/4	1/4	22	22
04-02	1/4	1/8	22	22
04-06	1/4	3/8	22	22
06	3/8	3/8	26	27
06-04	3/8	1/4	26	27
06-08	3/8	1/2	26	27
08	1/2	1/2	30	30
08-06	1/2	3/8	30	30
08-12	1/2	3/4	30	30
12	3/4	3/4	34	34
12-08	3/4	1/2	34	34
12-16	3/4	1	34	34
16	1	1	41	40
16-12	1	3/4	41	40

2088


オス・メス90°エルボ
Male female 90° elbow
External pipe/Internal pipe

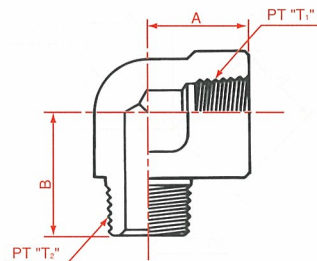

呼称サイズ	T ₁	T ₂	A	B
02	1/8	1/8	21	25
02-04	1/8	1/4	21	25
04-02	1/4	1/8	21	25
04	1/4	1/4	21	27
04-06	1/4	3/8	25	30
06-04	3/8	1/4	30	36
06	3/8	3/8	25	28
06-08	3/8	1/2	30	36
08-06	1/2	3/8	35	43
08	1/2	1/2	29	35
08-12	1/2	3/4	35	43
12-08	3/4	1/2	40	50
12	3/4	3/4	33	40
16	1	1	38	48

SKL-35

オス・メス回転90°エルボ
Male female 90° elbow
External pipe/Internal pipe

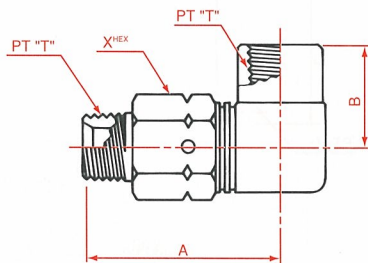

呼称サイズ	T ₁	A	B	X
04	1/4	53	18	19
06	3/8	58	20	22
08	1/2	69	26	27
12	3/4	79	41	36