

SUS-ER TYPE



There are some non-conforming products.



Fixed wheel





Plate type



Stainless steel



SUS-ER-100N

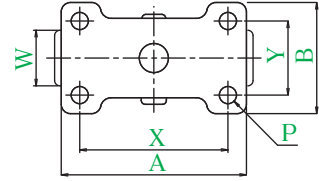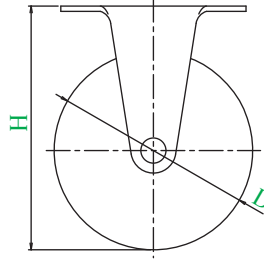

● Description of product number

SUS - ER - 100 N

Bracket type Wheel diameter Wheel type

Bracket = Stainless steel

Product number	Wheels								
		Wheel diameter D(mm)	Wheel width W(mm)	Mounting height H(mm)	Mounting base A × B(mm)	Mounting dimensions X × Y(mm)	Hole diameter P(mm)	Allowance load daN(kgf)	Wheel weight (g)
SUS-ER-50	R Rubber wheel	50	20	65	70 × 42	56 × 28	6.5	30(30.6)	120
	N Nylon wheel		21					40(40.8)	95
	UR Urethane wheel with nylon wheel assembly		20					38(38.8)	100
	EL Elastomer wheel		25					25(25.5)	95
SUS-ER-65	RH Rubber wheel	65	21	82	70 × 42	56 × 28	6.5	30(30.6)	165
	N Nylon wheel							40(40.8)	120
	UR Urethane wheel with nylon wheel assembly							40(40.8)	130
	EL Elastomer wheel							30(30.6)	150
SUS-ER-75	RH Rubber wheel	75	21	92	70 × 42	56 × 28	6.5	40(40.8)	200
	N Nylon wheel							50(51.0)	130
	UR Urethane wheel with nylon wheel assembly							45(45.9)	140
	EL Elastomer wheel							30(30.6)	150
SUS-ER-100	RH Rubber wheel	100	25	122	100 × 58	82 × 40	8.8	50(51.0)	460
	NR Rubber wheel with nylon wheel assembly		27					60(61.2)	380
	N Nylon wheel		25					60(61.2)	305
	UR Urethane wheel with nylon wheel assembly		28					60(61.2)	335
	EL Elastomer wheel		27					50(51.0)	325

- Conductive rubber wheel can be manufactured.
- The antistatic urethane wheel having wheel diameter of φ 100 can be manufactured.

Wheel in use

Refer to P163 for detailed specifications.



R RH NR N UR EL
 Rubber wheel Rubber wheel with nylon wheel assembly Nylon wheel Urethane wheel with nylon wheel assembly Elastomer wheel