

Conveyor Wheels / Rubber and Urethane Lined Wheels for Conveyors

Conveyor Wheels

Machined Wheels
HMH
HMHS

Pressed Wheels
HPH

Type	Material	Surface Treatment
HPH	Steel	Trivalent Chromate
HMH	Steel	Chromate
HMHS	Stainless Steel	-

Conveyor Wheels (Pressed Wheels)

Part Number		W	D	d	d1	B	Allowable Load (N)	Unit Price		Volume Discount Rate	
Type	No.							1 ~ 4 pc(s).	5-30 pcs.		
HPH	25	16	25.4	6.2	10	10	294				
	36	25	36	6.5	11	10	147				
	38	25	38	6.5	11	12	196				
	50	28	50	8.2	13	20	245				

For orders larger than indicated quantity, please request a quotation.

Conveyor Wheels (Machined Wheels)

Part Number		W	d	d1	B	Allowable Load (N)	HMH		HMHS	
Type	D						Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
HMH HMHS	*25	16	6.2	12	9	294	1 ~ 4 pc(s).	5-30 pcs.	1 ~ 4 pc(s).	5-30 pcs.
	36	25	6.2	14	9	392			-	-
	50	20	8.2	19	14.5	784			-	-
	50	20A	10.2	19	14.5	980			-	-
	50	32	8.2	19	14.5	980			-	-

* HMHS applies only to D25.

kgf=Nx0.101972


For orders larger than indicated quantity, please request a quotation.

Ordering Example


Part Number	W
HPH25	16
HMHS25	16

Rubber and Urethane Lined Wheels for Conveyors

Milled Rollers
HGH
HUH
HMHU
HMHSU

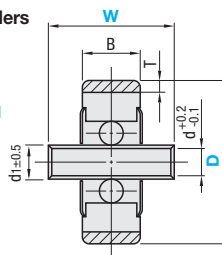

Press Formed Rollers
HPHU

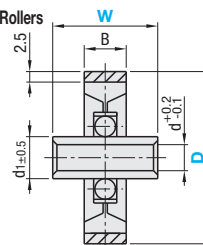

Type	Roller Type	Material	Surface Treatment	Material of Roller Surface
HGH	Milled Roller	Steel	Trivalent Chromate	Nitrile Rubber (White) (Shore A60)
HUH				Polyurethane (Blue) (Shore A90)
HMHU				Polyurethane (Black) (Shore A90)
HMHSU		Stainless Steel	-	
HPHU	Press Formed Rollers	Steel	Trivalent Chromate	

Part Number		W	d	d1	B	T	Allowable Load (N)				HGH		HUH		HMHU		HMHSU		HPHU	
Type	D						HGH	HUH	HMHU	HMHSU	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
HGH HUH	25	16	6.2	14	9	4	196	294	-	-	-	-	-	-	-	-	-	-	-	-
	14	28	8.2																	
	60	20	12	19	13	5	490	490												
HMHU HMHSU HPHU	30	16	6.2	12	10	2.5	-	-	294	147	-	-	-	-	-	-	-	-	-	-

kgf=Nx0.101972

For orders larger than indicated quantity, please request a quotation.

Ordering Example

Part Number	W
HGH40	25