

Metal Washer



Hardened Type, Standard Grade / Precision Grade, T Dimension Selectable



RoHS 10

Part Number		Material		Surface Treatment	Hardness
Standard Grade	Precision Grade				
WSSBH	WASBH	S45C (WSSBH)	S45C Equivalent (WASBH)	Black Oxide	45-50HRC
WSSMH	WASMH	S45C Equivalent		Electroless Nickel Plating	
WSSSH	WASSH	SUS440C or 13Cr stainless		-	

- ① Standard Grade is S45C Equivalent.
- ② Depending on thickness and length, S45C Hardened Type may be less than 45HRC.
- ③ Stainless Steel Hardened Type (WSSSH, WASSH) may be discolored by hardening.

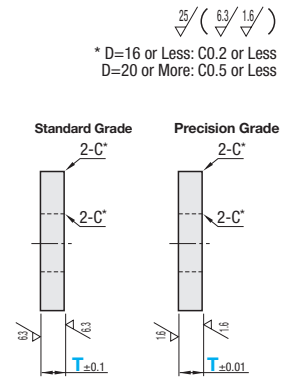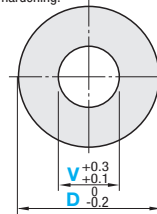

* D=16 or Less: C0.2 or Less
D=20 or More: C0.5 or Less

Part Number	Type	D	V Selection	T Selection	Unit Price					
					Standard Grade			Precision Grade		
					WSSBH	WSSMH	WSSSH	WASBH	WASMH	WASSH
Standard Grade	4	2		1 2						
	5	2 3		1 2						
	6	2 3 4		1 2						
	8	2 3 4 5 6		1 2 3 5						
	10	2 3 4 5 6 8		1 2 3 5						
	12	3 4 5 6 8 10		1 2 3 5						
	WSSBH	13	4 5 6 8 10		1 2 3 5					
	WSSMH	14	4 5 6 8 10		1 2 3 5					
	WSSSH	15	4 5 6 8 10 12		1 2 3 5					
	Precision Grade	16	4 5 6 8 10 12		1 2 3 5					
WASBH		20	4 5 6 8 10 12 15 16		2 3 5					
WASMH		25	6 8 10 12 15 16 20		2 3 5					
WASSH		30	8 10 12 15 16 20 25		2 3 5					
		35	10 12 15 16 20 25		3 5 10					
		40	10 12 15 16 20 25 30		3 5 10					
		50	10 12 15 16 20 25 30		3 5 10					
		60	15 16 20 25 30		3 5 10					



Ordering Example

Part Number - V - T
WASBH14 - 10 - 5