



Shim (Split Type)

Standard / Configurable

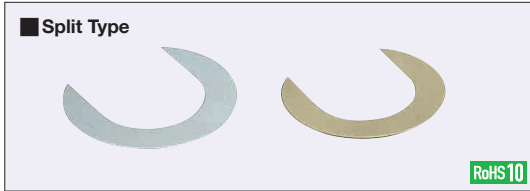

RoHS 10

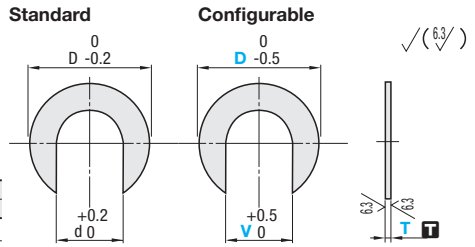

Part Number		Material	Hardness	Thickness (T) Tolerance					
Standard	Configurable			0.05	0.1	0.2	0.3	0.5	1.0
CIMW	CIMWF	SPCC Equivalent	-	-	±0.03	±0.04	±0.06	±0.11	
CIMWB	CIMWBF	Brass (C2801P or C2680P)	-	±0.005	±0.02	±0.03	±0.04	±0.05	±0.08
CIMWS	CIMWSF								
PACK-CIMWS	-	SUS304H	370~430HV	±0.005	±0.02	±0.03	±0.035	±0.04	±0.05

Standard

Part Number Type	No.	T	d	D	Unit Price		
					CIMW	CIMWB	CIMWS
CIMW CIMWB CIMWS	6	(0.05)	6.5	12			
	8	For CIMWB and CIMWS only	8.5	15			
	10		10.5	20			
	12	0.1	13	25			
	16	0.2	17	30			
	20	0.3	21	35			
	24	0.5	25	40			
30	1.0	31	50				

Standard, Sold by the package 1 package contains 10 pieces.

Part Number Type	No.	T Selection	d	D	Unit Price			
					T0.05	T0.1-0.3	T0.5	T1.0
PACK-CIMWS	6		6.5	12				
	8	0.05	8.5	15				
	10	0.1	10.5	20				
	12	0.2	13	25				
	16	0.3	17	30				
	20	0.5	21	35				
	24	1.0	25	40				
30		31	50					



Ordering Example
Part Number - T
CIMW10 - 0.2



Ordering Example
Part Number - T
PACK-CIMWS12 - 0.1

Please specify number of packages to order.
Quantity 1 means one package.

Configurable

Part Number	T Selection	V 0.5mm Increment	D 1mm Increment	Unit Price													
				CIMWF			CIMWBF				CIMWSF						
				T0.1-0.3	T0.5	T1.0	T0.05	T0.1-0.3	T0.5	T1.0	T0.05	T0.1-0.3	T0.5	T1.0			
CIMWF CIMWBF CIMWSF	(0.05) <small>For CIMWBF and CIMWSF only</small>	3~31	10~20														
	0.1		21~50														
	0.2																
	0.3																
	0.5																
	1.0																

V ≤ D-4



Ordering Example
Part Number - T - V - D
CIMWF - 0.2 - 8.5 - 20