


Low Small Head Cap Screws / Small Head Cap Screws

■ In Stock. Available at reduced price for 10 or above.




RoHS10

Product Name	Type	Material	Surface Treatment	Hardness	Strength Class	Small Head							
Low Small Head Cap Screws	KBB	SCM435	Black Oxide	22~32HRC	8.8 Equivalent	M	A	Low			Small Head		
	KBBS	SUS304 Equivalent	-	-	A2-50 Equivalent	3	4.5	2	2	(1.5)	3	2.5	(1.5)
Small Head Cap Screws	SBB	SCM435	Black Oxide	22~32HRC	8.8 Equivalent	4	5.5	2.8	2.5	(2)	4	3	(2)
	SBBSS	SUS304 Equivalent	-	-	A2-70 Equivalent	5	7	3.5	3	(2.5)	5	4	(2.5)
						6	8.5	4	4	(3)	6	5	(3)
						8	10	5	5	(4)	8	6	(4)
						10	13	6	6	(4.5)	10	8	(5)
						12	16	7	8	(5)	12	10	(6)


KBB
KBBS

(Low Small Head Cap Screws)

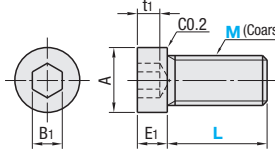

SBB
SBBSS

(Small Head Cap Screws)

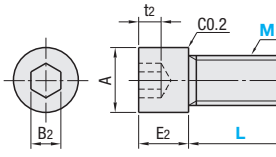


⚠ Low Small Head Cap Screws and Small Head Cap Screws are fully threaded. ⚠ The head is not knurled.

Type	M (Coarse)	Part Number	KBB		KBBS		SBB		SBBSS	
			Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
KBB KBBS SBB SBBSS	3	5 6 8 10								
	4	6 8 10 12 16 20								
	5	8 10 12 16 20								
	6	8 10 12 16 20								
	8	10 12 16								
	10	16 20 25 30 35								
	12	20 25 30								

Ordering Example Part Number
KBBSS6-20


■ Configurable Length Small Head Cap Screws




RoHS10

Type	Material	Surface Treatment	Hardness	Strength Class
Low Small Head Type	S45C	Black Oxide	22~32HRC	8.8 Equivalent
Small Head Type		Electroless Nickel Plating		
		SUS304 Equivalent	-	-

Low Small Head Type

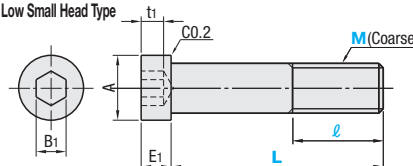

Small Head Type

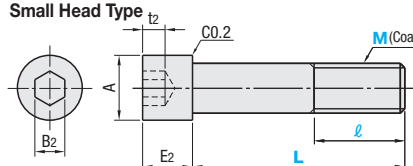

⚠ The head is not knurled.

Type	M (Coarse)	1mm Increment		l	A	E1	E2	B1	B2	t1	t2
		Low Small Head	Small Head								
FKBB FKBBM FKBBS FSBB FSBBM FSBBSS	4	10~50	10~100	10~40 ⚠ l ≤ L	5.5	2.8	4	2.5	3	(2)	(2)
	5	10~60	10~100		7	3.5	5	3	4	(2.5)	(2.5)
	6	10~80	10~150		8.5	4	6	4	5	(3)	(3)
	8	10~90	10~150		10	5	8	5	6	(4)	(4)

M	Unit Price											
	L10~50						L51~Lmax.					
	FKBB	FKBBM	FKBBS	FSBB	FSBBM	FSBBSS	FKBB	FKBBM	FKBBS	FSBB	FSBBM	FSBBSS
4												
5												
6												
8												

Ordering Example Part Number - L - l
FKBB4 - 40 - 36