

# Screws with Through Hole

Extra Low Head Cap Screws, Low Head Cap Screws, Hex Socket, Hex, Full Thread

Use in vacuum equipment or vacuum container where air in the tapped hole is required to be removed.

**Extra Low Head Cap Screws with Through Hole**

RoHS10

**CBASG**

M Material: SUS304 Equivalent

**Low Head Cap Screws with Through Hole**

RoHS10

**CBAST**

M Material: SUS304 Equivalent

**Hex Socket Head Cap Screws with Through Hole**

**CBAS CBASTN**

M Material: SUS304 Equivalent CBAS  
Pure Titanium Class 2 CBASTN

Part Number	M x P	A	E	B	d	Unit Price	Volume Discount Rate
Type M-L						1 - 49 pc(s)	50 - 100 pcs.
<b>CBASG 3- 6</b>	3						
8	3	6	1.3	1.5	1.2		
10	x						
12	0.5						
<b>CBASG 4- 6</b>	4						
8	x	8	1.5	2	1.5		
10	0.7						
12							
16							
<b>CBASG 5-10</b>	5						
12	x	9	1.5	3	1.5		
16	0.8						
20							
<b>CBASG 6-10</b>	6						
12	x	10	1.5	3	2		
16	1.0						
20							
30							

Part Number	M x P	A	E	B	d	Unit Price	Volume Discount Rate
Type M-L						1 - 49 pc(s)	50 - 100 pcs.
<b>CBAST 3- 6</b>	3						
8	x	5.5	2	2	1.2		
10	0.5						
12							
16							
<b>CBAST 4- 6</b>	4						
8	x	7	2.8	2.5	1.5		
10	0.7						
12							
16							
20							
<b>CBAST 5-10</b>	5						
12	x	8.5	3.5	3	1.5		
16	0.8						
20							
25							
<b>CBAST 6-10</b>	6						
12	x	10	4	4	2		
16	1.0						
20							
30							

Part Number	M x P	A	E	B	d	CBAS		CBASTN	
						Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
Type M-L						1 - 49 pc(s)	50 - 100 pcs.	1 - 49 pc(s)	50 - 100 pcs.
<b>CBAS CBASTN 3- 6</b>	3								
8	x	5.5	3	2.5	1.2				
10	0.5								
12									
15									
<b>CBAS CBASTN 4- 6</b>	4								
8	x	7	4	3	1.5				
10	0.7								
12									
15									
20									
<b>CBAS CBASTN 5- 8</b>	5								
10	x	8.5	5	4	1.5				
12	0.8								
15									
20									
<b>CBAS CBASTN 6- 8</b>	6								
10	x	10	6	5	2				
12	1.0								
15									
20									
25									
30									
<b>CBAS CBASTN 8-12</b>	8								
15	x	13	8	6	2				
20	1.25								
25									
30									
<b>CBAS CBASTN 10-15</b>	10								
20	x	16	10	8	2				
25	1.5								
30									

For orders larger than indicated quantity, please check with WOS.

For orders larger than indicated quantity, please check with WOS.

**Hex Screws with Through Hole**

RoHS10

**RCBAS**

M Material: SUS304 Equivalent

**Fully Threaded Screws with Through Hole**

RoHS10

**MCBAS**


M Material: SUS304 Equivalent

Part Number	M x P	A	E	d	Unit Price	Volume Discount Rate
Type M-L					1 - 49 pc(s)	50 - 100 pcs.
<b>RCBAS 3- 6</b>	3					
8	x	5.5	2	1.2		
10	0.5					
12						
16						
<b>RCBAS 4- 6</b>	4					
8	x	7	2.8	1.5		
10	0.7					
12						
15						
20						
<b>RCBAS 5- 8</b>	5					
10	x	8	3.5	2		
12	0.8					
16						
20						
25						
<b>RCBAS 6- 8</b>	6					
10	x	10	4	2		
12	1.0					
16						
20						
25						
30						
<b>RCBAS 8-15</b>	8					
20	x	13	5.5	2		
25	1.25					
30						

Part Number	M x P	B	t	d	Unit Price	Volume Discount Rate
Type M-L					1 - 49 pc(s)	50 - 100 pcs.
<b>MCBAS 3- 8</b>	3					
10	x	1.5	0.7	1.2		
15	0.5					
<b>MCBAS 4-12</b>	4					
15	x	2.0	2.2	1.5		
20	0.7					
25						
30						
<b>MCBAS 5-15</b>	5					
20	x	2.5	2.8	1.5		
25	0.8					
30						
<b>MCBAS 6-15</b>	6					
20	x	3.0	3.0	2		
25	1.0					
30						
<b>MCBAS 8-20</b>	8					
25	x	4.0	4.0	2		
30	1.25					
35						

No specifications available for sizes with no prices shown.

For orders larger than indicated quantity, please check with WOS.

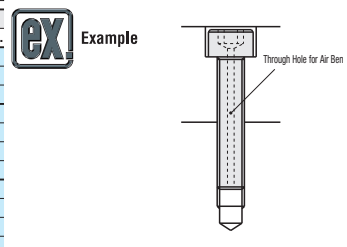

Preference	Tensile Breaking Load (N)	
	Extra Low Head / Low Head	
M3	1440	
M5	4630	

\* The above data are for reference, not guaranteed.



Ordering Example

Part Number  
CBAS5-10  
RCBAS4-6  
MCBAS8-30