


# Long Knurled Head Screws / Stepped Knurled Head Screws

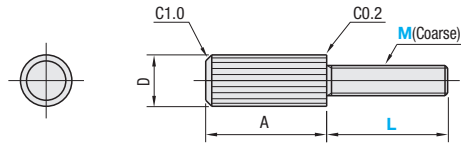

Type	Material	Surface Treatment
LRLM	SCM435	Electroless Nickel Plating
LRLB	SUS303	-




Part Number	Type	M (Coarse)	L	D	A	LRLM		LRLB		
						Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	
							1 ~ 9 pc(s)	10 ~ 30 pcs	1 ~ 9 pc(s)	10 ~ 30 pcs
	LRLM	3	6 10	5.5	10					
	LRLB	4	6 10 16	7	16					
		5	10 16 20	8.5	20					
		6	10 16 20 25 30	10	30					
		8	20 25 30	13	36					
		10	20 25 30 40	16	40					

Ordering Example: Part Number - L - L  
LRLB3 - L 10



Type	Material	Surface Treatment
LRLMF	SCM435	Electroless Nickel Plating
LRLBS, LRLBF	SUS303	-

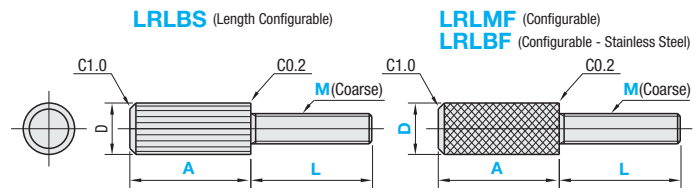

**Configurable Length**

Part Number	Type	M (Coarse)	A	L	D	Unit Price
			1mm Increment	1mm Increment		
	LRLBS	3	10-40	6-40	5.5	
		4		6-40	7	
		5		10-50	8.5	
		6		10-50	10	

Ordering Example: Part Number - A - L - D  
LRLBS3 - A15 - L10  
LRLBF5 - A10 - L35 - D12

**Configurable**

Part Number	Type	M (Coarse)	A	L	D	Unit Price
			1mm Increment	1mm Increment	1mm Increment	
	LRLMF	3	10-60	6-40	5-10	
	LRLBF	4		6-40	5-10	
		5		10-50	10-25	
		6		10-50	10-25	

Alterations: Part Number - A - L - D - (RS-MC)  
LRLMF4 - A10 - L30 - D8 - MC3

**Alteration** Undercut

**Code** RS

**Spec.** Adds an undercut under the head  
 Applicable only to LRLBS, LRLMF and LRLBF  
 For M3, 6 ≤ L ≤ 21  
 For M4, 7 ≤ L ≤ 21


M	e	f
3	1.5	2.1-2.3
4	1.5	2.9-3.1
5	1.5	3.6-3.9
6	2	4.4-4.6

**Alteration** Tapping


**Code** MC

**Spec.** Adds a tapped hole for the screw head.  
 Applicable only to LRLBS, LRLMF and LRLBF  
 2 ≤ D - MC

M	MC (Selection Range)
3	3
4	3, 4
5	3, 4, 5
6	3, 4, 5, 6

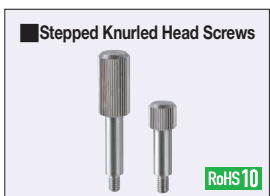

LRLBD

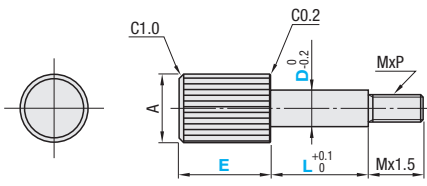

Material: SUS303

Part Number	Type	D	E	L	A	MxP	Unit Price
			1mm Increment	1mm Increment			
	LRLBD	4	8-30	10-30	5.5	2.5x0.45	
		5			7.0	3x0.5	
		6			8.5	4x0.7	
		8			10.0	6x1.0	

Ordering Example: Part Number - E - L  
LRLBD4 - E8 - L10