


Knurled Knobs with Hex Socket / Checker Knurled Knobs / Knurled Knobs - Captured

Knurled Knobs with Hex Socket



RoHS 10

Type		Material	Surface Treatment
Standard	Stepped		
NOBR	NKBR	SUM24L	Buff Polished + Chrome Plating
NOOSR	NKOSR	SUS303	Brushed Finish

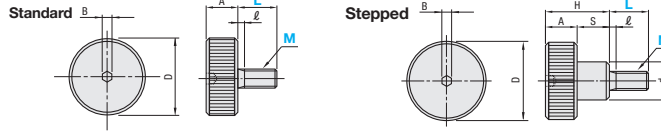

Part Number		M (Coarse)	L Selection					A	D	d	H	S	ℓ	B	Unit Price	
Type			6	10	16	20	NOBR NKBR								NOOSR NKOSR	
Standard	Stepped	3	6	10			12	12	6	17	5	1	2			
NOBR	NKBR	4	6	10	16		17	16	8	23	6	1.2	2.5			
NOOSR	NKOSR	5	10	16	20		26	20	10	33.5	7.5	1.4	3			


Ordering Example Part Number - L
NOBR3 - 6

Checker Knurled Knobs



RoHS 10

Type		Shape	Material	Surface Treatment
Standard	Stepped			
NOBX	NKBX	Threaded	SUM24L	Buff Polished + Chrome Plating
NOOSX	NKOSX			
NOMSX	NKMSX			

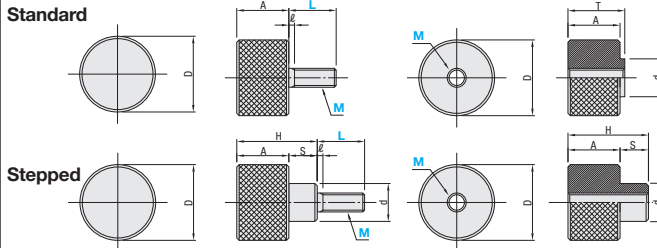

Part Number		M (Coarse)	L Selection (Threaded Type only)				A	D	d	T	H	S	ℓ	Unit Price		
Type			6	10	16	20								NOBX NKBX	NOOSX NKOSX	NOMSX NKMSX
Standard	Stepped	3	6	10		10	12	6	11	15	5	1				
NOBX	NKBX	4	6	10	16	11	16	8	12	17	6	1.2				
NOOSX	NKOSX	5	10	16	20	12	20	10	13	19.5	7.5	1.4				


Knurled Knobs - Captured



RoHS 10

Type		Material	Surface Treatment
Standard	Stepped		
NOBD	NKBD	SUM24L	Buff Polished + Chrome Plating
NOOSD	NKOSD	SUS303	Brushed Finish


There may be uneven chrome plating around the threads.

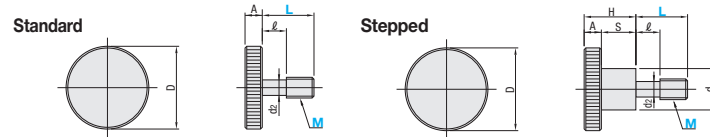

Part Number		M (Coarse)	L	D	d	A	H	S	ℓ	d2	Unit Price		
Type											NOBD NKBD	NOOSD NKOSD	
Standard	Stepped	3	10	12	6	2.5	7.5	5	6	2			
			10						5				
			15	16	8	3.5	9.5	6	10	3			
		5	10						4				
			15	20	10	4	11.5	7.5	9	3.8			
			20						14				
		6	15						7				
			20	24	12	5	15	10	12	4.5			
			30						22				
		8	20						10				
			30	30	16	6	18	12	20	6			



Example

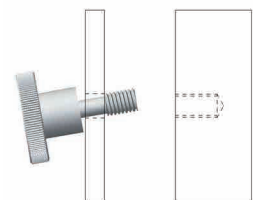

Ordering Example Part Number - L
NOBX3 - 6
NOOSD5 - 10