
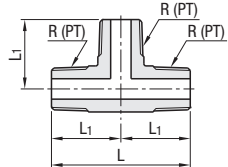


**Male Tees**


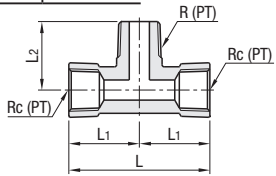
Type	Material
SJSMT	C3771

RoHS10

**Female/Male Tees**


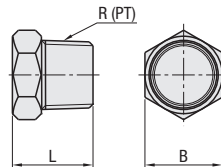
Type	Material
SJSXT	C3771

RoHS10

**Plugs**


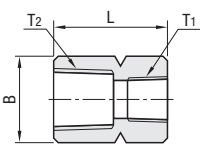
Type	Material
SJSPG	C3604

RoHS10

**Reducing Hex Sockets**

Type	Material
SJSFSD	C3604


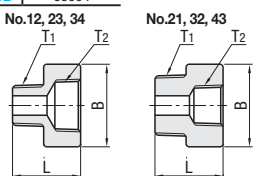



RoHS10

**Reducing Female/Male Sockets**

Type	Material
SJSXSD	C3604


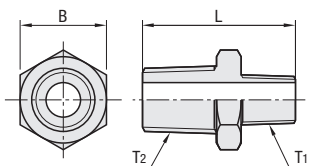
No.12, 23, 34      No.21, 32, 43

RoHS10

**Reducing Hex Nipples**


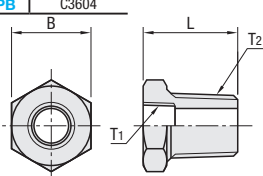
Type	Material
SJSRND	C3604

RoHS10

**Bushings**

Type	Material
SJSPB	C3604

RoHS10

Part Number	Type	No.	R (PT)	L	L1	Unit Price	Volume
						1 - 9 pc(s)	Discount Rate
SJSMT	6A	1/8	34	17			
	8A	1/4	44	22			
	10A	3/8	50	25			
	15A	1/2	58	29			

For orders larger than indicated quantity, please check with WOS.

Part Number	Type	No.	R Rc (PT)	L	L1	L2	Unit Price	Volume
							1 - 9 pc(s)	Discount Rate
SJSXT	6A	1/8	44	22	19			
	8A	1/4	50	25	24			
	10A	3/8	58	29	28			
	15A	1/2	68	34	32			

For orders larger than indicated quantity, please check with WOS.

Part Number	Type	No.	R (PT)	L	B	Unit Price	Volume
						1 - 9 pc(s)	Discount Rate
SJSPG	6A	1/8	14	12			
	8A	1/4	18	16			
	10A	3/8	21	19			
	15A	1/2	25	21			

For orders larger than indicated quantity, please check with WOS.

Part Number	Type	No.	Rc (PT)		L	B	Unit Price	Volume
			T1	T2				
SJSFSD	12	1/8	1/4	26	17			
	13	1/8	3/8	28	21			
	23	1/4	3/8	30	21			
	24	1/4	1/2	36	26			
	34	3/8	1/2	38	26			
	36	3/8	3/4	44	32			
46	1/2	3/4	46	32				

For orders larger than indicated quantity, please check with WOS.

Part Number	Type	No.	R (PT)		L	B	Unit Price	Volume
			T1	T2				
SJSXSD	12	1/8	1/4	22	17			
	21	1/4	1/8	22	14			
	23	1/4	3/8	26	21			
	32	3/8	1/4	26	17			
	34	3/8	1/2	31	26			
	43	1/2	3/8	30	22			

For orders larger than indicated quantity, please check with WOS.

Part Number	Type	No.	R (PT)		L	B	Unit Price	Volume
			T1	T2				
SJSRND	12	1/8	1/4	26	14			
	13	1/8	3/8	29	17			
	23	1/4	3/8	31	17			
	24	1/4	1/2	34	22			
	34	3/8	1/2	36	22			
	36	3/8	3/4	41	27			
46	1/2	3/4	43	27				

For orders larger than indicated quantity, please check with WOS.

Part Number	Type	No.	Rc (PT)		L	B	Unit Price	Volume
			T1	T2				
SJSPB	12	1/8	1/4	16	17			
	13	1/8	3/8	19	19			
	23	1/4	3/8	19	19			
	24	1/4	1/2	21	24			
	34	3/8	1/2	21	24			
	36	3/8	3/4	25	30			
46	1/2	3/4	25	30				

For orders larger than indicated quantity, please check with WOS.



Fitting Specifications

Operating Temperature Range	-50 ~ 150°C (No Freezing)
Max. Operating Pressure	6.9MPa



Ordering Example  
SJSMT6A