
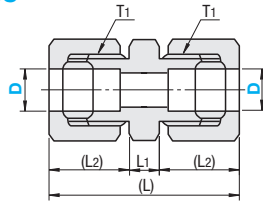


Copper Pipe Fittings

Copper Pipe Fittings Union

DKUS


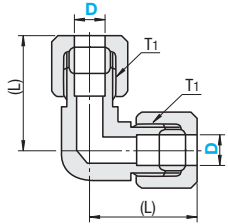



Ⓜ Ring included (part number: DKRG) Ⓜ Material: Brass

Part Number Type	Applicable Pipe O.D. D	(L)	L1	(L2)	T1G (PF)	Square		Unit Price
						Main Body	Nut	
DKUS	3	33	5	14.0	1/8	12	12	
	4	33	5	14.0	1/8	12	12	
	5	33	5	14.0	1/8	12	12	
	6	41	6	17.5	1/4	16	16	
	8	41	6	17.5	1/4	16	16	
	10	48	8	20.0	3/8	19	19	
	12	58	10	24.0	1/2	24	24	
	14	60	10	25.0	1/2	24	24	
15	65	11	27.0	5/8	27	27		
16	65	11	27.0	5/8	27	27		

Copper Pipe Fittings Union Elbow Connectors

DKUE


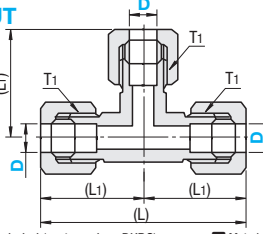



RoHS 10 Ⓜ Ring included (part number: DKRG) Ⓜ Material: Brass

Part Number Type	Applicable Pipe O.D. D	(L)	T1G (PF)	Square		Unit Price
				Main Body	Nut	
DKUE	3	25	1/8	12	12	
	4	25	1/8	12	12	
	5	25	1/8	12	12	
	6	31	1/4	16	16	
	8	31	1/4	16	16	
	10	35	3/8	19	19	
	12	42	1/2	24	24	
	14	43	1/2	24	24	
15	45	5/8	24	27		
16	45	5/8	24	27		

Copper Pipe Fittings Union Tees

DKUT


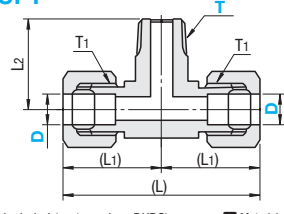



RoHS 10 Ⓜ Ring included (part number: DKRG) Ⓜ Material: Brass

Part Number Type	Applicable Pipe O.D. D	(L)	(L1)	T1G (PF)	Square		Unit Price
					Main Body	Nut	
DKUT	3	50	25	1/8	12	12	
	4	50	25	1/8	12	12	
	5	50	25	1/8	12	12	
	6	62	31	1/4	16	16	
	8	62	31	1/4	16	16	
	10	70	35	3/8	19	19	
12	84	42	1/2	24	24		

Copper Pipe Fittings Male Threaded Tee

DKUPT


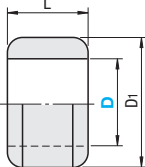
RoHS 10 Ⓜ Ring included (part number: DKRG) Ⓜ Material: Brass

Part Number Type	Applicable Pipe O.D. D	TR (PT) Selection	TR (PT)	(L)	(L1)	L2	T1G (PF)	Square		Unit Price
								Main Body	Nut	
DKUPT	4	1	1/8	50	25	20	1/8	12	12	
		2	1/4	54	27	25	1/8	16	12	
	5	1	1/8	50	25	20	1/8	12	12	
		2	1/4	54	27	25	1/8	16	12	
	6	1	1/8	62	31	22	1/4	16	16	
		2	1/4	62	31	25	1/4	16	16	
	3	1	1/8	66	33	28	1/4	19	16	
		2	1/4	62	31	22	1/4	16	16	
	8	2	1/4	62	31	25	1/4	16	16	
		3	3/8	66	33	28	1/4	19	16	
	10	2	1/4	70	35	27	3/8	19	19	
		3	3/8	70	35	28	3/8	19	19	
4	1	1/2	76	38	34	3/8	24	19		
	3	3/8	84	42	31	1/2	24	24		
12	3	3/8	84	42	34	1/2	24	24		
	4	1/2	84	42	34	1/2	24	24		

Ⓜ The PT thread size marked on the copper pipe fitting body might be different from actual size.

Copper Pipe Fittings Gland Ring

DKRG

RoHS 10 Ⓜ Material: Brass


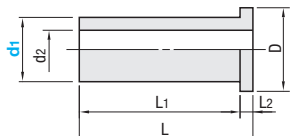
Part Number Type	Applicable Pipe O.D. D	D1	L	Unit Price 1 ~ 9 pcs(s).	Volume Discount Rate 10~20 pcs.
DKRG	3	5	5		
	4	6	5		
	5	7	5.5		
	6	8.5	7		
	8	10.5	7.5		
	10	12.5	8.5		
	12	15	10		
	14	17	11		
15	18	11.5			
16	19	12			

Ⓜ For orders larger than indicated quantity, please check with WOS.

Ordering Example: Part Number - T
DKUS3 - 2
DKUPT8 - 2

Pin-Ring Joints

DKPRJ

RoHS 10 Ⓜ Material: Brass

Part Number Type	d1	d2	D	L	L1	L2	Unit Price 1 ~ 4 pcs(s).	Volume Discount Rate 5~20 pcs.
DKPRJ	4	3.0	6.0	15.0	14.0	1.0		
	6	4.5	8.0	16.0	15.0	1.0		
	8	6.0	10.0	19.0	17.5	1.5		
	10	8.0	12.0	22.0	20.0	2.0		

Ⓜ For orders larger than indicated quantity, please check with WOS.

Fitting Specifications

Applicable Fluids	Air, Water, Industrial Oil
Normal Operating Pressure	3.5MPa
Max. Operating Pressure	7.0MPa
Operating Temperature Range	-20 ~ 150°C (No Freezing)