

■ For Aluminum Duct Hoses
45° Reducer

| Type | Material | Surface Treatment |
|--------|----------|---------------------|
| HOAFEM | SS400 | Baked Acrylic Paint |
| HOAFE | SUS304 | - |

RoHS10

■ For Aluminum Duct Hoses
Flanged

| Type | Material | Surface Treatment |
|------|----------|-------------------|
| HOAJ | SUS304 | - |

RoHS10

| Part Number | Type | Nominal Dia. | D | A1 | A2 | A3 | t | Unit Price | |
|-----------------|------|--------------|----|------|-------|-----|---|------------|-------|
| | | | | | | | | HOAFEM | HOAFE |
| HOAFEM HOAFE | 38 | 38 | 28 | 41 | 69 | 1.2 | | | |
| | 50 | 48.6 | 35 | 50 | 86.5 | 1.5 | | | |
| | 65 | 63.5 | 35 | 52.5 | 91 | | | | |
| | 75 | 75 | 35 | 56 | 95 | | | | |
| | 100 | 98 | 45 | 73 | 122 | 2 | | | |
| | 113 | 112 | 50 | 81.5 | 139 | | | | |
| | 125 | 124 | 55 | 89 | 151.5 | | | | |
| 150 | 149 | 60 | 98 | 170 | | | | | |

| Part Number | Type | Nominal Dia. | t | D1 | P. C. D. | d1 | Unit Price | |
|-------------|------|--------------|---|------|----------|-----|------------|--|
| | | | | | | | HOAJ | |
| HOAJ | 38 | | 2 | 66 | 52 | 6.6 | | |
| | 50 | | | 79 | 65 | | | |
| | 65 | | | 91.5 | 77.5 | | | |
| | 75 | | | 111 | 94 | | | |
| | 100 | | | 136 | 119 | 9 | | |
| | 113 | | | 152 | 134 | | | |
| | 125 | | | 168 | 148 | | | |
| | 150 | | | 193 | 173 | | | |



Ordering Example
Part Number
HOAFEM 38






Specifications
- Operating Temperature Range: 0 ~ 160°C

■ Duct Plumbing Manifolds



| Type | Size | Material |
|-----------------------------|----------------------------|----------|
| 2 Outlets DBXWS DBXWM | 150x150x300 200x200x300 | SUS304 |
| 3 Outlets DBXTS DBXTM | | |

① d1 is tapped hole, and nut is welded to the back side.
② There are no holes on other sides than the hole side.

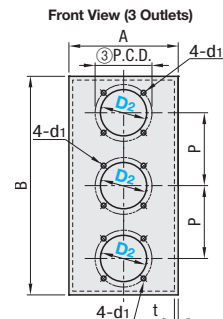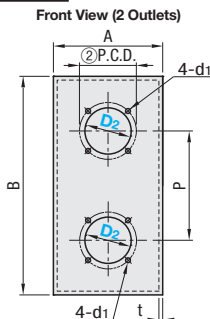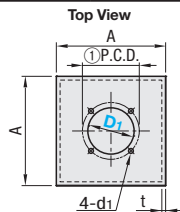

| Part Number | Type | D1 | D2 | A | B | D1 · D2 | P | | d1 | t | Unit Price 1 ~ 4 pc(s). | | | | |
|-------------|--|-----|-----|-----|-----|---------|----------|----------|----|----|-------------------------|-------|-------|-------|--|
| | | | | | | | ① P.C.D. | ② P.C.D. | | | DBXWS | DBXTS | DBXWM | DBXTM | |
| 150x150x300 | DBXWS (2 Outlets) DBXTS (3 Outlets) | 38 | 38 | 150 | 300 | 38 | 52 | 145 | 98 | M6 | 2 | | | | |
| | | 50 | 50 | | | 50 | 65 | | | | | | | | |
| | | 65 | 65 | | | 65 | 77.5 | | | | | | | | |
| | | 75 | 75 | | | 75 | 94 | | | | | | | | |
| | | 100 | 100 | | | 100 | 119 | | | | | | | | |
| 200x200x300 | DBXWM (2 Outlets) DBXTM (3 Outlets) | 38 | 38 | 200 | 300 | 38 | 52 | 145 | 98 | M6 | 2 | | | | |
| | | 50 | 50 | | | 50 | 65 | | | | | | | | |
| | | 65 | 65 | | | 65 | 77.5 | | | | | | | | |
| | | 75 | 75 | | | 75 | 94 | | | | | | | | |
| | | 100 | 100 | | | 100 | 119 | | | | | | | | |
| | | 113 | - | | | 113 | 134 | | | | | | | | |
| | | 125 | - | | | 125 | 148 | | | | | | | | |
| | | 150 | - | | | 150 | 173 | | | | | | | | |

① D2=75, 100 is not available for 3-story Type (DBXTS, DBXTM).



Ordering Example
Part Number - D1 - D2
DBXWS - 100 - 50
DBXTM - 113 - 38



Example

